

PrimEvo RS100E & SM100E

Productivity & reliability




RS100E



SM100E

PrimEvo RS100E & SM100E

- Available at your local wholesaler
- Plug and play, maintained and non-maintained in one
- Full LED range with best price/performance ratio

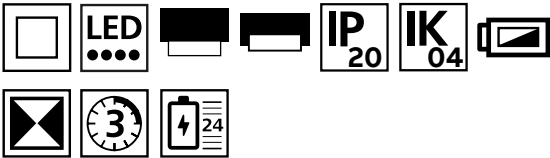

Luminaire


Order Code	Description	Input voltage	Lamp type	Power consumption** (VA/W)	Operation duration (hrs)	Environment temperature (°C)	Weight (kg)
RS100E	PrimEvo Recessed downlite	220 - 240 Vac, 50 Hz	2 x LED 1.5W*	10/4.8	3	0 - 25	0.425
SM100E	PrimEvo Surface downlite	220 - 240 Vac, 50 Hz		9/4.5	3	0 - 25	0.425

* = 3W LED

** maintained mode



PrimEvo RS100E

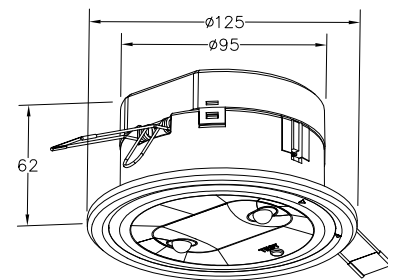

PrimEvo SM100E

