

Stanilite®

Platinum batten LED weatherproof - 5 foot - DALI on AC



Range

Platinum range

Product group


Batten LED



Features

- Typically 4,600 lumens on mains AC operation
- Dimming to 1% via DALI, mains only
- Weatherproof rating IP65
- IK08 impact rating
- Ceiling, wall mount or suspension mounting (wall mount requires optional 45° mounting brackets)
- Long LED life 75,000 hours
- Colour temperature 4,000K
- High colour rendering index CRI>80
- Mains terminal block accepts up to 2.5mm² cable
- External mounting clips for ease of installation
- Stainless steel diffuser clips
- High efficiency frosted polycarbonate diffuser
- AC efficacy typically 121 lumens/watt
- Ambient operating temperature; AC -20°C to +40°C
- DALI lighting management, mains only

Catalogue no.	Description
Standard products	
PBLWAC46L-DALI	Platinum batten LED weatherproof AC 4600 lumens - DALI on AC
Accessories	
21-PCCSBLW	Polycarbonate clips
26-PBMD001	Wall mount bracket pair 45°
PBLWSS316-KIT	SS316 marine grade accessory kit (includes diffuser clips x 10, suspension clips x 2, mounting bracket x 2 and M4 x 8 screws x 2)

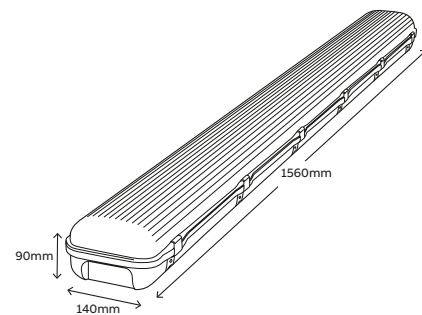

Dimensions		
Length	Width	Bare height
1560mm	140mm	90mm
Weight		
Model	Weight	
AC	3.2kg	
Construction		
Part	Construction	
Reflector	Powder coated steel	
Body and diffuser	Polycarbonate	
Clips	Stainless steel	

Light source				
	Model	Light source		
	AC	LED strips		

Power consumption				
	Model	Normal	S/A off	Standby
	AC	39.5W	0W	N/A

Note: Preliminary results

Note:
 – AC designed to comply with AS/NZS60598.2.1 and meet relevant Australian EMC standard