


Deep Blue™ is the largest single gang box from Carlon®


Carlon's most versatile box ever for professionals and DIYers alike

Carlon is proud to introduce its largest and most versatile non-metallic box ever — in single- or double-gang designs that work on wood or steel studs; in new or old work; with simple, fast installation.

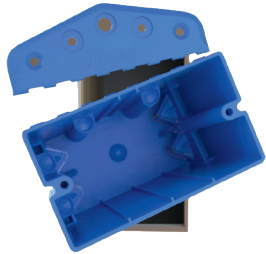

A unique combination of features:

- Captive nails and screw guides — for vertical or horizontal mounting.
- Break away flanges — for new or old work.
- Generous size — to hold dimmers and large switches.

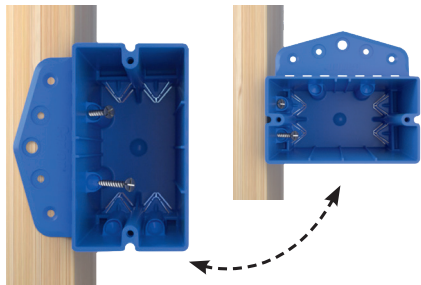

All in the same Carlon blue... because blue boxes meet Code!

Installs on both steel and wood studs



Available in one and two-gang



Contacts

ABB Installation Products


860 Ridge Lake Blvd
 Memphis, TN 38120
 USA
 tnb.abb.com

ABB Tech Support

888-862-3289
 Email: techsupport@us.abb.com

Carlon®

Largest single and double gang Multipurpose non-metallic electrical box

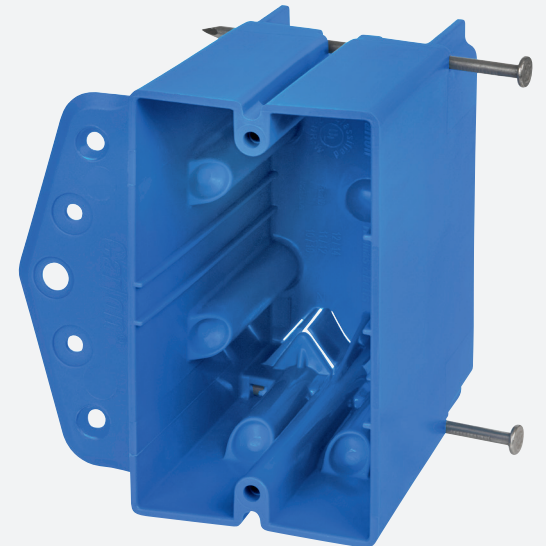


We reserve the right to make technical changes or modify the contents of this document without prior notice. With regard to purchase orders, the agreed particulars shall prevail. ABB AG does not accept any responsibility whatsoever for potential errors or possible lack of information in this document.

We reserve all rights in this document and in the subject matter and illustrations contained therein. Any reproduction, disclosure to third parties or utilization of its contents – in whole or in parts – is forbidden without prior written consent of ABB AG.


Copyright© 2019 ABB
 All rights reserved

Features

B125AB

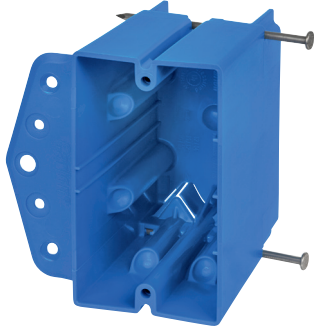

B249B

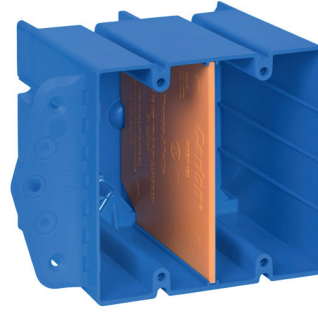

SCDIVS



B125AB	Features
	Carlson's largest standard single gang at 24.5 cu. in.
	New work and old work—stud mount applications
	Suitable for wood and steel studs
	Suitable for horizontal and vertical mounting
	Easy installation with captive nails
	Internal screw guides for installation
	Internal mounts allow to change depth of install
	Flange for new work application
	Break away flange for old work application
	Internal screws (not provided) #6x1.25" minimum
	Accepts wire fill/size: 12/14, 11/12, 10/10



Size (cu. in)	Mounting means	Dimensions (in.)	Std. Ctn
24.5	Captive nails, side flange, internal screws	3 15/16 L 2 7/32 W 3 13/16 D	24

B249B	Features
	Carlson's largest double-gang at 48.2 cu. in.
	Voltage divider available
	Suitable for old work and new work
	Suitable for wood and steel studs
	Internal screw guides for installation
	Internal mounts allow to change depth of install
	Flange for new work application
	Break away flange for old work application
	Internal screws (not provided) #6x1.25" minimum
	Accepts wire fill/size: 23/14, 20/12, 18/10



Size (cu. in)	Mounting means	Dimensions (in.)	Std. Ctn
48.2	Side flange, internal screws	3 15/16 L 4 1/32 W 3 13/16 D	12

SCDIVS	Features
	For high and low-voltage closed back box
	Slip-in place divider
	Ideal for Fire-rated box



Size (cu. in)	Mounting means	Dimensions (in.)	Std. Ctn
-	Insert into double gang B249B	-	5



**WATCH
OUR VIDEO**

