


# Guideway

Innovative & stylish



### Guideway 22m & 32m - Surface mount in black

- Bright and uniformed light distribution with 500 cd/sq.m
- Versatile mounting options with First-Fix control gear
- Unique frameless legend design with click-lock assembly
- Quick release legend panels

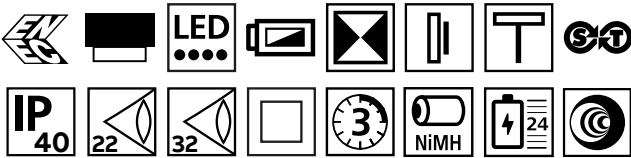

### Luminaire

Order code	Description	Input voltage	Lamp type	Power consumption (VA/W)	Operation / duration (hrs)	Environment temp. (°C)	Weight (kg)
CTEG3LS1-S22B	LED SIGN M3 CT-NAVEO 22M BLK	220-240 AC 50Hz	1 x LED 2W	4.4 / 4	3	5-35	1.5
CTEG3LS1-S32B	LED SIGN M3 CT-NAVEO 32M BLK	220-240 AC 50Hz	1 x LED 4W	7.1 / 6.5	3	5-35	1.6
EG3LS1-S22B	LED SIGN SELF-TEST M3 22M BLK	220-240 AC 50Hz	1 x LED 2W	4.4 / 4	3	5-35	1.5
EG3LS1-S32B	LED SIGN SELF-TEST M3 32M BLK	220-240 AC 50Hz	1 x LED 4W	7.1 / 6.5	3	5-35	1.6
EG1LS1LTC-S22B	LED SIGN 230VAC EMEX LTC 22M BLK	220-240 AC 50/60Hz	1 x LED 2W	4.4 / 4	230V	0-35	1.5
EG1LS1LTC-S32B	LED SIGN 230VAC EMEX LTC 32M BLK	220-240 AC 50/60Hz	1 x LED 4W	7.1 / 6.5	230V	0-35	1.6
EG1LS1D-S22B	LED SIGN SL 230VAC DIM 22M BLK	220-240 AC/DC 0-60Hz	1 x LED 2W	4.4 / 4	230V	0-35	1.5
EG1LS1D-S32B	LED SIGN SL 230VAC DIM 32M BLK	220-240 AC/DC 0-60Hz	1 x LED 4W	7.1 / 6.5	230V	0-35	1.6
EG1LS1-S22B	LED SIGN SL 230VAC 22M BLK	220-240 AC/DC 0-60Hz	1 x LED 2W	4.4 / 4	230V	0-35	1.5
EG1LS1-S32B	LED SIGN SL 230VAC 32M BLK	220-240 AC/DC 0-60Hz	1 x LED 4W	7.1 / 6.5	230V	0-35	1.6

60 hrs charge at first commissioning, 24 hrs re-charge thereafter  
Includes back to the wall mounting accessory as standard  
Add '-00' for product without legends

### Single sided

Part No.	Legends
<b>ISO 7010 legend format</b>	
XEN2EG22 or XEN2EG32	
XEN3EG22 or XEN3EG32	
XEN6EG22 or XEN6EG32	
XEN5EG22 or XEN5EG32	
XEN0G22 or XEN0G32	
<b>Arabic legend format</b>	
XBN1EG22 or XBN1EG32	

ISO 7010 pictogram legends are shown  
Euro format & Special legends are available  
to order see pages 139-141

### Flag mounted

Part No.	Legends
<b>ISO 7010 legend format</b>	
XEN602EG22 or XEN602EG32	
XEN603EG22 or XEN603EG32	
XEN606EG22 or XEN606EG32	
XEN605EG22 or XEN605EG32	

