


## Aqualux Freez-Lite

Durable & high performance



### High power open area luminaire

- Attractive aluminium modular enclosure
- Clear polycarbonate broad delivery diffuser
- Intelligent self-test as standard
- Complies to IEC 60598.2.22

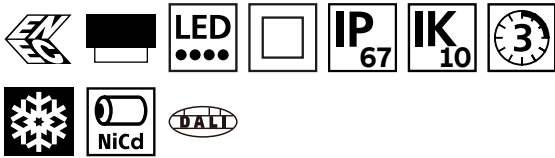

### Luminaire

Order code	Description	Input voltage	Lamp type	Lamp output (lm)	Power consumption (VA/W)	Operation / duration (hrs)	Environment temp. (°C)	Weight (kg)
CTSTF3L261	CT 2LED M3	220-240 AC 50Hz	2 x LED 1W	59	17.2/11.2	3	-25-+30	1.7
STF3L261	2LED M3	220-240 AC 50Hz	2 x LED 1W	59	17.2/11.2	3	-25-+30	1.7
DLSTF3LS60	3W LED DALI M3	220-240 AC 50Hz	1 x LED 3W	79	17.2/11.2	3	-25-+30	1.7

### Legends

Part No.	Pictogram
XEN2W	
XEN3W	
XEN6W	
XEN5W	
XLF802W	
XLF803W	

### Arabic legend format

On request	
------------	--

ISO 7010 pictogram legends are shown. Euro format & Special legends are available to order see pages 138-141.

### Accessories

Order code	Description
OW/BCM	Ceiling bracket, vertical mount
OW/BWA	Wall bracket, angled mount
OW/BWM	Wall mount end cantilever bracket
OW/BCR	Recessing kit

