
TECHNICAL DATA SHEET

Cable Tie, releasable

Natural and black

Catamount®



Feature:

- Releasable head

Materials and Finishes:

- Nylon 6.6 natural
- Nylon 6.6 UV resistant black

Cable ties are primarily used to cinch wires and cables together to form a neat and organized bundle.

Certifications / Standards:




Ratings:

- Minimum operating temperature: -40°C (-40°F)
- Maximum operating temperature: 85°C (185°F)
- Minimum installing temperature: -20°C (-4°F)
- Tensile Strength: 222N (50lbs)

Cable tie, releasable:

- Natural and black

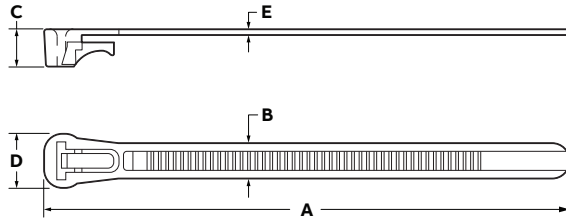

Part number characteristic:

L-5-50R-0-C

- C = 100 pack
- D = 1000 pack
- 0 = Nylon 6.6 UV resistant black
- 9 = Nylon 6.6 natural

Product selection - inches (mm)

Part no: GID no:	Min bundle diameter	Max bundle diameter	A ± 0.125 (3.0)	B ±0.01 (0.25)	C ±0.03 (0.76)	D ±0.03 (0.76)	E ±0.01 (0.25)	Tensile strength lbs. (N)
L-5-50R-0-C *	0.28 (7.0)	1.38 (35)	5.90 (150)	0.30 (7.6)	0.31 (8)	0.46 (11.6)	0.05 (1.3)	50 (222)
7TAG054750R0012								
L-5-50R-0-D *	0.28 (7.0)	1.38 (35)	5.90 (150)	0.30 (7.6)	0.31 (8)	0.46 (11.6)	0.05 (1.3)	50 (222)
7TAG054750R0013								
L-5-50R-9-C *	0.28 (7.0)	1.38 (35)	5.90 (150)	0.30 (7.6)	0.31 (8)	0.46 (11.6)	0.05 (1.3)	50 (222)
*7TAG054750R0014								
L-5-50R-9-D *	0.28 (7.0)	1.38 (35)	5.90 (150)	0.30 (7.6)	0.31 (8)	0.46 (11.6)	0.05 (1.3)	50 (222)
7TAG054750R0015								
L-8-50R-0-C	0.28 (7.0)	1.97 (50)	7.87 (200)	0.30 (7.6)	0.31 (8)	0.46 (11.6)	0.05 (1.3)	50 (222)
7TAG054750R0016								
L-8-50R-0-D	0.28 (7.0)	1.97 (50)	7.87 (200)	0.30 (7.6)	0.31 (8)	0.46 (11.6)	0.05 (1.3)	50 (222)
7TAG054750R0017								
L-8-50R-9-C	0.28 (7.0)	1.97 (50)	7.87 (200)	0.30 (7.6)	0.31 (8)	0.46 (11.6)	0.05 (1.3)	50 (222)
7TAG054750R0018								
L-8-50R-9-D	0.28 (7.0)	1.97 (50)	7.87 (200)	0.30 (7.6)	0.31 (8)	0.46 (11.6)	0.05 (1.3)	50 (222)
7TAG054750R0019								
L-10-50R-0-C	0.28 (7.0)	3.15 (80)	11.89 (302)	0.30 (7.6)	0.31 (8)	0.46 (11.6)	0.06 (1.5)	50 (222)
7TAG054750R0009								
L-10-50R-0-D	0.28 (7.0)	3.15 (80)	11.89 (302)	0.30 (7.6)	0.31 (8)	0.46 (11.6)	0.06 (1.5)	50 (222)
7TAG054740R0001								
L-10-50R-9-C	0.28 (7.0)	3.15 (80)	11.89 (302)	0.30 (7.6)	0.31 (8)	0.46 (11.6)	0.06 (1.5)	50 (222)
7TAG054750R0011								
L-10-50R-9-D	0.28 (7.0)	3.15 (80)	11.89 (302)	0.30 (7.6)	0.31 (8)	0.46 (11.6)	0.06 (1.5)	50 (222)
7TAG054980R0597								

Note: Product must be installed in accordance with applicable national and local electrical codes.

* L-5-50R series ties are Type 11 UR