

08/2022

Impressivo White Matt

Consistent electrification for flush and surface mounting



The modern design and unique soft touch surface material of Impressivo White Matt are now available for both surface and flush mounting.



Create luxurious atmosphere, play with or fade your building project with white matte colour (RAL 9016). Combine the best installability on the market with uncompromising elegance in both new construction and renovation projects.

Product range

The series is suitable for both flush and surface mounting in common dry and wet environments. Cover frames are available in 1–5 pieces (85 mm and 100 mm), and they can be mounted either vertically or horizontally.

Surface material

Pleasant to touch with a wear-resistant surface. Surface material: shockproof, unbreakable and UV-resistant thermoplastic. Contains no PVC or halogen compounds.

Clean and sleek design

Can be freely combined with Impressivo, steel, accent and carat designs.

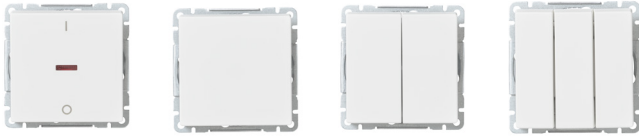


ABB Oy
Porvoon Sisäkehä 2, PO Box 16
FI-06101 Porvoo, Finland
Phone: +358 10 22 11

Order information

Flush mounted range - Impressivo White Matt

Semi-complete switches




Type	Description	Package
1062UC-884	2-pole 1-gang 1-way switch, 16AX/250V/IP21 UKJ 2X	1
10621UC-884	2-pole 2-gang 1-way switch, 16AX/250V/IP21 UKJ 0X	1
1066UC-884	1-gang 2-way switch, 16AX/250V/IP21 UKJ 2X	1
1065UC-884	2-gang 1-way switch, 16AX/250V/IP21 UKJ 2X	1
10666UC-884	2-gang 2-way switch, 16AX/250V/IP21 UKJ 0X	1
1067UC-884	1-gang intermediate switch, 16AX/250V, IP21, UKJ 2X	1
10631UC-884	3-gang 1-way switch, 16AX/250V/IP21 UKJ 0X	1

Socket outlets



Type	Description	Package
20EUCKS-884	1-gang with center plate	1
20EUCK-884	1-gang with lid	1
20EUJW-884	1-gang with cover plate, whole	1
20EUCBLI-884	1-gang with LED light	1
20EUCBUSB-884	1-gang with USB charger	1
302EUC-884	2-gang with center plate	1
302EUJ-884	2-gang with cover plate	1
302EUCK-884	2-gang with lid	1
302EUJW-884	2-gang with cover plate, whole	1
303UC-884	3-gang euro	1
3120EUC-884	Socket residual current device with a rated current of 16 A and s rated residual current of 30mA	1
3150UC-884.1	Residual current device with a rated current of 16A and s rated residual current of 30mA	1

Electronics

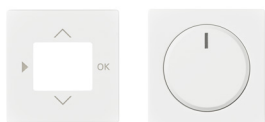

Type	Description	Package
6435-884	Center plate for thermostat/timer switch/timer	1
6540-884-102-510	Center plate for dimmer with neon lamp	1

Rockers for switches and push switches




Type	Description	Package
1786-884	Switch rocker, 1-gang	1
1785-884	Switch rocker, 2-gang	1
1783-884	Switch rocker, 3-gang	1
1788-884	Switch rocker, 1-gang, red lens, "1/0" symbol	1
1789-884	Switch rocker, 1-gang, red lens	1
1789KI-884	Switch rocker, 1-gang, "bell" symbol, lens	1
1789LI-884	Switch rocker, 1-gang, "light" symbol, lens	1
1789TR-884	Switch rocker, 1-gang, "key" symbol, lens	1
1764NLI-884	Switch rocker, 1-gang, nameplate	1
1785JA-884	Switch rocker, 2-gang, "up/down" symbol	1

Cover frames



Type	Description	Package
1721F85-884	1-gang, 85 mm	1
1722F85-884	2-gang, 85 mm	1
1723F85-884	3-gang, 85 mm	1
1724F85-884	4-gang, 85 mm	1
1725F85-884	5-gang, 85 mm	1
1721F100-884	1-gang, 100 mm	1
1722F100-884	2-gang, 100 mm	1
1723F100-884	3-gang, 100 mm	1
1724F100-884	4-gang, 100 mm	1
1725F100-884	5-gang, 100 mm	1

 Center plates and adapters



Type	Description	Package
1819DC-884	Center plate, 2xRJ45 with sliding dust covers	1
1766-884	Center plate for tele outlet	1
1743-884	Center plate, TV/R/Sat	1
1758-884	DKS center plate, DKS-system	1
2533-884	Tele outlet, 22,5 mm hole	1
1792-884	Center plate for card switch 8114.1	1
1742-884	Center plate, blind, 80 mm	1
2538-100-884	Blind center plate, 100 mm	1
2519-884	Adapter 85/100mm, IP21/IP44	1

Order information

Surface mounted range - Impressivo White Matt

Level controllers



Type	Description	Package
1066A-884	1-gang 2-way switch, 16AX/250V, IP21 PPJ 2X	1
1065A-884	2-gang 1-way switch, 16AX/250V, IP21 PPJ 2X	1

Surface socket outlets




Type	Description	Package
20ESW-884	1-gang socket outlet 16A/IP44 PPJ 1X	1
402EA-884	2-gang socket outlet 16A/IP21 PPJ HL	1
302ESW-884	2-gang socket outlet 16A/IP44 PPJ HL, with cover plate	1
402EE-884	2-gang socket outlet 16A/IP21 PPJ HL, angular mounting	1
402EL-884	2-gang socket outlet 16A/IP21 PPJ HL, batten-mounting	1
404EA-884	4-gang socket outlet 16A/IP21 PPJ HL	1

Surface boxes



Type	Description	Package
1722H-884	2-gang surface box 85 mm, angular mounting	1
1721L-884	2-gang surface box 85mm, batten-mounting	1
1721A-884	1-gang surface box 85 mm, height 41 mm	1
1721S80-884	1-gang surface box 80 mm, height 54 mm	1
1722S80-884	2-gang surface box 80 mm, height 54 mm	1
1723S80-884	3-gang surface box 80 mm, height 54 mm	1

Surface frames

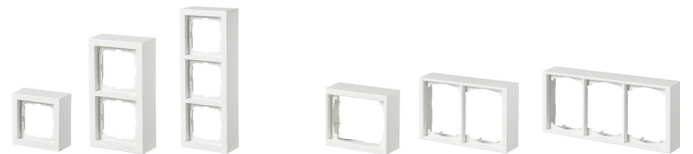

Type	Description	Package
1721S85-884	1-gang surface frame 85 mm, height 40 mm	1
1722S85-884	2-gang surface frame 85 mm, height 40 mm	1
1723S85-884	3-gang surface frame 85 mm, height 40 mm	1
1721S100-884	1-gang surface frame 100 mm, height 40 mm	1
1722S100-884	2-gang surface frame 100 mm, height 40 mm	1
1723S100-884	3-gang surface frame 100 mm, height 40 mm	1