


On-load tap-changer type UBBR, 21 tap positions, reverser.
 Max effective No. of turns in pos I.
 The tap-changer is delivered set in pos II, the preceding pos. was IIA.

Lindningskopplare typ UBBR, 21 lägen, plus/minus-koppling.
 Max antal effektiva varv i läge I.
 Lindningskopplaren levereras inställd i läge II, föregående läge var IIA.

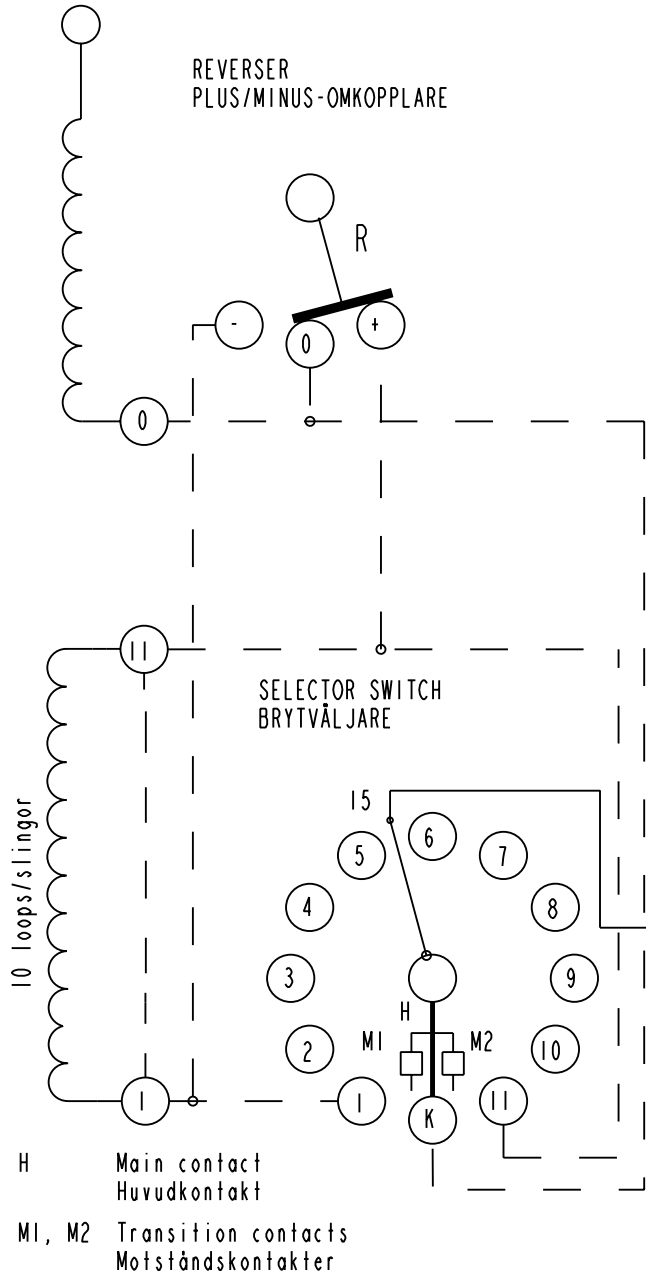

Pos Läge	R connects förbinder	H connects förbinder
1		1 - 15
2		2 - 15
3		3 - 15
4		4 - 15
5		5 - 15
6		6 - 15
7	0+	7 - 15
8		8 - 15
9		9 - 15
10		10 - 15
11A		11 - 15
11		K - 15
11B		1 - 15
12		2 - 15
13		3 - 15
14		4 - 15
15		5 - 15
16	0-	6 - 15
17		7 - 15
18		8 - 15
19		9 - 15
20		10 - 15
21		11 - 15

1) OUTPUT TERMINAL
STRÖMAVTAGNING

1) Internal connections between the terminals 15 of the three phases are included in the star-point type. Dashed lines show in delivery not included leads belonging to cleats and leads.

Inre förbindningar mellan uttag 15 i de tre faserna ingår i nollpunktsutförande. Streckade linjer visar i leveransen ej ingående ledare tillhörande anslutningsdonet.

We reserve all rights in this document and in the information contained therein. Reproduction, use or disclosure to third parties without express authority is strictly forbidden. © ABB 19

Sheet	Cont
Year	Week
Dept	
Rev Ind	Revision
Appd	Year Week
Rev Ind	Accepted for prod by
Design checked by	Drawn by
Design checked by	Issued by Dept Year Week

Accepted by qual control
R. Yngvesson

Accepted for prod by

Design checked by
B-O. Stenestam

Drawn by
L. Bergman

Design checked by
M. Hedlund

Issued by Dept Year Week
COM/TKO 97 32

Description (English)
CONNECTION DIAGRAM UBBR

DATA ORIGINAL

Description (own language)
KOPPLINGSSCHEMA UBBR

File name
0388-8

Lang Sheet
1

Rev Ind Cont
-



Asea Brown Boveri

5492 0388-8