

# 产品认证证书

## II型自愿认证

证书编号: CQC2016010309922937

发证日期: 2022年03月14日

有效期至: 2031年09月23日

委托人名称	ABB Stotz-Kontakt GmbH
及注册地址	Eppelheimer Strasse 82 69123 Heidelberg Germany
制造商名称	ABB Stotz-Kontakt GmbH
及注册地址	Eppelheimer Strasse 82 69123 Heidelberg Germany
生产企业名称	ABB Bulgaria EOOD
及生产地址	1, Varna Str., 2850 Petrich, Bulgaria
产品名称和系列、规格、型号	热过载继电器 TA42DU,TA75DU,TA80DU Ui: 690V; Uimp : 6kV; Ue: 690V; Ie: 18-25, 22-32, 29-42A(TA42DU), 18-25, 22-32, 29-42, 36-52, 45-63, 60-80A(TA75DU), 29-42, 36-52, 45-63, 60-80A(TA80DU); 脱扣级别: 10A, 20; 极数: 3P; IP20; 配用的辅助触头: (本体) Ith : 6A(NO), 10A(NC); AC-15 : NO : Ue/Ie : 240V/1.5A , 440V/1A , 500V/1A ; AC-15 : NC : Ue/Ie : 240V/3A , 440V/1A , 500V/1A ; DC-13 : NO : Ue/Ie : 24V/1.25A , 125V/0.25A , 250V/0.04A ; DC-13 : NC : Ue/Ie : 24V/1.25A , 125V/0.25A , 250V/0.12A; 1NO1NC ; 型号解释见附件
产品标准和技术要求	GB/T 14048.4-2020
认证模式	产品型式试验+初次工厂检查+获证后监督

上述产品符合 CQC12-000001-2020 认证规则的要求, 特发此证。

本证书为变更证书, 证书首次颁发日期: 2020年09月02日

证书有效期内本证书的有效性依据发证机构的定期监督获得保持。

可通过扫描下方二维码或登录国家认监委网站(www.cnca.gov.cn)查验证书信息



授权签字人

陈昕

签发

谢肇煦

中国质量认证中心



<http://www.cqc.com.cn>

中国·北京·南四环西路188号9区 100070

电话: +86 10 83886666

C(2) 0152612

# CERTIFICATE OF PRODUCT CERTIFICATION

## TYPE II CQC CERTIFICATION

CERTIFICATE NO.: CQC2016010309922937

Valid from: Mar.14,2022

Valid until: Sep.23,2031

<b>NAME AND REGISTERED ADDRESS OF THE APPLICANT</b>	ABB Stotz-Kontakt GmbH Eppelheimer Strasse 82 69123 Heidelberg Germany
<b>NAME AND REGISTERED ADDRESS OF THE MANUFACTURER</b>	ABB Stotz-Kontakt GmbH Eppelheimer Strasse 82 69123 Heidelberg Germany
<b>NAME AND LOCATION OF THE FACTORY</b>	ABB Bulgaria EOOD 1, Varna Str., 2850 Petrich, Bulgaria
<b>PRODUCT NAME, MODEL AND SPECIFICATION</b>	Thermal Overload Relay TA42DU,TA75DU,TA80DU Ui: 690V; Uimp : 6kV; Ue: 690V; Ie: 18-25, 22-32, 29-42A(TA42DU), 18-25, 22-32, 29-42, 36-52, 45-63, 60-80A(TA75DU), 29-42, 36-52, 45-63, 60-80A(TA80DU); TRIP CLASS: 10A, 20; 3P ; IP20;Auxiliary contact for use : Ith :6A(NO), 10A(NC) ; AC-15 :NO :Ue/Ie : 240V/1.5A , 440V/1A , 500V/1A ; AC-15 : NC : Ue/Ie : 240V/3A , 440V/1A , 500V/1A ; DC-13 : NO : Ue/Ie : 24V/1.25A , 125V/0.25A , 250V/0.04A ; DC-13 :NC :Ue/Ie :24V/1.25A , 125V/0.25A , 250V/0.12A; 1NO1NC; See attachment for model explanation
<b>THE STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS</b>	GB/T 14048.4-2020
<b>TYPE OF CERTIFICATION SCHEMES</b>	Type Testing of Product + Initial Factory Inspection + Follow up Factory Inspection

This is to certify that the above mentioned product(s) complies with the requirements of certification rules of CQC12-000001-2020.

Date of original issued: Sep.02,2020

The validity of the certificate is subject to positive result of the regular follow up inspection by issuing certification body until the expiry date.

The certificate information is available through the QR code below or CNCA's website: [www.cnca.gov.cn](http://www.cnca.gov.cn)



SIGN BY

陈昕

SIGNATURE

谢肇煦



CHINA QUALITY CERTIFICATION CENTRE



# 产品认证证书

## II型自愿认证


证书编号: CQC2016010309922937

本证书及附件应同时使用, 信息查验说明见证书页

型号解释:

第1页 共3页

纸号: 152612

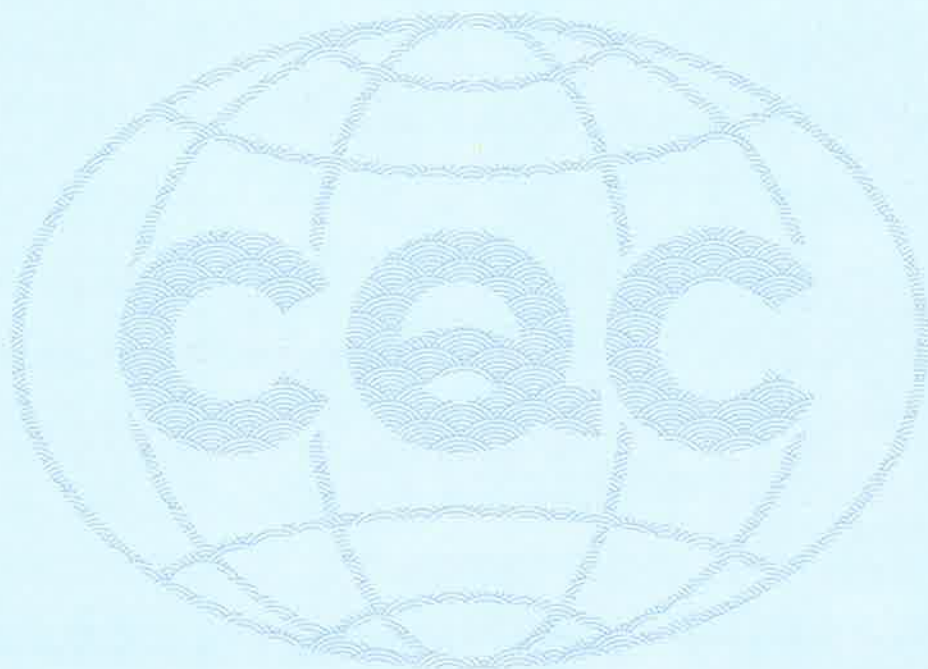

中国质量认证中心



# 产品认证证书

## II型自愿认证

证书编号: CQC2016010309922937

第 2 页 共 3 页

本证书及附件应同时使用, 信息查验说明见证书页

纸号: 152612

TA 42 D U - 25 - 20 -V1000  
1 2 3 4 5 6 7

1. Thermal Overload Relay 热过载继电器

2. Current code 电流代号: 42, 75, 80

3. Phase failure protection 缺相保护

4. Reset manual or automatic 复位功能可选手动或自动

5. Upper setting current 最大额定电流

6. Trip Class 脱扣级别: blank: 10A

-20: 20

7. Blank 空白: Standard version 标准版本

-V1000: Optional to indicate the ATEX version (Trip class 10 only)ATEX 认证版本 (仅适用于脱扣级别 10A)

-RT: Ring Tongue terminal version 环形端子版本

M: Marketing Variant 市场特定型号

Standard types			Standard types		
Order code	Type long	Setting range	Order code	Type long	Setting range
ISAZ311201R1001	TA42DU-25	18-25	ISAZ311401R1001	TA42DU-25-20	18-25
ISAZ311201R1002	TA42DU-32	22-32	ISAZ311401R1002	TA42DU-32-20	22-32
ISAZ311201R1003	TA42DU-42	29-42	ISAZ311401R1003	TA42DU-42-20	29-42
ISAZ321201R1001	TA75DU-25	18-25	ISAZ321401R1001	TA75DU-25-20	18-25
ISAZ321201R1002	TA75DU-32	22-32	ISAZ321401R1002	TA75DU-32-20	22-32
ISAZ321201R1003	TA75DU-42	29-42	ISAZ321401R1003	TA75DU-42-20	29-42
ISAZ321201R1004	TA75DU-52	36-52	ISAZ321401R1004	TA75DU-52-20	36-52
ISAZ321201R1005	TA75DU-63	45-63	ISAZ321401R1005	TA75DU-63-20	45-63
ISAZ321201R1006	TA75DU-80	60-80	ISAZ321401R1006	TA75DU-80-20	60-80
ISAZ331201R1003	TA80DU-42	29-42	ISAZ331401R1003	TA80DU-42-20	29-42
ISAZ331201R1004	TA80DU-52	36-52	ISAZ331401R1004	TA80DU-52-20	36-52
ISAZ331201R1005	TA80DU-63	45-63	ISAZ331401R1005	TA80DU-63-20	45-63
ISAZ331201R1006	TA80DU-80	60-80	ISAZ331401R1006	TA80DU-80-20	60-80
ISAZ381201R1003	TA80DU-42-RT	29-42			
ISAZ381201R1004	TA80DU-52-RT	36-52			
ISAZ381201R1005	TA80DU-63-RT	45-63			
ISAZ381201R1006	TA80DU-80-RT	60-80			



中国质量认证中心



# 产品认证证书

## II型自愿认证

证书编号: CQC2016010309922937

第3页 共3页

本证书及附件应同时使用, 信息查验说明见证书页

纸号: 152612

Standard types		
Order code	Type long	Setting range
ISAZ311201R2001	TA42DU-25M	18-25
ISAZ311201R2002	TA42DU-32M	22-32
ISAZ311201R2003	TA42DU-42M	29-42
ISAZ321201R2001	TA75DU-25M	18-25
ISAZ321201R2002	TA75DU-32M	22-32
ISAZ321201R2003	TA75DU-42M	29-42
ISAZ321201R2004	TA75DU-52M	36-52
ISAZ321201R2005	TA75DU-63M	45-63
ISAZ321201R2006	TA75DU-80M	60-80
ISAZ331201R2003	TA80DU-42M	29-42
ISAZ331201R2004	TA80DU-52M	36-52
ISAZ331201R2005	TA80DU-63M	45-63
ISAZ331201R2006	TA80DU-80M	60-80



中国质量认证中心

