



# 中国国家强制性产品认证证书

证书编号: 2008010304290409

委托人名称、地址

ABB France

3 Rue Jean Perrin CS 90009 69687, Chassieu Cedex, FRANCE

生产者(制造商)名称、地址

ABB新会低压开关有限公司

广东省江门市新会区今古洲工业开发区

生产企业名称、地址

ABB新会低压开关有限公司

广东省江门市新会区今古洲工业开发区

产品名称和系列、规格、型号

切换电容器接触器

UA50, UA63, UA75; 详见附件

产品标准和技术要求

GB 14048.4-2010

上述产品符合强制性产品认证实施规则  
CNCA-C03-02: 2014的要求, 特发此证。

发证日期: 2017年01月22日

有效期至: 2022年01月22日

证书有效期内本证书的有效性依据发证机构的定期监督获得保持。

本证书为变更证书, 证书首次颁发日期: 2008年08月29日

本证书的相关信息可通过国家认监委网站www.cnca.gov.cn查询



主任:

中国质量认证中心


中国·北京·南四环西路188号9区 100070

<http://www.cqc.com.cn>



Q 1615471



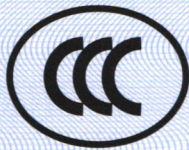

# CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

No. : 2008010304290409

## NAME AND ADDRESS OF THE APPLICANT

ABB France  
3 Rue Jean Perrin CS 90009 69687, Chassieu Cedex, FRANCE

## NAME AND ADDRESS OF THE MANUFACTURER

ABB Xinhui Low Voltage Switchgear Co., Ltd.  
Jinguzhou Industrial Development Zone, Xinhui Region, Jiangmen City,  
Guangdong Province

## NAME AND ADDRESS OF THE FACTORY

ABB Xinhui Low Voltage Switchgear Co., Ltd.  
Jinguzhou Industrial Development Zone, Xinhui Region, Jiangmen City,  
Guangdong Province

## NAME, MODEL AND SPECIFICATION

Contactor

UA50, UA63, UA75; see the Appendix

## THE STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS

GB 14048.4-2010

This is to certify that the above mentioned products have met the requirements of implementation rules for compulsory certification (REF NO. CNCA-C03-02:2014).

Date of issue: Jan. 22, 2017      Date of expiry: Jan. 22, 2022

Validity of this certificate is subject to positive result of the regular follow up inspection by issuing certification body until the expiry date.

Date of original certification: Aug. 29, 2008

This certificate can be verified through CNCA's website: [www.cnca.gov.cn](http://www.cnca.gov.cn)



President:

Wang Kejiao

**CHINA QUALITY CERTIFICATION CENTRE**

Section 9, No. 188, Nansihuan Xilu, Beijing 100070 P.R. China

<http://www.cqc.com.cn>



Q 1615471





# 中国国家强制性产品认证证书

附录:

第 1 页 共 1 页

证书编号: 2008010304290409

纸号: 1615471

UA50, UA63, UA75

UA50: Ith: 100A;

Ue: 230/240V, 400/415V, 440V, 500/550V, 690V; Ie: 51A, 51A, 51A, 51A, 51A;

Qe: 20kvar, 33kvar, 36kvar, 40kvar, 55kvar;

UA63: Ith: 125A;

Ue: 230/240V, 400/415V, 440V, 500/550V, 690V; Ie: 66A, 66A, 66A, 66A, 66A;

Qe: 25kvar, 45kvar, 50kvar, 50kvar, 70kvar;

UA75: Ith: 125A;

Ue: 230/240V, 400/415V, 440V, 500/550V, 690V; Ie: 76A, 76A, 76A, 76A, 76A;

Qe: 30kvar, 50kvar, 55kvar, 62kvar, 75kvar;

Us: AC 50/60Hz: 24V, 42V, 48V, 110/110-120V, 190/220V, 220-230/230-240V,

230-240/240-260V, 380-400/400-415V, 400-415/415-440V;

使用类别: AC-6b, 极数: 3P.

外置辅助触点 CAL5:

AC-15: Ue/Ie: 24~127V/6A, 220~240V/4A, 380~440V/3A, 500~690V/2A;

DC-13: Ue/Ie: 24V/6A, 48V/2.8A, 72V/1A, 110V/0.55A, 125V/0.55A, 220V/0.3A, 250V/0.3A;

注: 此附录与证书同时使用时有效。



主任:

中国质量认证中心

中国 · 北京 · 南四环西路 188 号 9 区 100070

<http://www.cqc.com.cn>

