

TECHNICAL DATA SHEET - INTERACTIVE PDF

Cable Tie, standard, 40 lbs. series

Colored Ties

Catamount[®]



Ratings:

- Tensile Strength: 40lb (178N)
- Min. Operating Temperature: -40°F (-40°C)
- Max. Operating Temperature: 185°F (85°C)
- Min. Installation Temperature: 4°F (-20°C)

Installation:

- Install with approved ABB cable tie tool such as ERG50 , QC-100, L-200, L-400-C

Cable ties are primarily used to cinch wires and cables together to form a neat and organized bundle.

Certifications / Standards:



3-Part Specification: End User Tools


Materials / Finishes:

- Natural Polyamide (Nylon 6.6)

Conforms to:

- AH-2 Plenum Rated
- UL94 V-2
- Type 21

Cable Tie, standard, 40 lbs. series
Colored ties

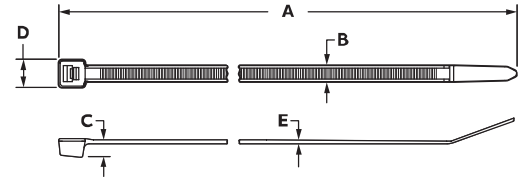

Product selection - in. (mm)

Part no: GID no:	Color	A ±0.25 (6.4)	B ±0.01 (0.25)	C ±0.03 (0.76)	D ±0.03 (0.76)	E ±0.01 (0.25)	Min. bundle diameter	Max. bundle diameter
L-5-30-2-C 7TAG054980R0634	Red	4.1 (104)	0.14 (3.6)	0.19 (4.8)	0.24 (6.1)	0.06 (1.5)	0.06 (1.6)	1.25 (31.7)
L-5-30-3-C 7TAG054180R0002	Orange							
L-5-30-4-C 7TAG054180R0003	Yellow							
L-5-30-5-C 7TAG054180R0005	Green							
L-5-30-6-C 7TAG054180R0007	Blue							
L-5-30-7-C 7TAG054060R0024	Purple							
L-5-30-8-C 7TAG054180R0009	Grey							
L-5-30FL-18-C	Fl. Green							
L-5-30FL-11-C	Fl. Pink							
L-5-30FL-17-C	Fl. Yellow							
L-5-30FL-16-C	Fl. Orange							
L-5-30FL-20-C	Fl. Blue							
L-8-40-2-C 7TAG054270R0032	Red	8.8 (223)						2.00 (50.8)
L-8-40-3-C 7TAG054270R0037	Orange							
L-8-40-4-C	Yellow							
L-8-40-5-C 7TAG054270R0042	Green							
L-8-40-6-C 7TAG054270R0046	Blue							
L-8-40-7-C	Purple							
L-8-40-8-C 7TAG054270R0053	Grey							
L-8-40FL-18-C 7TCG054270R0057	Fl. Green							
L-8-40FL-11-C 7TAG054270R0055	Fl. Pink							
L-8-40FL-17-C 7TAG054270R0056	Fl. Yellow							
L-8-40FL-16-C 7TCG054980R0652	Fl. Orange							
L-8-40FL-20-C 7TAG054270R0058	Fl. Blue							

Note: Product must be installed in accordance with applicable national and local electrical codes.

tnb.abb.com (US/Latin America)
tnb.ca.abb.com (Canada)
abb.com

We reserve the right to make technical changes or modify the contents of this document without prior notice. With regard to purchase orders, the agreed particulars shall prevail. ABB does not accept any responsibility whatsoever for potential errors or possible lack of information in this document.

We reserve all rights in this document and in the subject matter and illustrations contained therein. Any reproduction – in whole or in part – is forbidden without prior written consent of ABB.
© 2020 ABB Installation Products Inc. and/or its related companies. All Rights Reserved.