



产品认证证书

证书编号: CQC2019010303267993

申请人名称及地址

ABB France
2 Rue d' Arsonval 69680, Chassieu, FRANCE

制造商名称及地址

ABB France
2 Rue d' Arsonval 69680, Chassieu, FRANCE

生产企业名称及地址

ABB 新会低压开关有限公司 (V005372)
广东省江门市新会区今古洲工业开发区

产品名称和系列、规格、型号

接触器式继电器

NF;详见附件

产品标准和技术要求

GB/T14048.5-2017

认证模式

型式试验+获证后监督

上述产品符合 CQC11-462142-2019 认证规则的要求, 特发此证。

发证日期: 2020年08月14日 有效期至: 2024年12月31日

证书有效期内本证书的有效性依据发证机构的定期监督获得保持。

经中国合格评定国家认可委员会认可 CNAS C001-P

主任: 陆梅



中国质量认证中心

中国·北京·南四环西路188号9区100070

<http://www.cqc.com.cn>

C 0351943



PRODUCT CERTIFICATE

CERTIFICATE NO.: CQC2019010303267993

NAME AND ADDRESS OF THE APPLICANT

ABB France

2 Rue d'Arsonval 69680, Chassieu, FRANCE

NAME AND ADDRESS OF THE MANUFACTURER

ABB France

2 Rue d'Arsonval 69680, Chassieu, FRANCE

NAME AND ADDRESS OF THE FACTORY

ABB Xinhui Low Voltage Switchgear Co.,Ltd. (V005372)

Jinguzhou Industrial Development Zone, Xinhui District, Jiangmen City, Guangdong Province, P.R.China

PRODUCT NAME, MODEL AND SPECIFICATION

NF Relay

NF;See the appendix

THE STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS

GB/T14048.5-2017

TYPE OF CERTIFICATION SCHEMES

Type testing+Follow up factory inspection

This is to certify that the above mentioned product(s) complies with the requirements of certification rules of CQC11-462142-2019 .

Valid from: Aug.14,2020

Valid until: Dec.31,2024

The validity of the certificate is subject to positive result of the regular follow up inspection by issuing certification body until the expiry date.

Accredited by China National Accreditation Service for Conformity Assessment CNAS C001-P

President: _____

Lu Mei



CHINA QUALITY CERTIFICATION CENTRE

Section 9, No.188, Nanshuan Xilu, Beijing 100070 P.R.China

<http://www.cqc.com.cn>

C 0351943



产品认证证书

附录

第 1 页 共 2 页

证书编号: CQC2019010303267993

纸号: 351943

NF

Ui: 690V;

Uimp: 6kV;

Ith: 16A;

AC-15: Ue/le: 24-127V/6A, 220-240V/4A, 400-440V/3A, 500-690V/2A;

DC-13: Ue/le: 24V/6A, 48V/4A, 72V/1A, 110-125V/0.55A, 220-250V/0.27A, 400V/0.15A, 500V/0.13A, 600V/0.1A;

Us: 常规功耗: AC24-60V 50/60Hz/DC20-60V, AC48-130V 50/60Hz/DC48-130V,

AC100-250V 50/60Hz/DC100-250V, AC250-500V 50/60Hz/DC250-500V;

低功耗: AC24-60V 50/60Hz/DC20-60V, AC48-130V 50/60Hz/DC48-130V,

AC100-250V 50/60Hz/DC100-250V, DC12-20V;

外壳防护等级: IP20

注: 此附录与证书同时使用时有效。

主任: 陆梅



中国质量认证中心

中国·北京·南四环西路188号9区100070

<http://www.cqc.com.cn>



产品认证证书


附录

第 2 页 共 2 页

证书编号: CQC2019010303267993

纸号: 351943

型号解释:

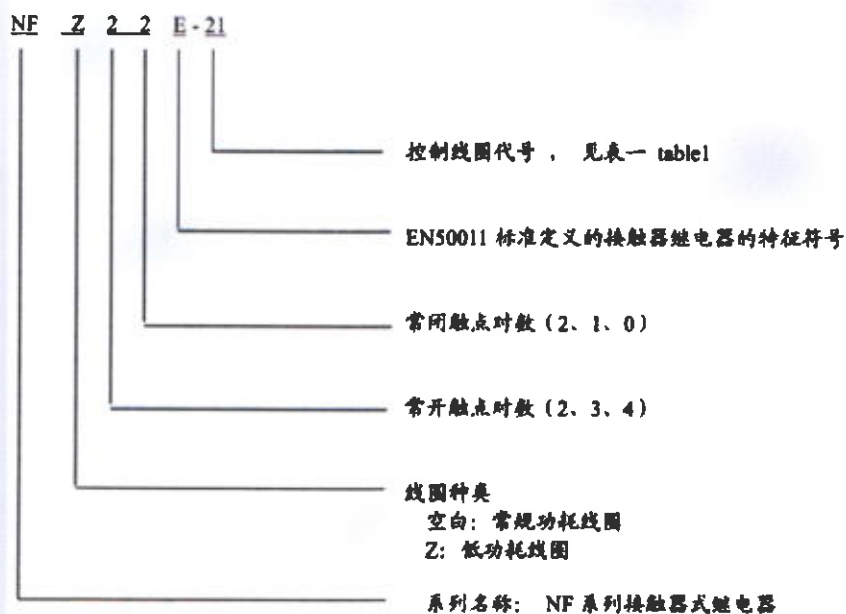

表一:

| 额定工作电压 Rated voltage (V) | | 线径 (mm) Wire dia. | 匝数 $\pm 1\%$ NO. turn | 线圈代号 Code | 线圈类型 |
|--------------------------|------------|----------------------|--------------------------|--------------|------|
| DC | AC 50/60Hz | | | | |
| 20-60 | 24-60 | 0.355 | 556 | 11 | NP |
| 48-130 | 48-130 | 0.224 | 1335 | 12 | NP |
| 100-250 | 100-250 | 0.140 | 2782 | 13 | NP |
| 250-500 | 250-500 | 0.100 | 12240 | 14 | NP |
| 12-20 | / | 0.475 | 580 | 20 | LP |
| 20-60 | 24-60 | 0.355 | 1020 | 21 | LP |
| 48-130 | 48-130 | 0.224 | 2448 | 22 | LP |
| 100-250 | 100-250 | 0.150 | 5100 | 23 | LP |

注: 此附录与证书同时使用时有效。

主任: 陆楠



中国质量认证中心

中国·北京·南四环西路 188 号 9 区 100070

<http://www.cqc.com.cn>