


CCSB Conduit Clips

Reducing closure clips for slit conduit

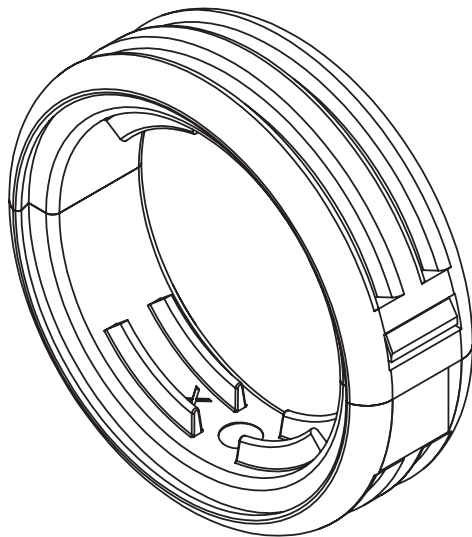

Circular conduit clips to provide a secure closing for slit conduits and reducing function for fitting entries allowing smaller conduits to be installed securely in larger openings. Certain options can be stacked to further reducer openings

Features & Benefits:

- Internal Ribs to aid conduit retention
- External grooves to allow stacking
- single piece clip for ease of install when used as security rings for slit conduit
- Prevent slit conduit opening
- Securely closes slit conduit
- Improves crush strength of slit conduits

Applications:

- Provide a means to close slit conduits
- Reducing conduit outlets to allow smaller conduits to be used
- can be stacked to enable further reduction in conduit size

Material:

- Polyamide 6 (Nylon)
 - UV Resistant
 - Heat Stabilised

Temperature range:

- Normal use -40 to +120°C (-40 to +248)°F

Ingress protection:



- N/A

Chemical resistance guide:

- Please refer to TDS000081

Suitable for use with:

- **Conduits**
 - All Harnessflex conduit systems
 - Also compatible with other conduit systems
- **Fittings**
 - TPS - T Piece conduit manifold
 - YPS - Y Piece conduit manifold
 - JPS - Straight conduit joiner
 - EPS - Conduit elbow
 - CI - Conduit to connector interfaces
 - Other harness fitting may also be compatible

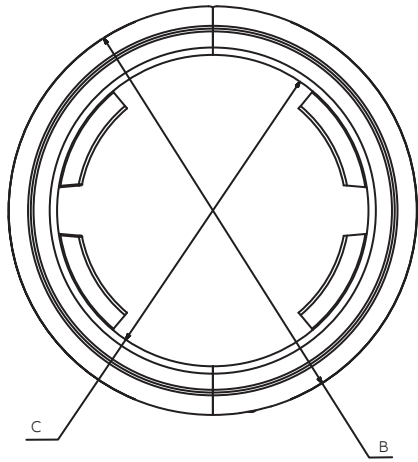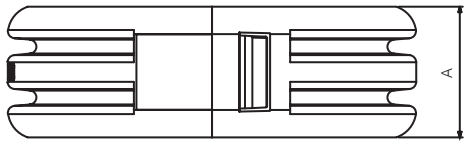

Product selection

Part no:	Dimensions			For conduit	Fits Outlet CCSB Reducer
	A	B	C		
CCSB08	8.1	16.0	10.5	NC08 / NW7.5	NC16 / NW13 CCSB16
CCSB10	9.5	19.4	12.1	NC10 / NW8.5	
CCSB12	9.5	20.8	13.6	NC12 / NW10	NC20 / NW17 CCSB20
CCSB16	9.3	20.9	16.8	NC16 / NW13	NC20 / NW17 CCSB20
CCSB20	9.0	27.8	21.7	NC20 / NW17	NC28 / NW23 CCSB28
CCSB25	10.2	34.2	26.4	NC25 / NW22	NC32 / NW29 CCSB32
CCSB28	10.2	36.0	29.0	NC28 / NW23	
CCSB32	11.5	42.2	35.1	NC32 / NW29	NC40 / NW36 CCSB40
CCSB40	11.5	53.8	43.1	NC40 / NW36	NC50 / NW48 CCSB50
CCSB50	11.5	62.3	55.4	NC50 / NW48	

Colour: Black as standard