
TECHNICAL DATA SHEET

Terminals, pin

Un-insulated

Spec-Kon[®]



Un-insulated pin terminals for wire termination of copper conductors ranging from 0.5mm² to 6mm²

Certifications / Standards:



Features:

- Corrosive resistant plating
- Brazed seam crimp

Maximum rating:

- Copper conductors only

Application tool:

- ERG9001

Conforms to:

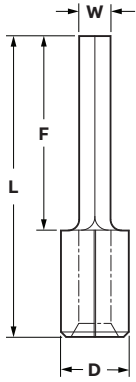
- IEC 60352-2

Materials / Finishes:

- Copper terminal
- Electro-Tin plated

Terminals, pin:
Un-insulated

Product selection

Drawing	Part no:	Wire size range (mm ²)	Dimensions (mm)				Crimping tool
			L	F	W	D	
	P1.5-14	0.5-1.5	13.8	9.0	1.9	3.4	ERG9001
	P1.5-15	0.5-1.5	14.8	10.0	1.9	3.4	
	P1.5-17	0.5-1.5	16.8	12.0	1.9	3.4	
	P1.5-18	0.5-1.5	17.8	13.0	1.9	3.4	
	P2.5-14	1.5-2.5	13.8	9.0	1.9	4.0	
	P2.5-15	1.5-2.5	14.8	10.0	1.9	4.0	
	P2.5-17	1.5-2.5	16.8	12.0	1.9	4.0	
	P2.5-18	1.5-2.5	17.8	13.0	1.9	4.0	
	P2.5-19	1.5-2.5	18.8	14.0	1.9	4.0	
	P2.5-20	1.5-2.5	19.8	15.0	1.9	4.0	
	P2.5-21	1.5-2.5	21.0	16.0	1.9	4.0	
	P6-17	4.0-6.0	16.0	10.0	2.8	5.5	
	P6-19	4.0-6.0	19.0	13.0	2.8	5.5	
	P6-18	4.0-6.0	20.0	14.0	2.8	5.5	

Note: Products must be installed in accordance with applicable national and local electrical codes.