

TECHNICAL DATA SHEET

Earth Tags (ET Series)

Earth tags for cable glands and conduit fittings



Provides a termination point for earth connectivity with metallic cable glands and conduit fittings

Features & Benefits:

- Simple to install
- Low space consideration

Applications:

- Creating earth connectivity point with threaded metallic fittings
- Suitable for use with all threaded fittings
- Can be used inside or outside of an enclosure

Material:

- Nickel plated brass

Temperature range:


- Normal use -45 to +150°C (-50 to +300)°F

Compatible with:

- Metallic cable glands
- Metallic conduit fittings
- Rigid conduit fittings

Chemical resistance guide:

- Please refer to TDS000081

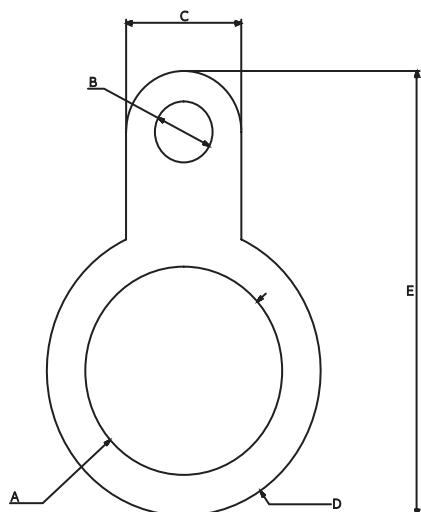

Product selection		Dimensions, mm (Inches)				
Part no:	Thread Size	A	B	C	D	E
ET-M16	M16x1.5	16.25 (0.640)	6.50 (0.256)	13.00 (0.512)	25.00 (0.984)	45.00 (1.772)
ET-M20	M20x1.5	20.25 (0.797)	6.50 (0.256)	13.00 (0.512)	29.00 (1.142)	48.00 (1.890)
ET-M25	M25x1.5	25.50 (1.004)	6.50 (0.256)	13.00 (0.512)	37.00 (1.457)	57.50 (2.264)
ET-M32	M32x1.5	33.50 (1.319)	6.50 (0.256)	15.80 (0.622)	44.00 (1.732)	69.30 (2.728)
ET-M40	M40x1.5	40.25 (0.64)	6.50 (0.256)	16.20 (0.512)	52.50 (0.984)	78.00 (1.772)
ET-M50	M50x1.5	50.25 (1.978)	6.50 (0.256)	16.00 (0.63)	64.00 (2.52)	90.50 (3.563)
ET-M63	M63x1.5	63.30 (2.492)	6.50 (0.256)	23.00 (0.906)	79.50 (3.13)	117.00 (4.606)
ET-M75	M75x1.5	75.20 (2.961)	6.50 (0.256)	24.00 (0.945)	96.25 (3.789)	133.50 (5.256)
ET-038	3/8"	18.50 (0.728)	6.50 (0.256)	13.00 (0.512)	25.00 (0.984)	45.00 (1.772)
ET-050	1/2"	22.30 (0.878)	6.50 (0.256)	13.00 (0.512)	29.00 (1.142)	48.00 (1.890)
ET-075	3/4"	27.00 (1.063)	6.50 (0.256)	13.00 (0.512)	37.00 (1.457)	57.50 (2.264)
ET-100	1"	33.60 (1.323)	6.50 (0.256)	15.80 (0.622)	44.00 (1.732)	69.30 (2.728)
ET-125	1-1/4"	42.50 (1.673)	6.50 (0.256)	16.20 (0.638)	52.50 (2.067)	78.00 (3.071)
ET-150	1-1/2"	50.25 (1.978)	6.50 (0.256)	16.00 (0.630)	64.00 (2.520)	90.50 (3.563)
ET-200	2"	63.30 (2.492)	6.50 (0.256)	23.00 (0.906)	79.50 (3.130)	117.00 (4.606)
ET-250	2-1/2"	75.20 (2.961)	6.50 (0.256)	24.00 (0.945)	96.25 (3.789)	133.50 (5.256)

ABB Cable Management Products Ltd
Station Road
Coleshill
Birmingham
B46 1HT

Technical Support: cmg.conduitsystems@abb.com

abb.com

We reserve the right to make technical changes or modify the contents of this document without prior notice. With regard to purchase orders, the agreed particulars shall prevail. ABB does not accept any responsibility whatsoever for potential errors or possible lack of information in this document.

We reserve all rights in this document and in the subject matter and illustrations contained therein. Any reproduction, disclosure to third parties or utilisation of its contents – in whole or in parts – is forbidden without prior written consent of ABB. Copyright© 2018 ABB
All rights reserved