

FES7000-ES7 / FSM1000-SM1

External transmitter

For electromagnetic
flowmeters

FSM1000-DS21,
FSM1000-DS41F,
FSM1000-DS44F




Contents

- 1 Name plate specifications for spare parts orders 3

- 2 Overview 4
 - 2.1 Housing 5
 - 2.2 Slide-in converter 6
 - 2.3 Additional boards (not shown) 6
 - 2.4 Connection board 7
 - 2.5 Accessories 7

1 Name plate specifications for spare parts orders


The transmitter version can be identified by referring to the name plate that is attached to the housing. When placing spare parts orders, always remember to state the order number as shown on the name plate.

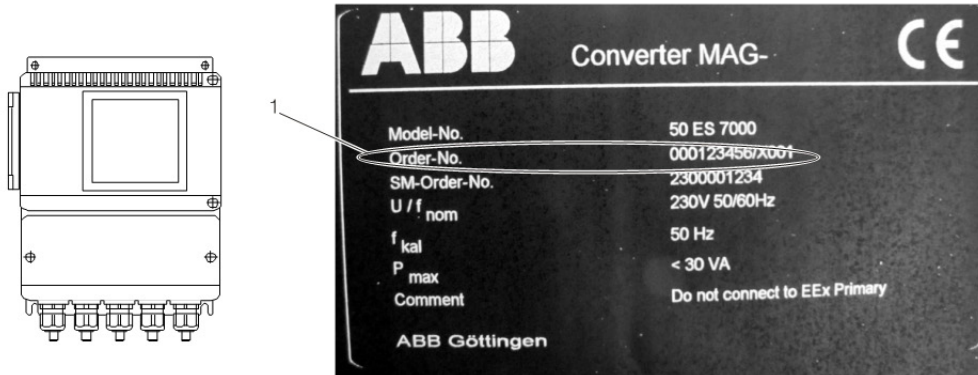

G11549

Fig. 1
1 Order number

2 Overview

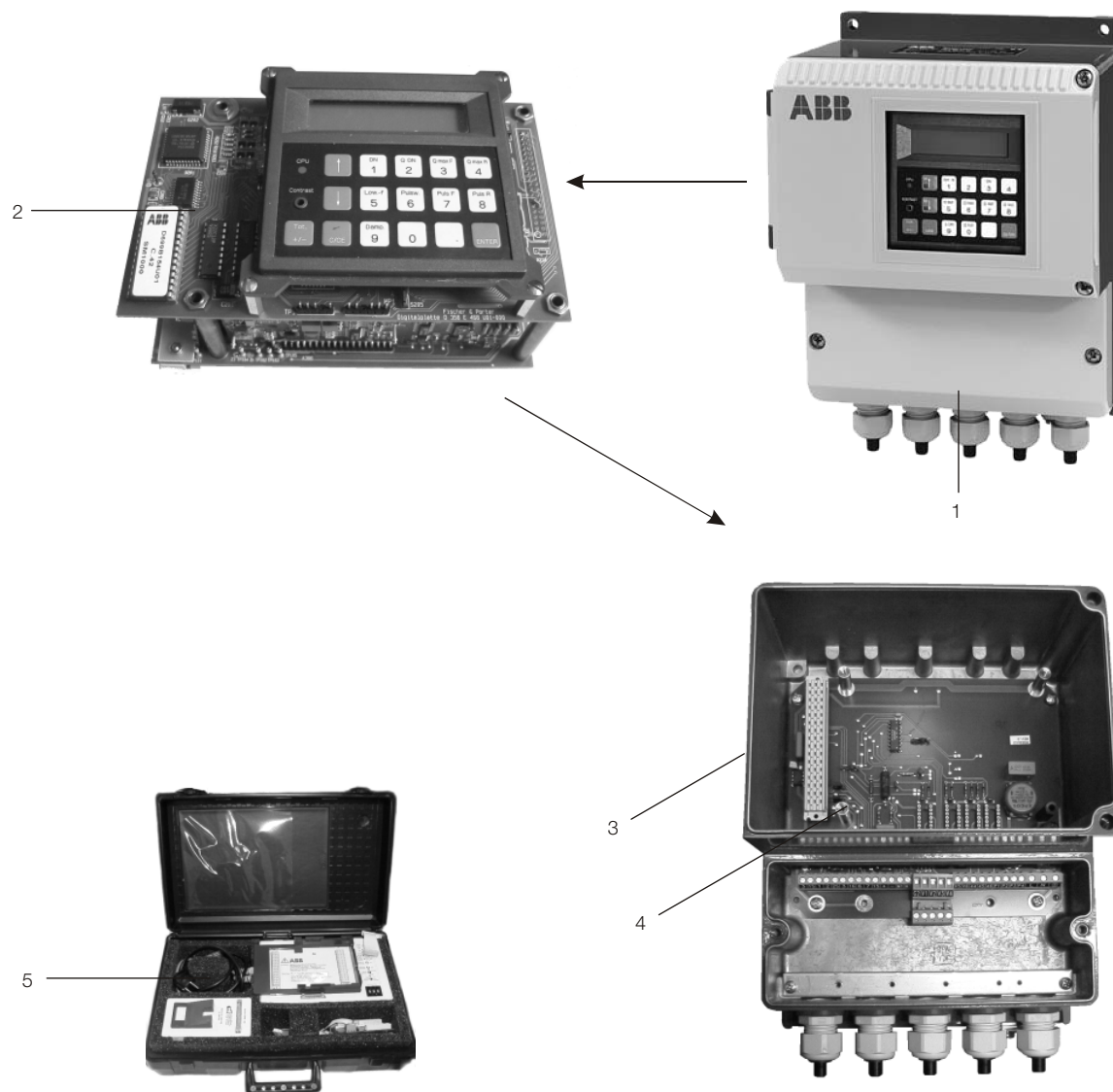

G10200

Fig. 2: Overview


1 Housing complete (new) | 2 Slide-in converter | 3 Lower connection box (neu) | 4 Connection board |
5 55XC4000 Simulator (see separate spare parts list for 55XC4000)



IMPORTANT (NOTE)

All prices on inquiry!

2.1 Housing

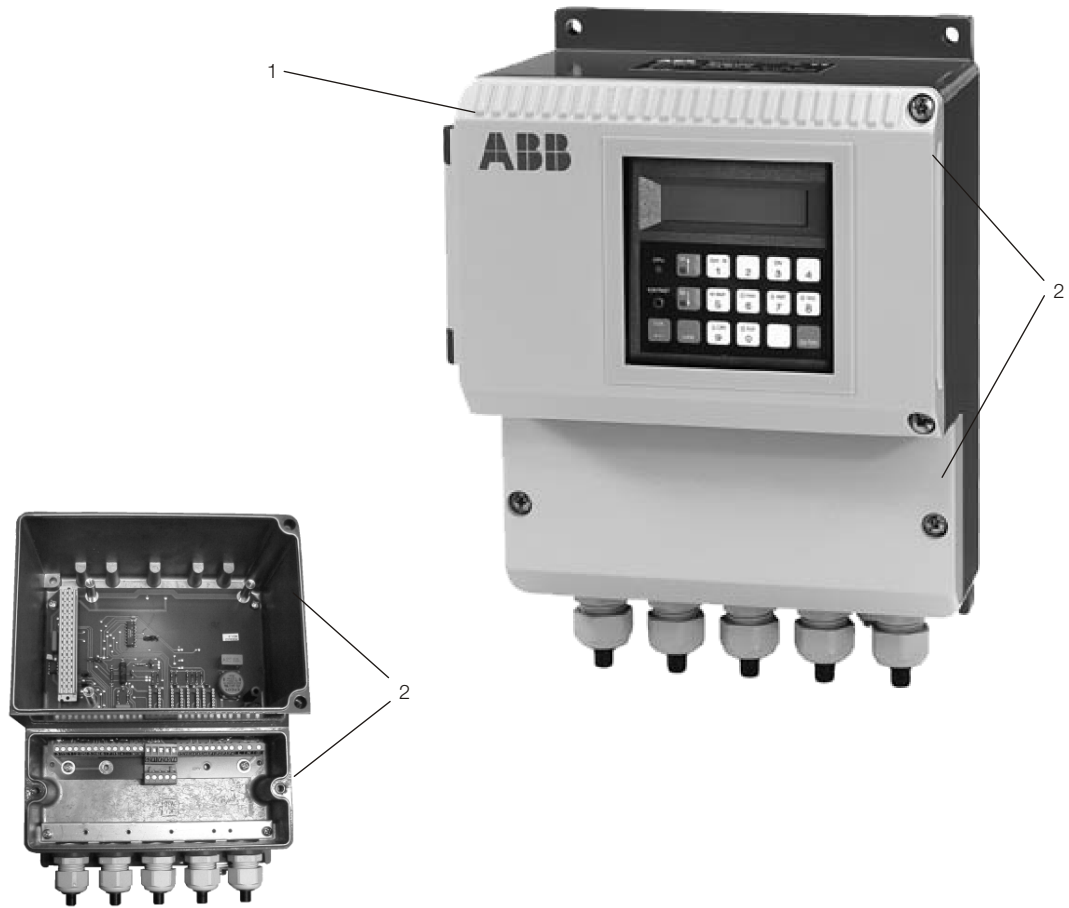


G10201

Fig. 3

Position	Name of part	Variant	Order number	Weight kg (lb)	Price (€)
1	Field-mount housing complete (new)	-	D641A033U01	3.8	
2	Cover set (new) includes: Cover large / small Gasket large / small	-	D614L999U05	-	

2.2 Slide-in converter

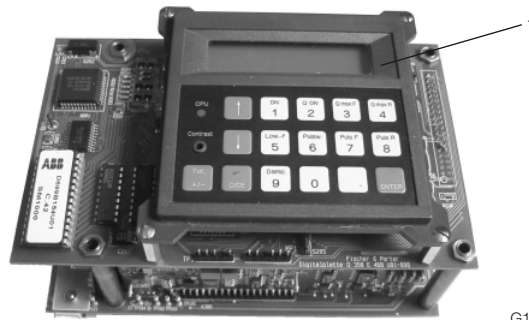

G10202


Fig. 4

Position	Name of part	Variant	Order number	Weight kg (lb)	Price (€)
1	Slide-in converter ES7 field-mount housing 230 V AC 50 Hz	-	D674A340U10	-	
	Slide-in converter ES7 RS485, field-mount housing 230 V AC 50 Hz	-	D674A340U14	-	
	Slide-in converter ES7 19" 230 V AC 50 Hz	-	D674A348U10	-	
	Slide-in converter ES7 RS485, 19" 230 V AC 50 Hz	-	D674A348U14	-	
	Slide-in converter SM1 field-mount housing 230 V AC 50 Hz	-	EXCD674A322U10	-	

2.3 Additional boards (not shown)

Position	Name of part	Variant	Order number	Weight kg (lb)	Price (€)
-	Current output module SM1 + ES7	-	D685A473U04	-	
	Current output module HART SM1 + ES7	-	D685A473U05	-	
	Keyboard with display ES7 field-mount housing	-	D674A238U04	-	
	Keyboard with display ES7 19"	-	D674A238U03	-	
	Keyboard with display SM1 field-mount housing	-	D674A238U16	-	

2.4 Connection board

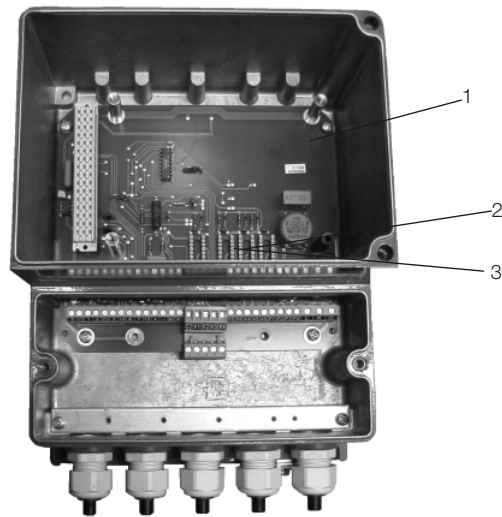

G10205

Fig. 5

Position	Name of part	Variant	Order number	Weight kg (lb)	Price (€)
1	Connection board field-mount housing	-	D685A583U02	0.5	
2	Relay	-	D163B013U01	0.02	
3	Optocoupler	-	D177B009U17	0.001	

2.5 Accessories

Position	Name of part	Variant	Order number	Weight kg (lb)	Price (€)
-	Keypad ES7	-	D698B014U15	-	
-	Keypad SM1	-	D698B014U09	0.02	
-	Fuse 0.160 A	-	D151B025U02	0.001	
-	Display SM1 + ES7	-	D177A003U17S	-	
-	RS422 / RS485 module		D685A299U01	-	

Contact us

To find your local ABB branch, go to:
www.abb.com/contacts

Additional product information is
available at:
www.abb.com

ABB Automation GmbH

Service Instrumentation
Dransfelder Str. 2
37079 Göttingen
Germany

Note

We reserve the right to make technical changes and changes affecting content to this document at any time without prior notice.

Orders are subject to the agreed detailed terms and conditions. ABB cannot be held responsible for any errors or omissions in this document.

We reserve all rights to this document and its content, including images. This document must not be copied, shared with third parties, or its content (in whole or in part) used without the prior written permission of ABB.

Copyright© 2013 ABB
All rights reserved

3KXF200001R4701

SPL/FEST000-ES7/FSM1000-SM1-EN Rev. B 09.2013