

---

TECHNICAL DATA SHEET

# Terminals, male disconnect

## Un-insulated

### Spec-Kon<sup>®</sup>



Un-insulated male disconnects for wire termination of copper conductors ranging from 0.5mm<sup>2</sup> to 6mm<sup>2</sup>

**Certifications / Standards:**



---

**Features:**

- Corrosive resistant plating
- Seamless Metal Sleeve to hold crimp barrel together
- Funnel entry sleeve

---

**Maximum rating:**

- Copper conductors only

---

**Application tool:**

- ERG9001
- DIE9001 with ERG9000EX

---

**Conforms to:**

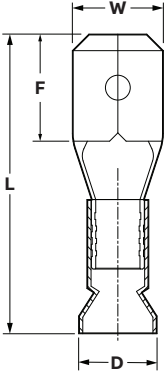
- IEC 60352-2

---

**Materials / Finishes:**

- Copper terminal
- Electro-Tin plated

**Terminals, male disconnect:  
Un-insulated**

Product selection							
Drawing	Part no:	Wire size range (mm <sup>2</sup> )	Dimensions (mm)				Crimping tool
			L	F	W	D	
	MD1.5-285	0.5-1.5	16.7	6.5	2.8	3.3	ERG9001
	MD1.5-288	0.5-1.5	16.7	6.5	2.8	3.3	
	MD1.5-485	0.5-1.5	17.3	6.7	4.8	3.3	
	MD1.5-488	0.5-1.5	17.3	6.7	4.8	3.3	
	MD1.5-638	0.5-1.5	19.0	7.6	6.4	3.3	
	MD2.5-285	1.5-2.5	16.7	6.5	2.8	4.0	
	MD2.5-288	1.5-2.5	16.7	6.5	2.8	4.0	
	MD2.5-485	1.5-2.5	17.3	7.6	4.8	4.0	
	MD2.5-488	1.5-2.5	17.3	7.6	4.8	4.0	
	MD2.5-638	1.5-2.5	19.0	7.6	6.4	4.0	
	MD6-638	4.0-6.0	21.0	7.6	6.4	5.5	

Note: Products must be installed in accordance with applicable national and local electrical codes.