



by ABB



1M000000


Catalog Number **Type QL-WP**
9T17A0012

22.5 KVA **60 HZ** **3 PH** **3.7 % IMP**
40 C AMB. **150 C RISE** **220 C SYSTEM** **IS-19C**


JUMPER CONNECTION

TAP	VOLTS
1	504
2	492
3	480
4	468
5	456
6	444
7	432

PRIMARY (H) 480 VOLTS (LINE-LINE)
SECONDARY (X) 208 VOLTS (LINE-LINE)
 120 VOLTS (LINE-NEUTRAL)

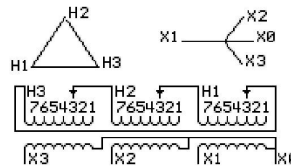

 NET WGT **INSPECTION & FINAL TEST**
 330 LB
 149.7 Kg
 90482 **NOG**
 UX72A **N320!**
 051723



ENCLOSURE TYPE 2 (IP20). OR RAINPROOF TYPE 3R (IP22) WHEN PROVIDED SHIELD

ASSEMBLED IN MEXICO

BEFORE HANDLING, INSTALLING AND OPERATING, SEE INSTRUCTION 475A667AAP001
 ALUMINUM CONDUCTOR PRIMARY: 10 KV BIL SECONDARY: 10 KV BIL
 IN ACCORDANCE WITH NEC SECTION 450-9, ALLOW AT LEAST SIX INCHES CLEARANCE FOR VENTILATION.
 CHECK ADDITIONAL NEC AND LOCAL CODE

X3	H3	X2	H2	X1	H1	X0
-	-	-	-	-	-	-

Note: standard

Outline: 303B424AAP022

NEMA CLASS AA DRY TYPE TRANSFORMER

Meets DOE 2016 efficiency

X3 H3 X2 H2 X1 H1 X0



2M000000

X3 H3 X2 H2 X1 H1 X0



3M000000