



Cable - C8

Machine Safety - Jokab Safety products

ID 2TLC172004L0201, Date July 2013

C8 cable 8 x 0.34 shielded

Technical data - C8

Article number	2TLA020057R1000
EAN	7350024452549
Specification	22AWG*8C+F+D+AL
Conductor	
Specification	22 AWG
Material	Tinned stranded copper
Configuration	TS17/0.16 ± 0.005 mm
Insulation	
Avg. Thick	0.26 mm
Min. Thick	0.22 mm
Diameter	1.30 ± 0.10 mm
Material	Environmental protection PVC (RoHS)
Colour	White, Brown, Green, Yellow, Gray, Pink, Blue, Red
Assembly	
Filler	1 OS/12SOL*1 PCS Cotton construction
Drain wire	TS7/0.16 ± 0.005 mm
Aluminum	15*0.025 mm
Jacket	
Avg. Thick	1.00 mm
Min. Thick	0.80 mm
Diameter	6.50 ± 0.15 mm
Material	Environmental protection PVC60P (RoHS)
Colour	Black (fog matte)
Electrical capability	
Rated temperature	80 °C
Rated voltage	300 V
Cond. Resistance	60.25 Ω /KM 20 °C
Insu. Resistance	2.5 MΩ/KM 20 °C
Bending radius	
	Static: 7 x cable diameter
	Dynamic: 12 x cable diameter
Marking	
	ABB  AWM 2464 22AWG VW-1 80 °C 300V E343967 FINECABLES
	 AWM 2464 22AWG I/II A FT1 80 °C 300V +LF+

Cross section

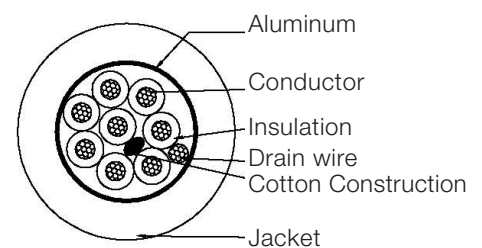


ABB AB
 Low Voltage Products
 Safety products
<http://www.abb.com/jokabsafety>