


Guideway

Innovative & stylish



Guideway 22m & 32m - Recessed in black

- Bright and uniformed light distribution with 500 cd/sq.m
- Versatile mounting options with First-Fix control gear
- Unique frameless legend design with click-lock assembly
- Quick release legend panels

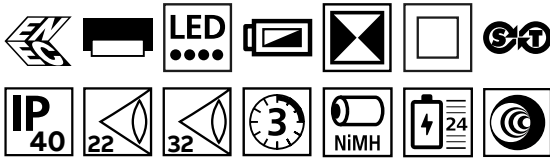

Luminaire

Order code	Description	Input voltage	Lamp type	Power consumption (VA/W)	Operation / duration (hrs)	Environment temp. (°C)	Weight (kg)
CTEGR3LS1-S22B	REC LED SIGN M3 CT-NAVEO 22M BLK	220-240 AC 50Hz	1 x LED 2W	4.4 / 4	3	5-35	1.2
CTEGR3LS1-S32B	REC LED SIGN M3 CT-NAVEO 32M BLK	220-240 AC 50Hz	1 x LED 4W	7.1 / 6.5	3	5-35	1.5
EGR3LS1-S22B	REC LED SELF-TEST SIGN M3 22M BLK	220-240 AC 50Hz	1 x LED 2W	4.4 / 4	3	5-35	1.2
EGR3LS1-S32B	REC LED SELF-TEST SIGN M3 32M BLK	220-240 AC 50Hz	1 x LED 4W	7.1 / 6.5	3	5-35	1.5
EGR1LS1LTC-S22B	REC LED SIGN 230VAC EMEX 22M BLK	220-240 AC 50/60Hz	1 x LED 2W	4.4 / 4	230V	0-35	1.2
EGR1LS1LTC-S32B	REC LED SIGN 230VAC EMEX 32M BLK	220-240 AC 50/60Hz	1 x LED 4W	7.1 / 6.5	230V	0-35	1.5
EGR1LS1D-S22B	REC LED SIGN SL 230DIM 22M BLK	220-240 AC/DC 0-60Hz	1 x LED 2W	4.4 / 4	230V	0-35	1.2
EGR1LS1D-S32B	REC LED SIGN SL 230DIM 32M BLK	220-240 AC/DC 0-60Hz	1 x LED 4W	7.1 / 6.5	230V	0-35	1.5
EGR1LS1-S22B	REC LED SIGN SL 230VAC 22M BLK	220-240 AC/DC 0-60Hz	1 x LED 2W	4.4 / 4	230V	0-35	1.2
EGR1LS1-S32B	REC LED SIGN SL 230VAC 32M BLK	220-240 AC/DC 0-60Hz	1 x LED 4W	7.1 / 6.5	230V	0-35	1.5

60 hrs charge at first commissioning, 24 hrs re-charge thereafter
Includes back to the wall mounting accessory as standard
Add '-00' for product without legends



Single sided

Part No.	Legends
ISO 7010 legend format	
XEN2EG22 or XEN2EG32	
XEN3EG22 or XEN3EG32	
XEN6EG22 or XEN6EG32	
XEN5EG22 or XEN5EG32	
XEN0G22 or XEN0G32	
Arabic legend format	
XBN1EG22	


ISO 7010 pictogram legends are shown
Euro format & Special legends are available
to order see pages 139-141

Flag mounted

Part No.	Legends
ISO 7010 legend format	
XEN602EG22 or XEN602EG22	
XEN603EG22 or XEN603EG32	
XEN606EG22 or XEN606EG32	
XEN605EG22 or XEN605EG32	

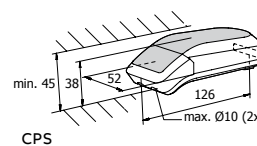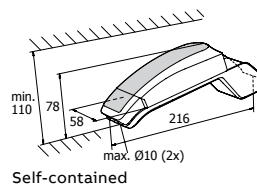

22m

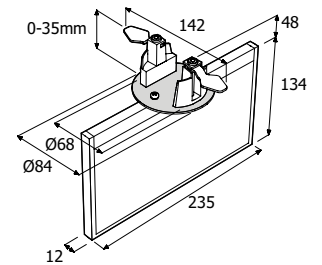

32m

