


On-load tap-changer type UBBL, 13 tap positions, linear switching.
 Max effective No. of turns in pos 1.
 The tap-changer is delivered set in pos 7.

Lindningskopplare typ UBBL, 13 lägen, linjär-koppling.
 Max antal effektiva varv i läge 1.
 Lindningskopplaren levereras inställd i läge 7.

Pos Läge	H connects förbinder
1	2 - 15
2	3 - 15
3	4 - 15
4	5 - 15
5	6 - 15
6	7 - 15
7	8 - 15
8	9 - 15
9	10 - 15
10	11 - 15
11	12 - 15
12	13 - 15
13	14 - 15

We reserve all rights in this document and in the information contained therein. Reproduction, use or disclosure to third parties without express authority is strictly forbidden. © ABB 19

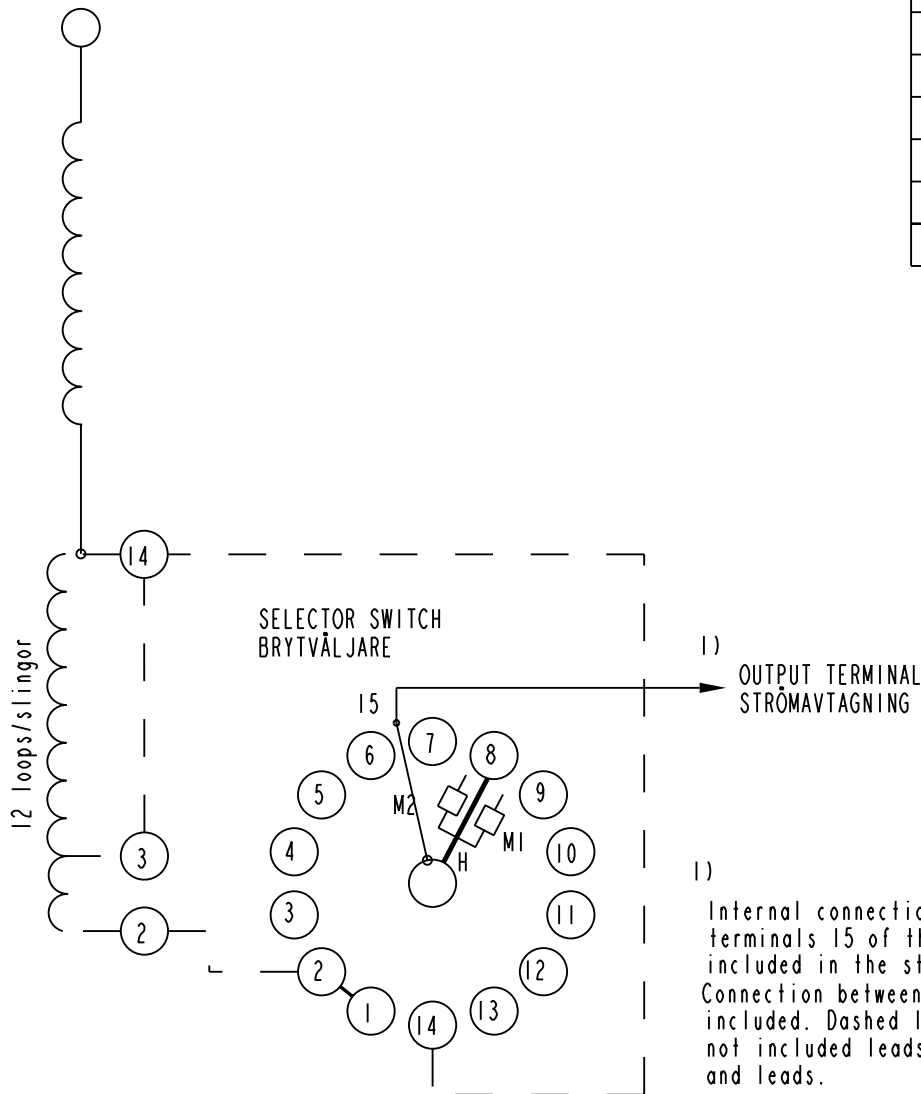

1) OUTPUT TERMINAL
STRÖMAVTAGNING

1) Internal connections between the terminals 15 of the three phases are included in the star-point type. Connection between 1 and 2 is included. Dashed lines show in delivery not included leads belonging to cleats and leads.

H Main contact
Huvudkontakt
M1, M2 Transition contacts
Motståndskontakter

Inre förbindningar mellan uttag 15 i de tre faserna ingår i nollpunktsutförande. Förbindningar mellan 1 och 2 ingår. Streckade linjer visar i leveransen ej ingående ledare tillhörande anslutningsdonet.

Sheet	Cont	Year	Week	Appd	Year	Week
Rev Ind	Revision	Accepted by	Accepted for prod by	Appd	Year	Week
Rev Ind	Revision	Accepted by	Accepted for prod by	Appd	Year	Week
Design checked by	Design checked by	Drawn by	Issued by	Dept	Year	Week
M.Hedlund	B-O.Stenestam	L.Bergman	COM/TKO		97	32
Asea Brown Boveri				5492 0387-9		
				Description (English)		DATAORIGINAL
				Description (own language)		File name
				KOPPLINGSSCHEMA UBBL		0387-9
				Lang	Sheet	
				Rev Ind	Cont	