


On-load tap-changer type (V)UCGR./F, (V)UCLR./F, UCCR./F,
 9 tap positions, plus/minus switching.
 Max. effective No. of turns in pos. 1.
 The tap-changer is delivered set in pos. 5,
 the preceding pos. was 4.

Lindningskopplare typ (V)UCGR./F, (V)UCLR./F, UCCR./F,
 9 lägen, plus/minus koppling.
 Max antal effektiva varv i läge 1.
 Lindningskopplaren levereras inställd i läge 5,
 föregående läge var 4.

Pos. Läge	R connects in direction R förbinder i riktning		Tap selector and diverter switch connect	Väljaren och lastkopplaren förbinder
1		▲	1-H-v	
2	↓	▲	2-V-x	
3	20-21	20-21	3-H-v	
4	↓		4-V-x	
5	▼	▲	5-H-v	
6		▲	6-V-x	
7	↓		7-H-v	
8	20-22	20-22	8-V-x	
9	▼		9-H-v	

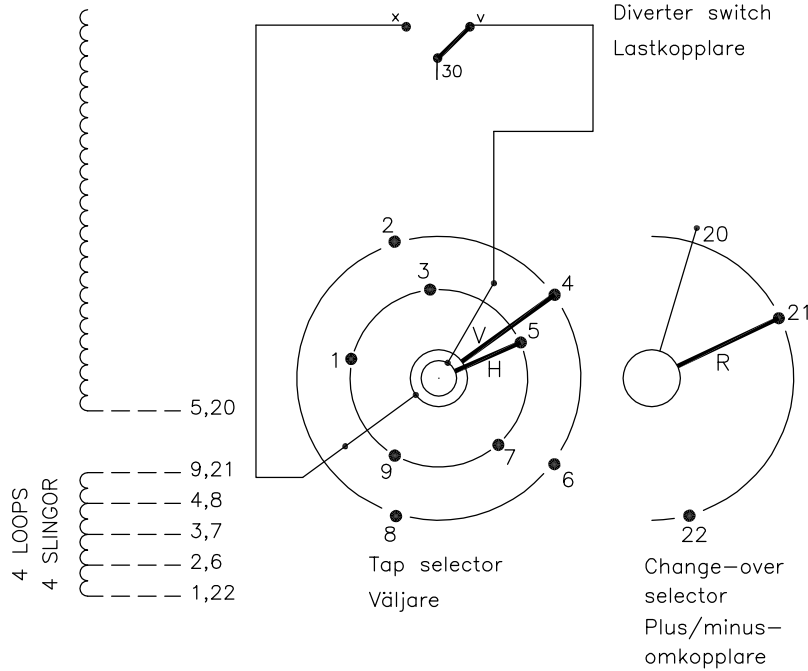

The tap-changer is shown in pos. 5,
 the preceding pos. was 4.
 The tap selector and the change-over selector
 are seen from above.
 Contact arm V is located above contact arm H.

Lindningskopplaren visad i läge 5,
 föregående läge var 4.
 Väljaren och plus/minus-omkopplaren sedda uppifrån.
 Kontaktarm V ligger över kontaktarm H.

Continuous lines show leads included in the
 tap-changer. Dashed lines show leads belonging
 to the cleats and leads.

Heldragna linjer visar ledare som ingår i
 lindningskopplaren. Streckade linjer visar
 ledare som tillhör anslutningsdonet.

We reserve all rights in this document and in the
 information contained therein. Reproduction, use or
 disclosure to third parties without express authority
 is strictly forbidden. © ABB '19

Sheet	Cont	Year	Week	Dept	Rev Ind	Revision	Appd	Year	Week	Description (English)	DATAORIGINAL
Form No.	Design checked by	Year	Week	Rev Ind	Accepted by qual control	Accepted for prod by				Description (own language)	File name
	H.Sundberg	14	02	L.Oberg	M.Haggmar					KOPPLINGSSHEMA	Lang
	N.Gustavsson	CO/TK	14	02							Sheet
											1
											Rev Ind
											Cont
											-
										1ZSC004309-AAA	