

## Pedestals

### EH1 - Small pedestal



EH1C14VH

#### Applications

- Cable television
- Gas distribution
- Telecommunication (surface connections)
- Camping sides



#### Standard: EN / IEC 62208

#### Specifications

- Small outdoor enclosure with integrated base.
- Hood grey colour RAL 7035:
  - ventilated version in polyester or thermoplastic engineering polymer,
  - non ventilated version in hot moulded, glass fibre reinforced polyester,
  - blackened triangular zamac locking screws, vandalproof and for all seasons.
- - Degrees of protection:
  - IP43 for the non ventilated hoods,
  - IP23 for the ventilated hoods.
- According to IEC 60529:
  - protection degree against external mechanical impacts according to EN/IEC 62262.
- IK09 polyester hood
- IK10 thermoplastic hood
- Rated insulation voltage  $U_i$  690V
- Base in high density polyethylene (HDPE) RAL 9005
- Base resists a ground temperature of  $-50^{\circ}\text{C}$
- The upper part of the base serves as a mounting plate and is provided with three slots for fixation points.
- Moulded-in indication of burial depth.
- Option: 2432E lock.
- Easy to install by one person only (weight: 4.5 kg).
- Dimensions: 753×385×270 (H×W×D in mm)


#### EH1 - Column cabinet

| Type                                                         | Type       | Order code      | Pack |
|--------------------------------------------------------------|------------|-----------------|------|
| (H x W x D) 753 x 385 x 270 mm                               |            |                 |      |
| Ventilated                                                   | EH1C14VHNA | 4TBE841037C0100 | 1    |
| Non-ventilated                                               | EH1C14NH   | 4TBE841038C0100 | 1    |
| <b>Accessories</b>                                           |            |                 |      |
| The protective hood may be opened by an 8 mm triangular key. | PS832027   | 4TBP832027C0100 | 1    |
| Ventilated protective hood                                   | EH1AEEV3   | 4TBE841039N0100 | 1    |
| Non-ventilated protective hood                               | EH1AEEEN4  | 4TBE841040N0100 | 1    |
| Closure for older models                                     | EH1AEEEI   | 4TBE841041N0100 | 1    |

 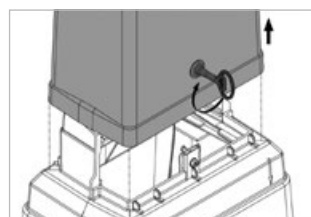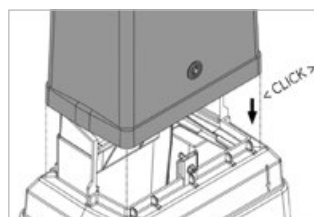


## Pedestals

### EH2 - Column cabinets

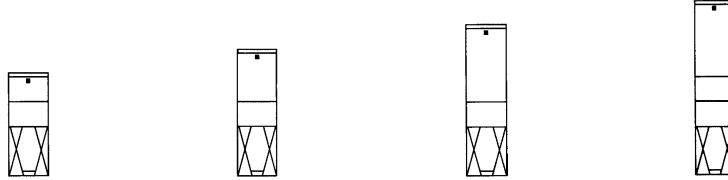


|                            | Type       | EH2-NA          | EH2-NB          | EH2-NC          | EH2-ND          |
|----------------------------|------------|-----------------|-----------------|-----------------|-----------------|
|                            | H x W x D  | 1097x433x240    | 1347x433x240    | 1622x433x240    | 1896x433x240    |
| Standard                   | Type       | EH2C25CH        | EH2C35CH        | EH2C45CH        | EH2C55CH        |
|                            | Order code | 4TBE842072C0100 | 4TBE842073C0100 | 4TBE842074C0100 | 4TBE842075N0100 |
| With UV coating            | Type       | EH2U25CH        | EH2U35CH        | EH2U45CH        | EH2U55CH        |
|                            | Order code | 4TBE842082N0100 | 4TBE842083N0100 | 4TBE842084N0100 | 4TBE842085N0100 |
| Mounting plate             | H x W x D  | 200x395x5       | 450x395x5       | 700x395x5       | 700x395x5       |
|                            | Type       | EH2M25EH        | EH2M35EH        | EH2M45EH        | EH2M45EH        |
|                            |            | Order code      | 4TBE842002C0100 | 4TBE842000C0100 | 4TBE842001C0100 |
| Pertinax with fixing bolts | Type       | EH2M25EH        | EH2M35EH        | EH2M45EH        | EH2M45EH        |
|                            | Order code | 4TBE842002C0100 | 4TBE842000C0100 | 4TBE842001C0100 | 4TBE842001C0100 |



### EH2 - Accessories

| Product                                   | Type                       | Order code      | Pack            |
|-------------------------------------------|----------------------------|-----------------|-----------------|
| <b>Locks - profile half cylinder type</b> |                            |                 |                 |
|                                           | With 2 keys , V2432-E      |                 |                 |
|                                           | EH3AEECI                   | 4TBE843001C0100 | 1               |
|                                           | spare keys for EH3AEECI    | PS832022        | 4TBP832022C0100 |
|                                           | With 1 square key, 8mm     |                 |                 |
|                                           | EH3AEEQHN                  | 4TBE843002C0100 | 1               |
|                                           | With an 8mm triangular key |                 |                 |
|                                           | EH3AEETHN                  | 4TBE843003C0100 | 1               |
|                                           | With 2 keys A434           |                 |                 |
|                                           | EH3UAECI                   | 4TBE843248C0100 | 1               |
| Replacement keys upon request.            |                            |                 |                 |

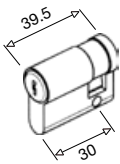

| Product                                                                                                                                                                                                                                                                                                                                                                                     | Type     | Order code      | Pack |
|---------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|----------|-----------------|------|
| <b>Vandal proof nameplate holder</b>                                                                                                                                                                                                                                                                                                                                                        |          |                 |      |
| Can be placed on every flat surface, by drilling two holes $\varnothing$ 5.5 mm; the identification window is used as a drill template. Steady against vandalism; it keeps its total isolation. Possibility to write on manually and/or to use the standard letteringsystems; the maximal letterheight is 18 mm. Usefull dimensions of letters: 18 x 143. Outside dimensions: 30 x 183 x 5. |          |                 |      |
|                                                                                                                                                                                                                                                                                                                                                                                             | EH3AEEE4 | 4TBE843304C0100 | 1    |


### Inserts

|                                        |                                                            |                 |     |
|----------------------------------------|------------------------------------------------------------|-----------------|-----|
|                                        | M6 x 11 threaded inserts                                   |                 |     |
|                                        | VJ890846                                                   | 4TBO890846C0100 | 100 |
| Punch for inserting M6 threaded barrel |                                                            |                 |     |
|                                        | Support for cable release clamp (to be ordered separately) |                 |     |
|                                        | APPL                                                       | 4TBO852004C0100 | 1   |

 
## Pedestals

### EH3 - Accessories


#### DIN bases
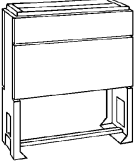
|                                                                                   |                                                                                 | DIN 00                            | DIN 0           | DIN 1           | DIN 2           | DIN 3           |
|-----------------------------------------------------------------------------------|---------------------------------------------------------------------------------|-----------------------------------|-----------------|-----------------|-----------------|-----------------|
|  | HxWxD                                                                           | 900x450x310                       | 900x585x310     | 900x780x310     | 900x1110x310    | 900x1430x310    |
|                                                                                   | Factory-assembled                                                               | <b>Type</b> EH3BEXEH              | EH3BE0EH        | EH3BE1EH        | EH3BE2EH        | -               |
|                                                                                   |                                                                                 | <b>Order code</b> 4TBE843390N0100 | 4TBE843391N0100 | 4TBE843392N0100 | 4TBE843393C0100 |                 |
|                                                                                   | Polyester base, supplied in kit form, RAL 7035                                  | <b>Type</b> EH3SEXEI              | EH3SE0EI        | EH3SE1EI        | EH3SE2EI        | EH3SE3EI        |
|                                                                                   |                                                                                 | <b>Order code</b> 4TBE843204R0100 | 4TBE843205R0100 | 4TBE843206R0100 | 4TBE843207R0100 | 4TBE843208R0100 |
|                                                                                   | Base made from recycled material<br>Construction kit, Color similar to RAL 7035 | <b>Type</b> EH3SEXEH              | EH3SE0EH        | EH3SE1EH        | EH3SE2EH        | EH3SE3EH        |
|                                                                                   | <b>Order code</b> 4TBE842098C0100                                               | 4TBE842099R0100                   | 4TBE842100R0100 | 4TBE842101R0100 | 4TBE843144R0100 |                 |
| Concrete base (with metal front plate)                                            | <b>Type</b> EH3REXEJ                                                            | EH3RE0EJ                          | EH3RE1EJ        | EH3RE2EJ        | EH3RE3EJ        |                 |
|                                                                                   | <b>Order code</b> 4TBE843272C0100                                               | 4TBE843273C0100                   | 4TBE843274C0100 | 4TBE843275C0100 | 4TBE843276C0100 |                 |

 
#### Mounting plates

|                                                                                    |                         |                                   |                 |                 |                 |                 |            |
|------------------------------------------------------------------------------------|-------------------------|-----------------------------------|-----------------|-----------------|-----------------|-----------------|------------|
|  | HxWxD                   | 665x350x5                         | 665x485x5       | 665x680x5       | 705x1000x5      | 705x1340x5      |            |
|                                                                                    | Pertinax mounting plate | <b>Type</b> EH3M8XEH              | EH3M80EH        | EH3M81EH        | EH3M82EH        | EH3M83EI        |            |
|                                                                                    |                         | <b>Order code</b> 4TBE843681C0100 | 4TBE843024C0100 | 4TBE843044C0100 | 4TBE843057C0100 | 4TBE843067C0100 |            |
|                                                                                    | Height 1125 mm          | HxWxD                             | 915x350x5       | 915x485x5       | 915x680x5       | 955x1000x5      | 955x1340x5 |
|                                                                                    |                         | <b>Type</b> EH3M9XEH              | EH3M90EH        | EH3M91EH        | EH3M92EH        | EH3M93EI        |            |
|                                                                                    |                         | <b>Order code</b> 4TBE843682C0100 | 4TBE843070C0100 | 4TBE843071C0100 | 4TBE843072C0100 | 4TBE843256C0100 |            |
|                                                                                    | HxWxD                   |                                   |                 | 915x680x10      | 955x1000x10     | 955x1340x10     |            |
|                                                                                    | <b>Type</b> -           | -                                 |                 | EH3M91EHP       | EH3M92EHP       | EH3M93EH        |            |
|                                                                                    | <b>Order code</b>       |                                   |                 | 4TBE783325C0100 | 4TBE783326C0100 | 4TBE783327C0100 |            |

#### Base plates

|                                                                                     |                                                |                                   |                 |                 |                 |                 |
|-------------------------------------------------------------------------------------|------------------------------------------------|-----------------------------------|-----------------|-----------------|-----------------|-----------------|
|  | HxWxD                                          | 427x285x3                         | 562x285x3       | 757x285x3       | 1086x285x3      | 1416x285x3      |
|                                                                                     | Base plate 3 mm polyester with securing screws | <b>Type</b> EH3PEXEI              | EH3PE0EH        | EH3PE1EH        | EH3PE2EH        | EH3PE3EH        |
|                                                                                     |                                                | <b>Order code</b> 4TBE843683C0100 | 4TBE843300C0100 | 4TBE843301C0100 | 4TBE843302C0100 | 4TBE843303C0100 |


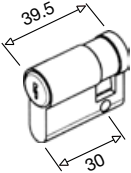




#### Wall mounting kit

|                                                                                     |                                                                      |                                   |                 |                 |                 |                 |
|-------------------------------------------------------------------------------------|----------------------------------------------------------------------|-----------------------------------|-----------------|-----------------|-----------------|-----------------|
|  | B                                                                    | 555                               | 710             | 885             | 1215            | 1545            |
|                                                                                     | Wall mounting kit Two Alu C profiles with brackets for wall mounting | <b>Type</b> EH3WEXEI              | EH3WE0EH        | EH3WE1EH        | EH3WE2EH        | EH3WE3EH        |
|                                                                                     |                                                                      | <b>Order code</b> 4TBE843684N0100 | 4TBE843441C0100 | 4TBE843442C0100 | 4TBE843443C0100 | 4TBE843444N0100 |

 
## Pedestals

### EH3 - Accessories


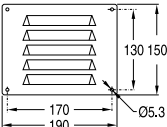
#### EH3 - Accessories

| Product                                                                                                                                                                | Type                                                                                                          | Order code               | Pack |
|------------------------------------------------------------------------------------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------------|--------------------------|------|
| <b>Locks with profile half cylinder</b>                                                                                                                                |                                                                                                               |                          |      |
| <br> |  With 2 keys , V2432-E       | EH3AEECI 4TBE843001C0100 | 1    |
|                                                                                                                                                                        | Spare keys for EH3AEECI                                                                                       | PS832022 4TBP832022C0100 | 2    |
|                                                                                                                                                                        |  With 1 square key, 8 mm     | EH3AEEQH 4TBE843002C0100 | 1    |
|                                                                                                                                                                        |  With an 8 mm triangular key | EH3AEETH 4TBE843003C0100 | 1    |
|                                                                                                                                                                        |  With 2 keys A434            | EH3UAECI 4TBE843248C0100 | 1    |
|                                                                                                                                                                        | Spare keys upon request.                                                                                      |                          |      |


#### Diagram holder

|                                                                                    |                            |   |  |
|------------------------------------------------------------------------------------|----------------------------|---|--|
|  | DIN A4 - W x H = 325x180mm |   |  |
|                                                                                    | AR811516 4TBX811516R0100   | 1 |  |
|                                                                                    | DIN A5 - W x H= 155x225 mm |   |  |
|                                                                                    | PS832000 4TBP832000C0100   | 1 |  |

#### IP44 ventilation grille

|                                                                                                                                                                            |                                                                                                     |                          |   |
|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------|--------------------------|---|
| <br> | Set of 2 pieces                                                                                     | PS832019 4TBP832019C0100 | 1 |
|                                                                                                                                                                            | Suitable for a ventilation opening Includes 2 grilles and 4 nylon nails. Total insulation. RAL 7035 |                          |   |
|                                                                                                                                                                            |                                                                                                     |                          |   |


#### Threaded insert

|                                                                                     |                                                          |     |  |
|-------------------------------------------------------------------------------------|----------------------------------------------------------|-----|--|
|  | M8 threaded insert<br>Dodge-type for rear wall and door. |     |  |
|                                                                                     | APTIM4 4TBO851026C0100                                   | 100 |  |
|                                                                                     | Punch for inserting M8 threaded barrel.                  |     |  |
|                                                                                     | EHUOEEEG 4TBC844039C0100                                 | 1   |  |


| Product                                                                                                                                                                                                                                                                                                                                                                           | Type | Order code | Pack |
|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|------|------------|------|
| <b>Vandal proof nameplate holder</b>                                                                                                                                                                                                                                                                                                                                              |      |            |      |
| Can be placed on every flat surface, by drilling two holes Ø 5.5 mm; the identification window is used as a drill template. Steady against vandalism; it keeps its total isolation . Possibility to write on manually and/or to use the standard lettering systems; the maximal letter height is 18 mm. Usefull dimensions of letters: 18 x 143. Outside dimensions: 30 x 183 x 5 |      |            |      |

|                                                                                    |                          |   |  |
|------------------------------------------------------------------------------------|--------------------------|---|--|
|  | EH3AEEE4 4TBE843304C0100 | 1 |  |
|                                                                                    |                          |   |  |


#### Handle

|                                                                                     |                                              |   |  |
|-------------------------------------------------------------------------------------|----------------------------------------------|---|--|
|  | Handle for lock with a profile half cylinder |   |  |
|                                                                                     | EH3EEESH 4TBE843000C0100                     | 1 |  |
|                                                                                     | Spare part                                   |   |  |

#### Double closure handle

|                                                                                      |                                                                                                   |   |  |
|--------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------|---|--|
|  | For two locks with profile half cylinder                                                          |   |  |
|                                                                                      | EH3AEEDH 4TBE783042C0100                                                                          | 1 |  |
|                                                                                      | Spare part (Note: for after-market installation, an operation is required on the door mechanism). |   |  |



#### Concrete base (kit)

|                                                                                      |                          |   |  |
|--------------------------------------------------------------------------------------|--------------------------|---|--|
|  | Size: DIN00              |   |  |
|                                                                                      | EH3REXEJ 4TBE843272C0100 | 1 |  |
|                                                                                      | Size: DIN0               |   |  |
|                                                                                      | EH3RE0EJ 4TBE843273C0100 | 1 |  |
|                                                                                      | Size: DIN1               |   |  |
|                                                                                      | EH3RE1EJ 4TBE843274C0100 | 1 |  |
|                                                                                      | Size: DIN2               |   |  |
|                                                                                      | EH3RE2EJ 4TBE843275C0100 | 1 |  |
| Size: DIN3                                                                           |                          |   |  |
| EH3RE3EJ 4TBE843276C0100                                                             | 1                        |   |  |


## Pedestals


### EH3 - Accessories


#### EH3 - Accessories


| Product                                                                                                                                                                                                                                                                                                                                                                            | Type                                                                                                                            | Order code | Pack              |
|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------------------------------|------------|-------------------|
| <b>Front plate with opening for temporary connections on DIN base</b>                                                                                                                                                                                                                                                                                                              |                                                                                                                                 |            |                   |
| May be used with DIN -00 to -2 bases in RAL 7035 color (EH3SEXEI-EH3SE2EI). This front plate is not standard and must be ordered in addition. The standard closed front plate may be used if it is not necessary for temporary connections. The DIN 3 base is standard with a front plate for temporary connections. The front plates on the front and rear are secured by screws. |                                                                                                                                 |            |                   |
|                                                                                                                                                                                                                                                                                                   | For DIN 0 base - EH3SE0EI - 1 opening                                                                                           | EH3TE0EE   | 4TBE843713R0100 1 |
|                                                                                                                                                                                                                                                                                                                                                                                    | For DIN 1 base - EH3SE1EI - 1 opening                                                                                           | EH3TE1EE   | 4TBE843714R0100 1 |
|                                                                                                                                                                                                                                                                                                   | For DIN 2 base - EH3SE2EI - 2 openings                                                                                          | EH3TE2EE   | 4TBE843715R0100 1 |
|                                                                                                                                                                                                                                                                                                                                                                                    | Standard DIN 3 base with a front plate for temporary connections. The front plates on the front and rear are secured by screws. | EH3TE3EE   | 4TBE843716R0100 1 |



| Product                                                                           | Type                                                  | Order code | Pack              |
|-----------------------------------------------------------------------------------|-------------------------------------------------------|------------|-------------------|
| <b>Locking plate</b>                                                              |                                                       |            |                   |
|  | Double door lock with 3-point lock for reinforcement. | EH3AEECY   | 4TBE843560N0100 1 |

| Product                                                                            | Type                                                                                                                                       | Order code | Pack              |
|------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------|------------|-------------------|
| <b>Door locking</b>                                                                |                                                                                                                                            |            |                   |
|  | May be installed on left-hand or right-hand swinging doors. Mounting by drilling 2 holes in the interior profile. Includes mounting parts. | EH3AEEEZ   | 4TBE843007C0100 1 |


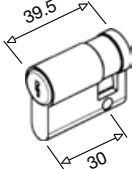




| Product                                                                            | Type                               | Order code | Pack              |
|------------------------------------------------------------------------------------|------------------------------------|------------|-------------------|
| <b>Screws (replacement parts)</b>                                                  |                                    |            |                   |
|  | Clip-in button<br>Hilo 5.8 x 16 mm | EH3AEEEN   | 4TBE843556C0100 1 |
|                                                                                    | Clip-in button<br>Hilo 5.8 x 22 mm | EH3OEEEG   | 4TBE890278C0100 1 |

| Product                                                                             | Type       | Order code | Pack              |
|-------------------------------------------------------------------------------------|------------|------------|-------------------|
| <b>Mounting bolts for mounting plates (replacement parts)</b>                       |            |            |                   |
|  | DIN 00-0-1 | EH3AE0EI   | 4TBE843566C0100 1 |
|                                                                                     | DIN 2-3    | EH3AE2EI   | 4TBE843567C0100 1 |

 
# Pedestals

## EH3 / GD - Accessories


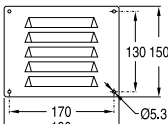
### EH3 - Accessories

| Product                                                                                                                                                                | Type                                                                                                          | Order code               | Pack |
|------------------------------------------------------------------------------------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------------------|--------------------------|------|
| <b>Locks with profile half cylinder</b>                                                                                                                                |                                                                                                               |                          |      |
| <br> |  With 2 keys , V2432-E       | EH3AEECI 4TBE843001C0100 | 1    |
|                                                                                                                                                                        | Spare keys for EH3AEECI                                                                                       | PS832022 4TBP832022C0100 | 2    |
|                                                                                                                                                                        |  With 1 square key, 8 mm     | EH3AEEQH 4TBE843002C0100 | 1    |
|                                                                                                                                                                        |  With an 8 mm triangular key | EH3AEETH 4TBE843003C0100 | 1    |
|                                                                                                                                                                        |  With 2 keys A434            | EH3UAECI 4TBE843248C0100 | 1    |
|                                                                                                                                                                        | Spare keys upon request.                                                                                      |                          |      |


### Diagram holder

|                                                                                    |                            |   |  |
|------------------------------------------------------------------------------------|----------------------------|---|--|
|  | DIN A4 - W x H = 325x180mm |   |  |
|                                                                                    | AC811516 4TBC811516C0100   | 1 |  |
|                                                                                    | DIN A5 - W x H= 155x225 mm |   |  |
|                                                                                    | PS832000 4TBP832000C0100   | 1 |  |


### IP44 ventilation grille

|                                                                                                                                                                            |                                                                                                     |                          |   |
|----------------------------------------------------------------------------------------------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------|--------------------------|---|
| <br> | Set of 2 pieces                                                                                     | PS832019 4TBP832019C0100 | 1 |
|                                                                                                                                                                            | Suitable for a ventilation opening Includes 2 grilles and 4 nylon nails. Total insulation. RAL 7035 |                          |   |

### Threaded insert

|                                                                                     |                                                          |     |  |
|-------------------------------------------------------------------------------------|----------------------------------------------------------|-----|--|
|  | M8 threaded insert<br>Dodge-type for rear wall and door. |     |  |
|                                                                                     | APTIM4 4TBO851026C0100                                   | 100 |  |
|                                                                                     | Punch for inserting M8 threaded barrel.                  |     |  |
|                                                                                     | EHUOEEEG 4TBC844039C0100                                 | 1   |  |


| Product                                                                                                                                                                                                                                                                                                                                                                           | Type | Order code | Pack |
|-----------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|------|------------|------|
| <b>Vandal proof nameplate holder</b>                                                                                                                                                                                                                                                                                                                                              |      |            |      |
| Can be placed on every flat surface, by drilling two holes Ø 5.5 mm; the identification window is used as a drill template. Steady against vandalism; it keeps its total isolation. Possibility to write on manually and/or to use the standard lettering systems; the maximal letter height is 18 mm. Usefull dimensions of letters: 18 x 143. Outside dimensions: 30 x 183 x 5. |      |            |      |

|                                                                                    |                          |   |
|------------------------------------------------------------------------------------|--------------------------|---|
|  | EH3AEEE4 4TBE843304C0100 | 1 |
|------------------------------------------------------------------------------------|--------------------------|---|

### Handle

|                                                                                     |                                              |   |  |
|-------------------------------------------------------------------------------------|----------------------------------------------|---|--|
|  | Handle for lock with a profile half cylinder |   |  |
|                                                                                     | EH3EEESH 4TBE843000C0100                     | 1 |  |
|                                                                                     | Spare part                                   |   |  |

### Double closure handle

|                                                                                      |                                                                                                   |   |  |
|--------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------------|---|--|
|  | For two locks with profile half cylinder                                                          |   |  |
|                                                                                      | EH3AEEDH 4TBE783042C0100                                                                          | 1 |  |
|                                                                                      | Spare part (Note: for after-market installation, an operation is required on the door mechanism). |   |  |


### Concrete base (kit)

|                                                                                      |                          |   |  |
|--------------------------------------------------------------------------------------|--------------------------|---|--|
|  | Size: DIN00              |   |  |
|                                                                                      | EH3REXEJ 4TBE843272C0100 | 1 |  |
|                                                                                      | Size: DIN0               |   |  |
|                                                                                      | EH3RE0EJ 4TBE843273C0100 | 1 |  |
|                                                                                      | Size: DIN1               |   |  |
|                                                                                      | EH3RE1EJ 4TBE843274C0100 | 1 |  |
|                                                                                      | Size: DIN2               |   |  |
|                                                                                      | EH3RE2EJ 4TBE843275C0100 | 1 |  |
| Size: DIN3                                                                           |                          |   |  |
| EH3RE3EJ 4TBE843276C0100                                                             | 1                        |   |  |

 
## Pedestals

### EH4 - Column cabinets

#### EH4/ EH4S - Distribution columns

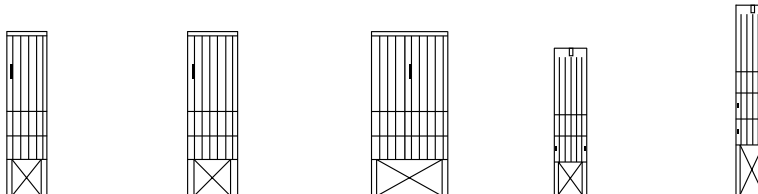

|                   | Width | 395              | 495              | 745              | 320              | 320              |
|-------------------|-------|------------------|------------------|------------------|------------------|------------------|
| <b>Type</b>       |       | <b>EH4-00</b>    | <b>EH4-0</b>     | <b>EH4-1</b>     | <b>EH4-S1</b>    | <b>EH4-S2</b>    |
| HxWxD             |       | 1600 x 395 x 224 | 1600 x 495 x 224 | 1600 x 745 x 224 | 1420 x 320 x 234 | 1850 x 320 x 234 |
| <b>Type</b>       |       | EH4CAECH         | EH4CAECI         | EH4CAEL          | EH4CB9CH         | EH4CC9CH         |
| <b>Order code</b> |       | 4TBE844130R0100  | 4TBE844131R0100  | 4TBW844132C0100  | 4TBE844153R0100  | 4TBE844185R0100  |



|                   | HxWxD | 790 x 370 x 5   | 790 x 470 x 5   | 790 x 720 x 5   | 600 x 278 x 5   | 950 x 278 x 5   |
|-------------------|-------|-----------------|-----------------|-----------------|-----------------|-----------------|
| <b>Type</b>       |       | EH4MEXEH        | EH4ME0EH        | EH4ME1EH        | EH4MB9EH        | EH4MC9EH        |
| <b>Order code</b> |       | 4TBE844133C0100 | 4TBE844134C0100 | 4TBE844135N0100 | 4TBE844154R0100 | 4TBE844186R0100 |

#### Accessories

| Product                                 | Type                                               | Order code      | Pack |
|-----------------------------------------|----------------------------------------------------|-----------------|------|
| <b>Locks with profile half cylinder</b> |                                                    |                 |      |
|                                         | For EH4 - security lock V2432E                     |                 |      |
|                                         | PS832030                                           | 4TBP832030C0100 | 1    |
|                                         | Spare keys for PS832030                            |                 |      |
|                                         | PS832741                                           | 4TBP832741R0100 | 2    |
|                                         | For EH4 - security lock V2432E with double closure |                 |      |
|                                         | PS832331                                           | 4TBP832331R0100 | 1    |
| For EH4-S - with 2 keys, V2432-E        |                                                    |                 |      |
| EH3AEECI                                | 4TBE841001C0100                                    | 1               |      |
| Spare keys for 843001                   |                                                    |                 |      |
| PS832022                                | 4TBP832022C0100                                    | 1               |      |
| Spare keys upon request.                |                                                    |                 |      |

| Product                      | Type                                                                                              | Order code      | Pack |
|------------------------------|---------------------------------------------------------------------------------------------------|-----------------|------|
| <b>Double closure handle</b> |                                                                                                   |                 |      |
|                              | For two locks with profile half cylinder                                                          |                 |      |
|                              | EH4AEEDH                                                                                          | 4TBE844152C0100 | 1    |
|                              | Spare part (Note: for after-market installation, an operation is required on the door mechanism). |                 |      |

