

# Stanilite®

## Platinum exit LED evago Nexus® wall mount



### Range

Platinum range

### Product group


Exit LED evago



### Features

- LED technology 100,000 hours plus lamp life
- Low power consumption and LED light source for reduced operation and maintenance costs
- Advanced charging technology combined with Lithium iron phosphate battery for long life and low maintenance
- Nexus monitored, wireless
- RF frequency range 920 - 925 MHz
- Bright and uniform exit face luminance
- Architecturally pleasing frameless slim line design
- First-fix plate for quick and easy installation and maintenance
- 24m viewing distance
- Surface mounting (requires space behind the wall for Nexus RF communication module and antenna)
- Product comes standard with running man pictograph straight. Other pictograph diffuser options (arrow left/right) can be ordered separately - see accessories

Catalogue no.	Description
<b>Nexus products</b>	
SGPELEVRFSWM-1	Platinum exit LED evago Nexus RF wall mount single sided picto
<b>Accessories</b>	
31-BPGEVG	Backplate evago 24m
31-PEVG1	Diffuser evago 24m picto
31-PEVG2	Diffuser evago 24m <picto
31-PEVG3	Diffuser evago 24m picto>
<b>Spare parts</b>	
03-YPMA011	Battery LiFePO4 3.2V 1.14Ah

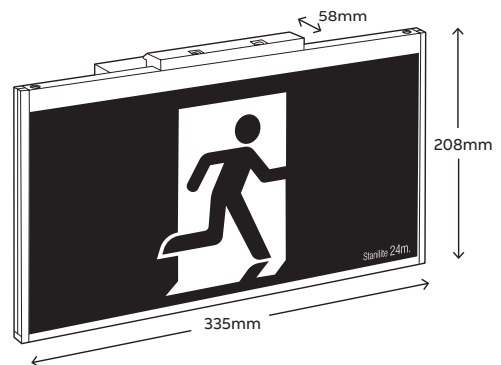

Dimensions			
Item	Length	Width	Height
Control module	159mm	52mm	41mm
Diffuser assembly	335mm	12mm	184mm

Weight	
Model	Weight
Nexus RF	1.6kg

Construction	
Part	Construction
Body	Diecast aluminum
Light guide	Polycarbonate
Diffuser	Acrylic

<b>Light source</b>		
	<b>Model</b>	<b>Light source</b>
	Nexus RF	Multiple LED 0.6W

<b>Power consumption</b>		
	<b>Model</b>	<b>Power consumption</b>
	Nexus RF	2.0W average

Note: Preliminary results

Note:  
 - Complies to IEC60598.2.22 and AS2293