


—
INSTALLATION INSTRUCTION

Fourth pole

OTP_80FP, OTP_80FD

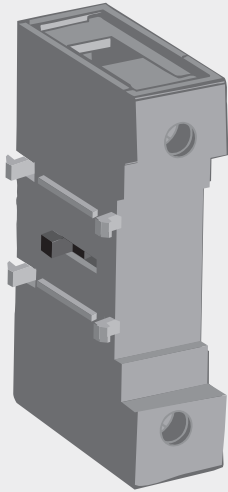

OTP_80FP


OTPS80FP OTPL80FP OTPN80F OTPE80FP OTPD80FP




UL not completed
CSA not completed
OTPL80FP
OTPD80FP

UL US IND.CONT. EQ 3E73
General Use Ratings
600 VAC 80 A
Listed for use with
OT63F3, OT80F3



OT63F3, OT80F3

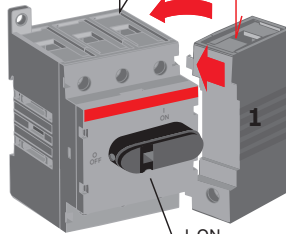

ON
OFF

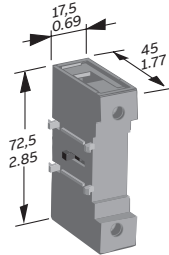


OTPD80FP



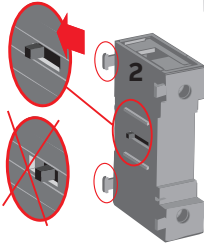
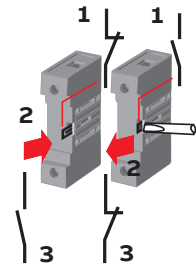


! Connect in the middle of the terminal clamp.

 1,5...6 mm²
14...10 AWG




> 6...35 mm²
> 10...4 AWG

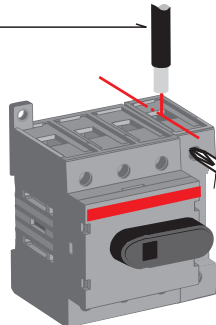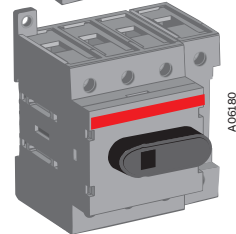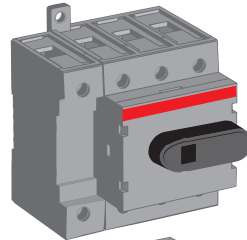 


2 Nm
17.7 lb.in

POZIDRIVE
M5 Form 2

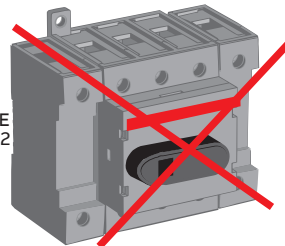

OTP_80FD

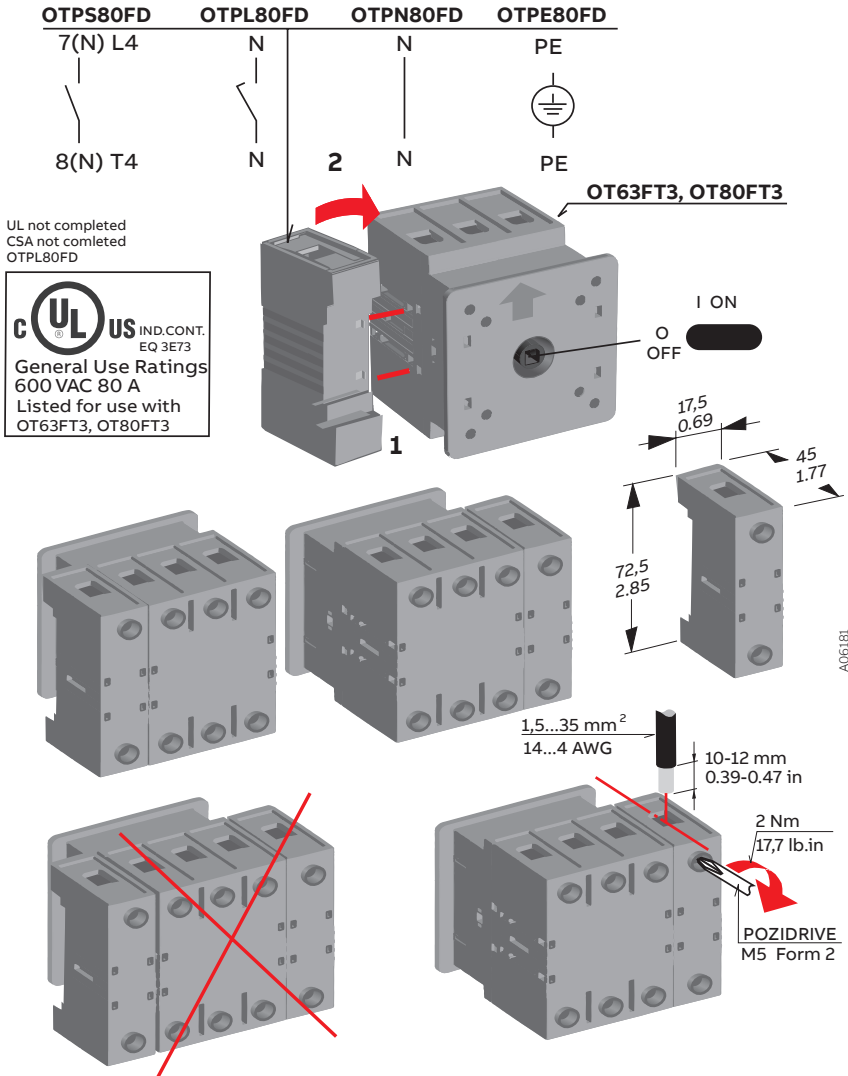



Contact us

ABB Oy

P.O. Box 622
FI-65101 Vaasa
Finland

abb.com/lowvoltage