



# Cable - C5

## Machine Safety - Jokab Safety products

ID 2TLC172005L0201 Date July 2013

### C5 cable 5 x 0.34 shielded

#### Technical data - C5

Article number	2TLA020057R0000
EAN	7350024452532
Specification	22AWG*5C+D+AL
<b>Conductor</b>	
Specification	22 AWG
Material	Tinned stranded copper
Configuration	TS17/0.16 ± 0.005 mm
<b>Insulation</b>	
Avg. Thick	0.26 mm
Min. Thick	0.22 mm
Diameter	1.30 ± 0.10 mm
Material	Environmental protection PVC (RoHS)
Colour	Brown, White, Blue, Black, Gray
<b>Assembly</b>	
Drain wire	TS7/0.16 ± 0.005 mm
Aluminum	10*0.025 mm
<b>Jacket</b>	
Avg. Thick	1.00 mm
Min. Thick	0.80 mm
Diameter	5.50 ± 0.20 mm
Material	Environmental protection PVC60P (RoHS)
Colour	Black (fog matte)
<b>Electrical capability</b>	
Rated temperature	80 °C
Rated voltage	300 V
Cond. Resistance	60.25 Ω /KM 20 °C
Insu. Resistance	2.5 MΩ/KM 20 °C
<b>Bending radius</b>	
	Static: 7 x cable diameter
	Dynamic: 12 x cable diameter
<b>Marking</b>	
	ABB  AWM 2464 22AWG VW-1 80 °C 300V E343967 FINECABLES
	 AWM 2464 22AWG I/II A FT1 80 °C 300V +LF+

#### Cross section

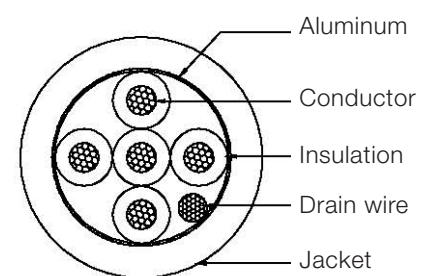


ABB AB  
 Low Voltage Products  
 Safety products  
<http://www.abb.com/jokabsafety>