


# Aqualux

Durable & high performance



### Back-lit LED exit sign

- Attractive aluminium modular enclosure
- Clear polycarbonate broad delivery diffuser
- Intelligent self-test as standard
- Complies to IEC 60598.2.22

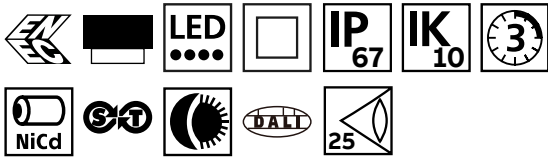

### LED base unit

Order code	Description	Input voltage	Lamp type	Lamp output (lm)	Power consumption (VA/W)	Operation / duration (hrs)	Environment temp. (°C)	Weight (kg)
CTOW3L261	CT 2LED M3	220-240 AC 50Hz	2 x LED 1W	59	9.9 / 5.1	3	0-25	1.7
IR2OW3L261	2LED M3 IR2	220-240 AC 50Hz	2 x LED 1W	59	9.9 / 5.1	3	0-25	1.7
OW1L261HF	2XLED SIGN 230VHF	220-240 AC/DC 0-60Hz	2 x LED 1W	89	8 / 3.5	230V	0-40	1.5
OW1L261LTC	2XLED 230V LTC	220-240 AC 50/60Hz	2 x LED 1W	89	8 / 3.5	230V	0-40	1.5
OW3L261	2LED M3	220-240 AC 50Hz	2 x LED 1W	59	9.9 / 5.1	3	0-25	1.7
OW3L261LS	2LEDM3 LSENS	220-240 AC 50Hz	2 x LED 1W	59	9.9 / 5.1	3	0-25	1.7
OW3L261V2	2LED M3 220V60HZ	220-240 AC 50/60Hz	2 x LED 1W	59	9.9 / 5.1	3	0-25	1.7
DLOW3LS60	3W LED DALI M3	220-240 AC 50Hz	1 x LED 3W	79	9.9 / 5.1	3	0-25	1.7

### Legends

Part No.	Pictogram
XEN2W	
XEN3W	
XEN6W	
XEN5W	
XLF802W	
XLF803W	
Arabic legend format	

ISO 7010 pictogram legends are shown. Euro format & Special legends are available to order see pages 138-141.

### Accessories

Order code	Description
OW/BCM	Ceiling bracket, vertical mount
OW/BWA	Wall bracket, angled mount

