



中国国家强制性产品认证证书

证书编号：2024010307646938

认证委托人名称及地址

ABB S. P. A.

Via Pescaria 5, 24123 Bergamo Italy

生产者名称及地址

ABB S. P. A.

Via Pescaria 5, 24123 Bergamo Italy

生产企业名称及地址

ABB S. P. A.

Via Enrico Fermi, 14 - 03100 Frosinone Italy

产品名称和系列、型号、规格

塑料外壳式断路器

A1A, A1B, A1C, A1N; 型号解释详见附页

产品标准和技术要求

GB/T 14048.2-2020

上述产品符合《强制性产品认证实施规则 低压电器 低压元器件》
(CNCA-C03-02:2024) 的要求，特发此证。

发证日期：2024 年 06 月 25 日 有效期至：2029 年 06 月 24 日

证书信息和有效性可扫描下方二维码或登录发证机构网站查验，
也可在认监委网站 (www.cnca.gov.cn) 查询。



签发：

谢肇煦



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

中国质量认证中心有限公司





中国国家强制性产品认证证书

证书编号: 2024010307646938

证书附页: 第 1 页 共 2 页

A1A, A1B, A1C, A1N

Ui: 690V;

Uimp: 6kV;

Ue: AC240V, AC415V, AC480V, AC550V, DC250V(两极串);

In: 15A, 16A, 20A, 25A, 30A, 32A, 40A, 50A, 60A, 63A, 70A, 80A, 90A, 100A, 125A;

Ics 和 Icu 参数如下:

		A1A	A1B	A1C	A1N
240Vac	Icu	10kA	25kA	30kA	100kA
	Ics	5kA	12.5kA	15kA	50kA
415Vac	Icu	10kA	18kA	25kA	36kA*
	Ics	5kA	5kA	9kA	9kA
480Vac	Icu	7.5kA	10kA	15kA	18kA
	Ics	4kA	5kA	5kA	5kA
550Vac	Icu	5kA	5kA	8kA	10kA
	Ics	2.5kA	2.5kA	2.5kA	2.5kA
250Vdc 2 poles in series	Icu	5kA	5kA	10kA	10kA
	Ics	2.5kA	2.5kA	5kA	5kA

*30kA for In 15A

选择性类别: A;

过电流脱扣器类型: 热磁式;

适用频率: 50/60Hz;

适用隔离;

极数: 3P, 4P

配用辅助触头: 证书编号: CQC2015010304766024

2NO2NC, 3NO3NC

AC-15:Ue/Ie:250V/4A,125V/5A;

AC-14:Ue/Ie:250V/5A,125V/6A;

AC-13:Ue/Ie:250V/6A,125V/6A;

DC-14:Ue/Ie:250V/0.03A,110V/0.05A;

DC-13:Ue/Ie:250V/0.03A,110V/0.05A;

DC-12:Ue/Ie:250V/0.3A,110V/0.5A;

本页为证书附页, 应与证书主页同时使用。



中国质量认证中心

CHINA QUALITY CERTIFICATION CENTRE

中国质量认证中心有限公司




中国国家强制性产品认证证书

证书编号: 2024010307646938


证书附页: 第 2 页 共 2 页

直流接线图如下:

3 极断路器

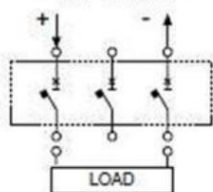

4 极断路器

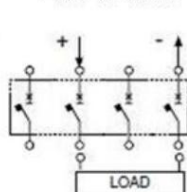

型号解释:

Tmax series Molded-case circuit breaker. Tmax 系列塑壳断路器

A 1 A/B/C/N 125

① ② ③ ④

①: MCCB Formula Series (Formula 系列塑壳断路器)

②: Frame Size 125A (框架电流 125A)

③: Breaking Capacity (短路分断能力)

④: Rated Current (额定电流)

本页为证书附页, 应与证书主页同时使用。



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

中国质量认证中心有限公司



CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation

CERTIFICATE NO.: 2024010307646938

NAME AND ADDRESS OF THE APPLICANT

ABB S.P.A.

Via Pescaria 5, 24123 Bergamo Italy

NAME AND ADDRESS OF THE MANUFACTURER

ABB S.P.A.

Via Pescaria 5, 24123 Bergamo Italy

NAME AND LOCATION OF THE FACTORY

ABB S.P.A.

Via Enrico Fermi,14 - 03100 Frosinone Italy

PRODUCT NAME,MODEL AND SPECIFICATION

Moulded Case Circuit-breaker

A1A , A1B , A1C , A1N; See the appendix

STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS

GB/T 14048.2-2020

This is to certify that the above mentioned product(s) complies with the requirements of implementation rules for compulsory certification(REFNO. CNCA-C03-02:2024).

Valid from: Jun.25,2024

Valid until: Jun.24,2029

The certificate information and validity could be checked by scanning the QR code below or logging in to the website of the issuing authority, or on the website of the CNCA (www.cnca.gov.cn).



SIGNATURE:

谢肇煦



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.





CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

CERTIFICATE NO. : 2024010307646938

Appendix: Page 1 of 2

本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation

A1A, A1B, A1C, A1N

Ui: 690V;

Uimp: 6kV;

Ue: AC240V, AC415V, AC480V, AC550V, DC250V(两极串);

In: 15A, 16A, 20A, 25A, 30A, 32A, 40A, 50A, 60A, 63A, 70A, 80A, 90A, 100A, 125A;

Ics 和 Icu 参数如下:

		A1A	A1B	A1C	A1N
240Vac	Icu	10kA	25kA	30kA	100kA
	Ics	5kA	12.5kA	15kA	50kA
415Vac	Icu	10kA	18kA	25kA	36kA*
	Ics	5kA	5kA	9kA	9kA
480Vac	Icu	7.5kA	10kA	15kA	18kA
	Ics	4kA	5kA	5kA	5kA
550Vac	Icu	5kA	5kA	8kA	10kA
	Ics	2.5kA	2.5kA	2.5kA	2.5kA
250Vdc 2 poles in series	Icu	5kA	5kA	10kA	10kA
	Ics	2.5kA	2.5kA	5kA	5kA

*30kA for In 15A

选择性类别: A;

过电流脱扣器类型: 热磁式;

适用频率: 50/60Hz;

适用隔离;

极数: 3P, 4P

配用辅助触头: 证书编号: CQC2015010304766024

2NO2NC, 3NO3NC

AC-15:Ue/Ie:250V/4A,125V/5A;

AC-14:Ue/Ie:250V/5A,125V/6A;

AC-13:Ue/Ie:250V/6A,125V/6A;

DC-14:Ue/Ie:250V/0.03A,110V/0.05A;

DC-13:Ue/Ie:250V/0.03A,110V/0.05A;

DC-12:Ue/Ie:250V/0.3A,110V/0.5A;

This page is attached to the certificate and should be used at the same time as the certificate page.



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.



CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION


CERTIFICATE NO. : 2024010307646938

Appendix: Page 2 of 2


本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation

直流接线图如下:

3 极断路器

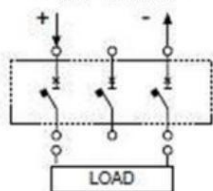

4 极断路器

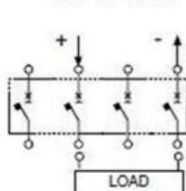

型号解释:

Tmax series Molded-case circuit breaker. Tmax 系列塑壳断路器

A 1 A/B/C/N 125

① ② ③ ④

①: MCCB Formula Series(Formula 系列塑壳断路器)

②: Frame Size 125A(框架电流 125A)

③: Breaking Capacity (短路分断能力)

④: Rated Current (额定电流)

This page is attached to the certificate and should be used at the same time as the certificate page.



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.