




TOP VIEW

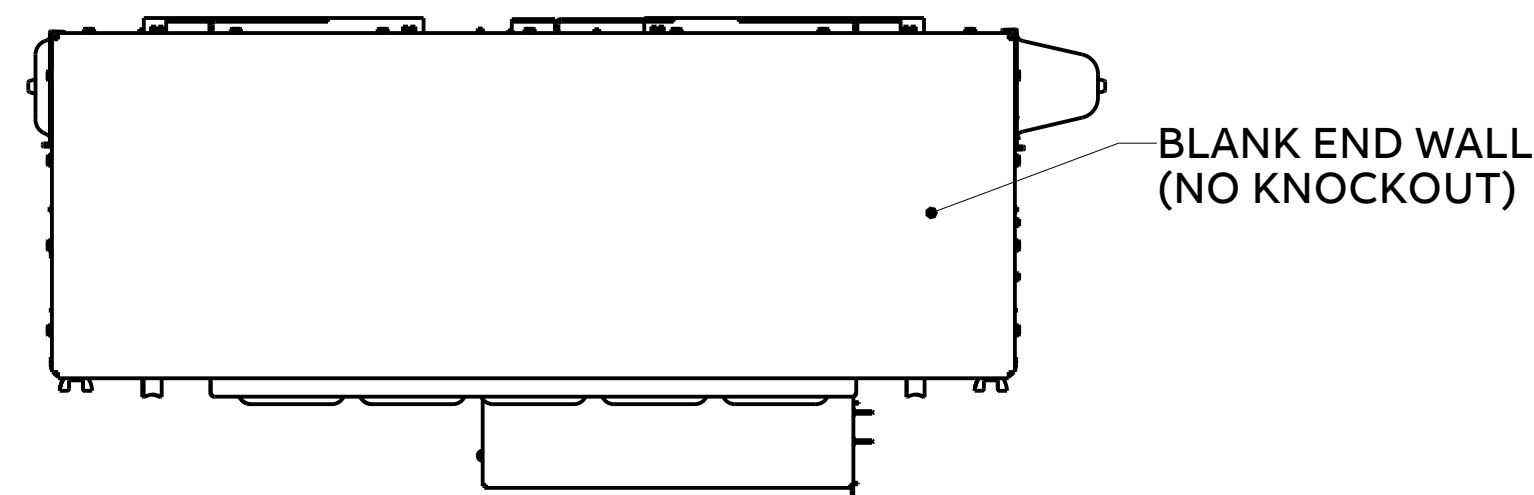


SECTIONAL SIDE VIEW

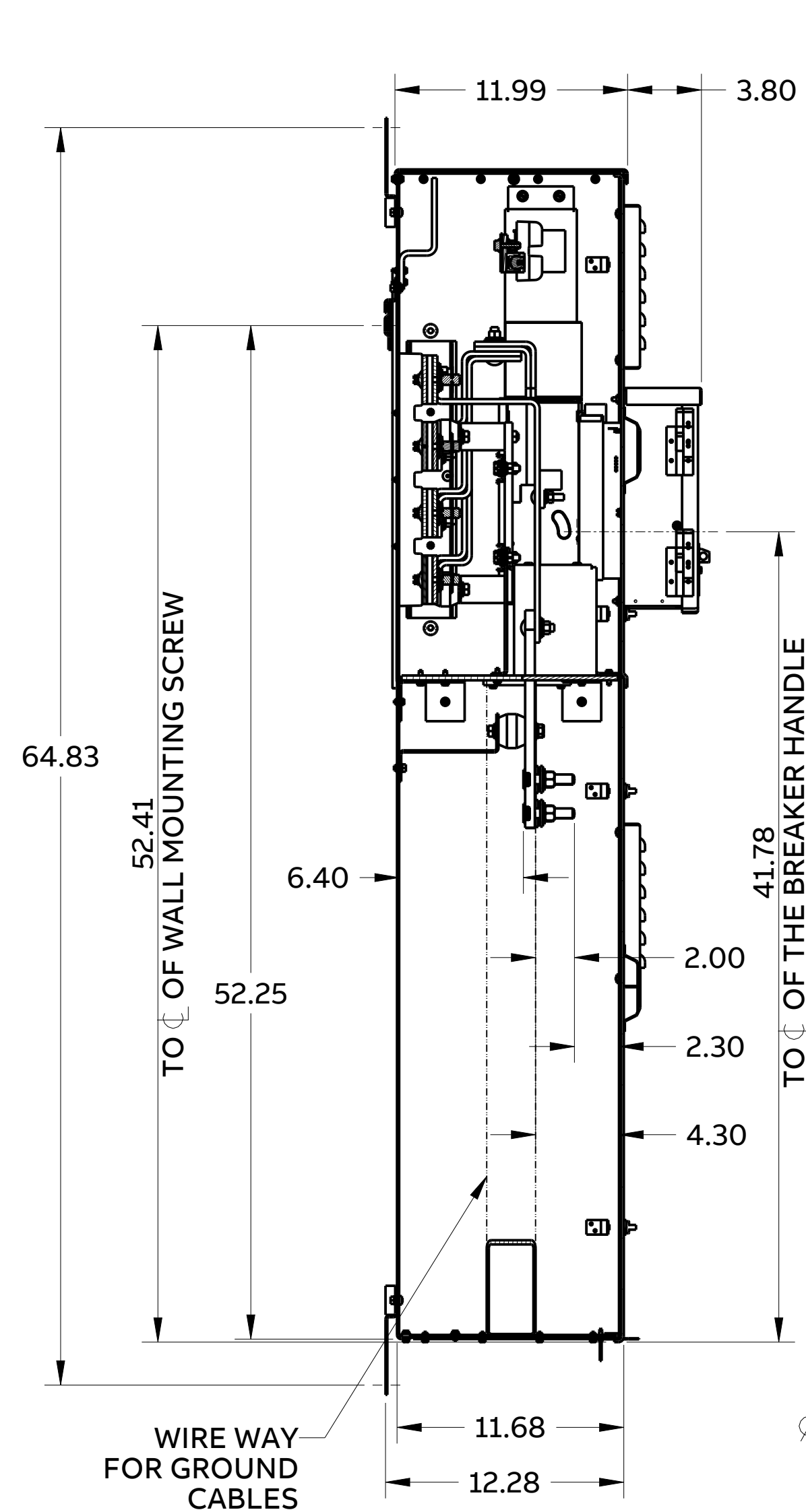


FRONT VIEW

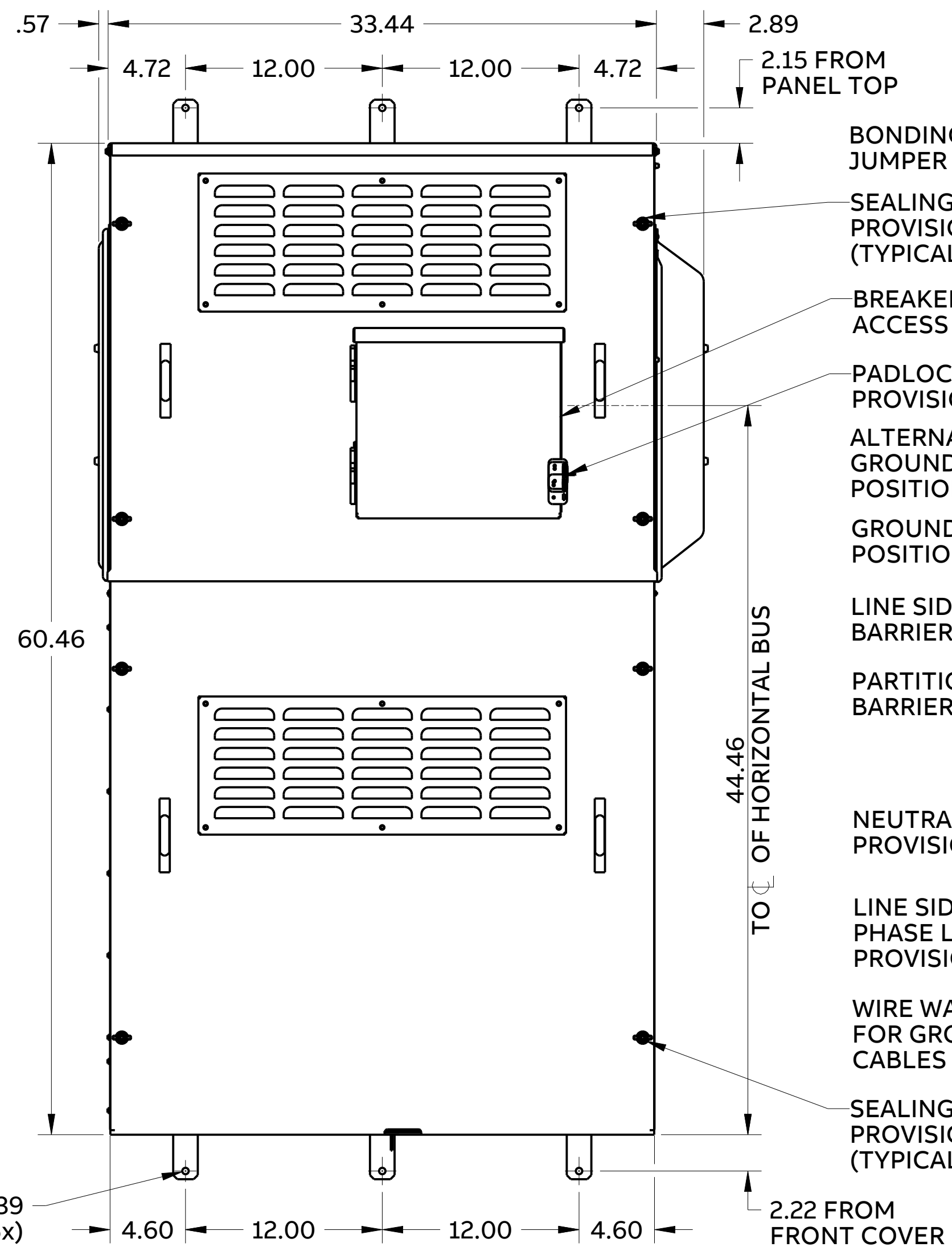

FRONT VIEW (WITH OUT FRONT COVERS)

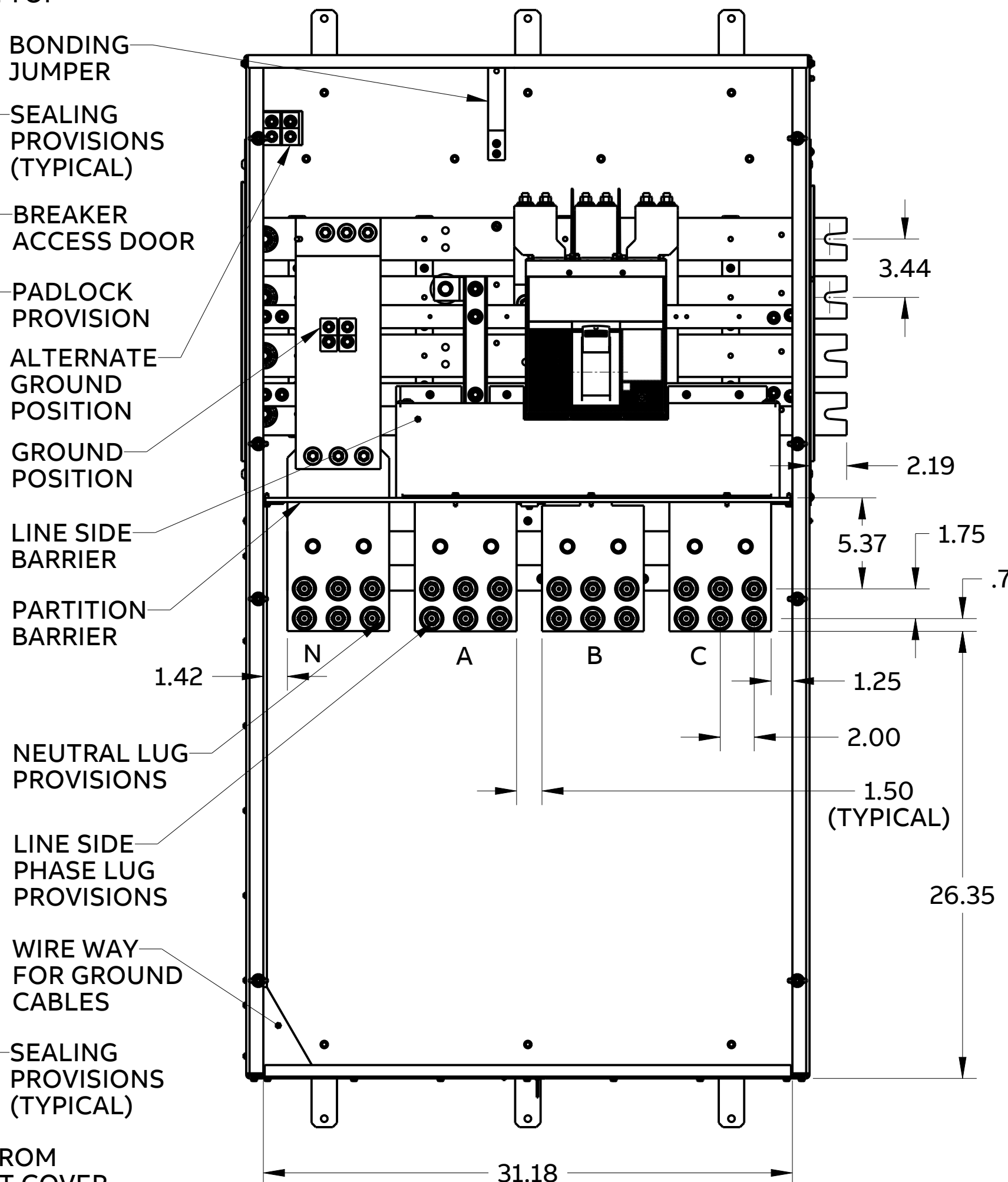

BOTTOM VIEW

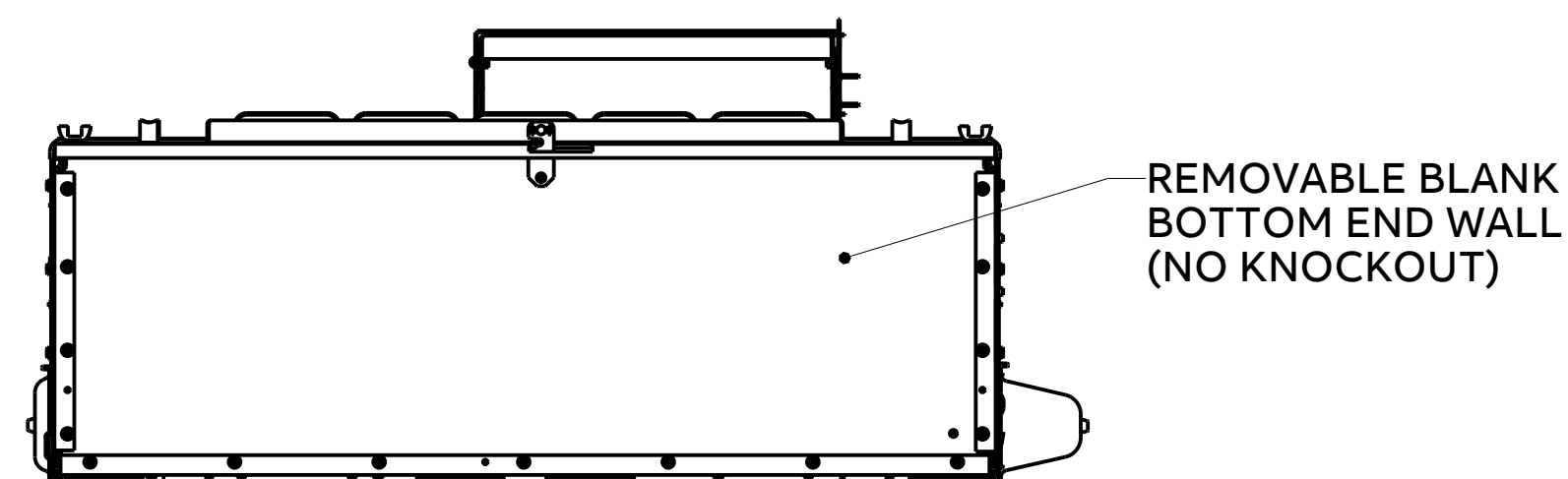

Specification:

- Phase: 3-Phase 4-Wire
- Voltage: 208Y/120V
- Amperage: 1000A
- Circuit Breaker Frame: XT7H
- Circuit Breaker Trip Unit: Ekip Dip LS/I
- Circuit Breaker kAIC: 100kA @ 240V
- Incoming Feed: Bottom Only
- Enclosure: N3R Outdoor
- Estimated Weight: 330 lbs
- Meets EUSERC Requirements, EUSERC Drawing Reference 315, 343, 347

Conductor Range:

- Phase lugs and neutral lugs not included, Landing Pad only.
- Landing Pad has provision for double hole lugs up to (3) 750kcmil Cu/Al.
- Ground Lugs: (2) #6-350 kcmil Cu/Al.



ReliaMod™

**1000A MAIN BREAKER MODULE
100kA 3PH 4W 208Y/120V N3R EUSERC**

THIRD ANGLE	SHEET#	CATALOG NO.	DATE	REV
	1 of 1	RMM3BEH10R	01-Aug-23	A

DIMENSIONS: INCH