

# Electrical installation solutions for buildings – Technical details

## Junction boxes


### Index

Livorno Series emergency consumer units	21/2
IP44, IP55 and IP65 Junction boxes	21/4
Europa65 junction boxes	21/7


## Junction boxes - technical details

Livorno Series flush- and wall- mounting emergency consumer units


### Front view

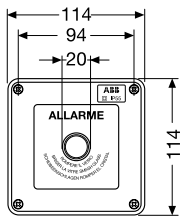


13 180 - 13 183

 


13 186

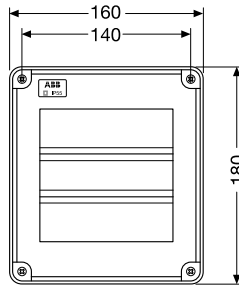


13 161 - 13 165

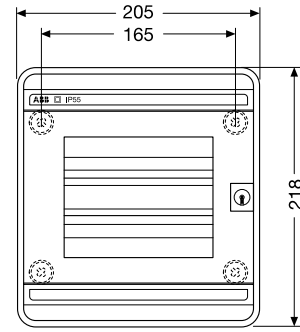

13 171 - 13 175

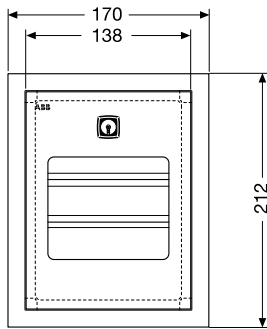


13 141 - 13 151

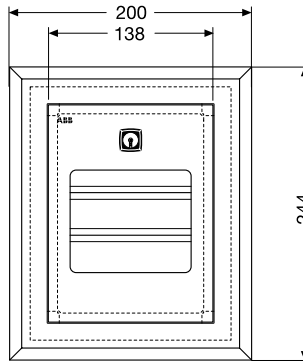


13 144  
13 143


### Side view

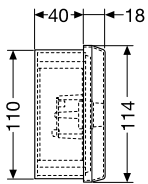


13 180

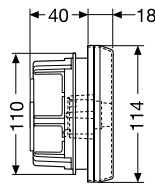


13 183

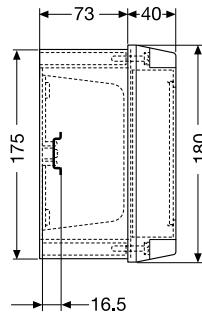


13 161 - 13 165

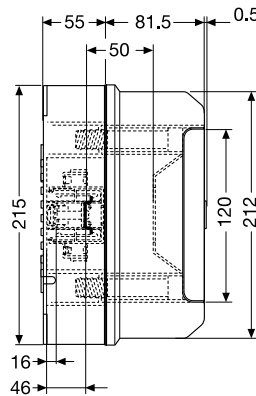

13 171 - 13 175

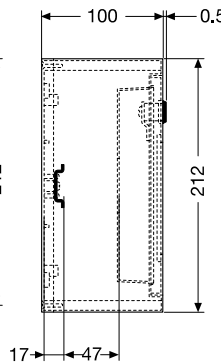

13 141 - 13 151

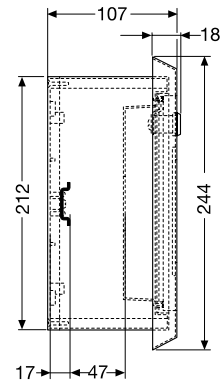


13 144  
13 143


## Junction boxes - technical details

Livorno Series flush- and wall- mounting emergency consumer units


### Drilling sheets

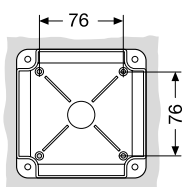


13 180

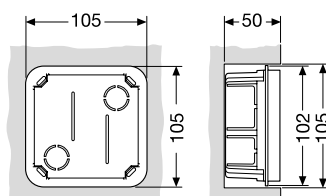


13 183

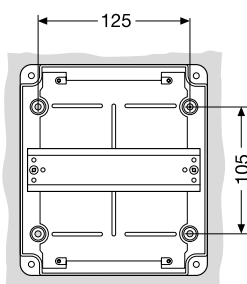


13 161 - 13 165

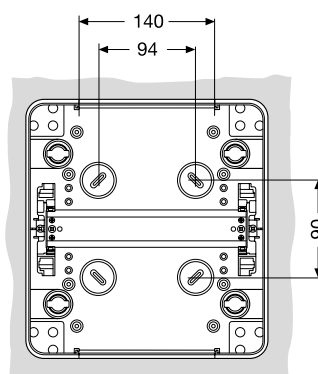

13 171 - 13 175

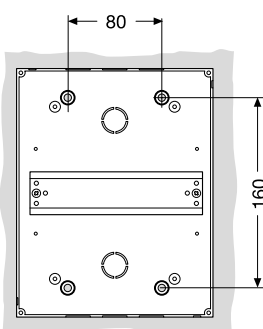


13 141 - 13 151

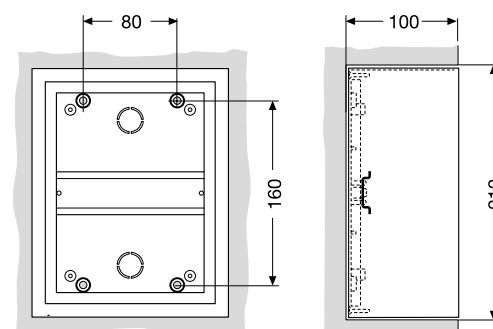13 144  
13 143


## Junction boxes - technical details

 IP 44 and IP 55 junction boxes in thermoplastic material


### Front view




00 800  
1SL0900A00

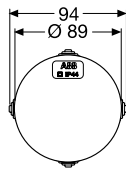


00 802  
1SL0901A00

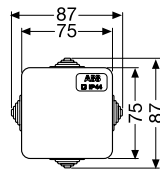


00 808  
1SL0902A00

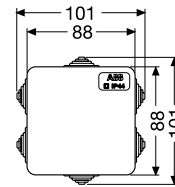


00 810  
1SL0903A00

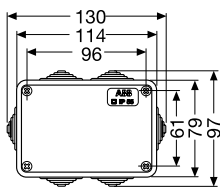


00 820 - 00 850  
1SL0820A00 - 1SL0850A00

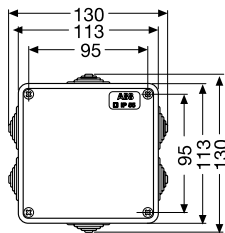


00 816 - 00 821  
00 846 - 00 851  
1SL0816A00 - 1SL0821A00  
1SL0846A00 - 1SL0851A00  
1SL0916A00 - 1SL0921A00  
1SL0946A00 - 1SL0951A00

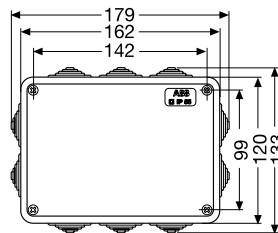


00 822 - 00852 - 00 872  
1SL0822A00 - 1SL0852A00  
1SL0872A00  
1SL0922A00

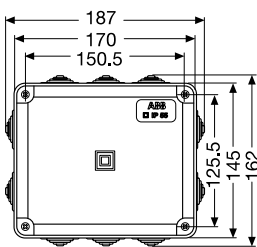

1SL0830A00 - 1SL0824A00  
1SL0874A00 - 1SL0854A00  
1SL0860A00 - 1SL0880A00  
1SL0924A00  
1SL0954A00  
1SL0960A00

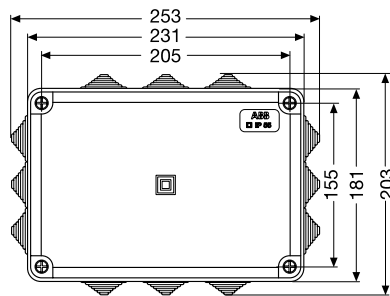

1SL0826A00 - 1SL0832A00  
1SL0876A00 - 1SL0856A00  
1SL0862A00 - 1SL0884A00  
1SL0926A00  
1SL0956A00  
1SL0962A00

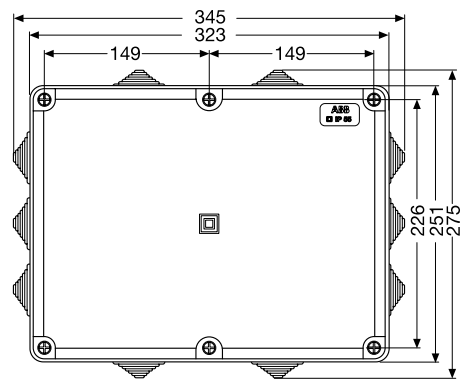


1SL0828A00 - 1SL0834A00  
1SL0858A00  
1SL0864A00 - 1SL0884A00  
1SL0928A00  
1SL0958A00  
1SL0964A00

## Junction boxes - technical details

IP 44 and IP 55 junction boxes in thermoplastic material

### Side view

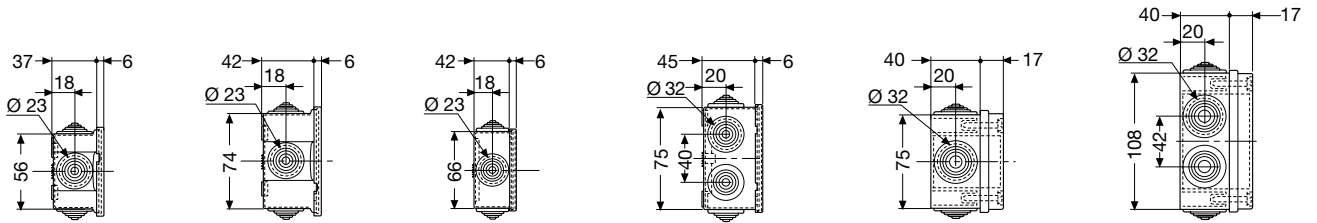

00 800  
1SL0900A00


00 802  
1SL0901A00

00 808  
1SL0902A00

00 810  
1SL0903A00

00 820 - 00 850  
1SL0820A00  
1SL0850A00

00 816 - 00 846  
1SL0816A00  
1SL0846A00  
1SL0916A00  
1SL0946A00

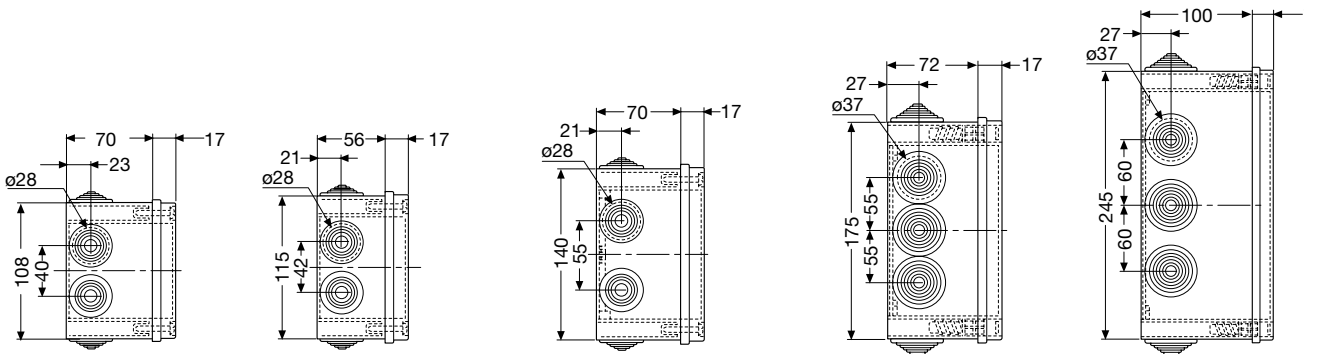


00 821 - 00 851  
1SL0821A00  
1SL0851A00  
1SL0921A00  
1SL0951A00

00 822 - 00 852  
00 872 - 1SL0822A00  
1SL0852A00 - 1SL0872A00  
1SL0922A00  
1SL0952A00

1SL0824A00 - 1SL0854A00  
1SL0874A00 - 1SL0924A00  
1SL0954A00

1SL0826A00  
1SL0856A00  
1SL0876A00  
1SL0926A00  
1SL0956A00

1SL0828A00  
1SL0858A00  
1SL0878A00  
1SL0928A00  
1SL0958A00

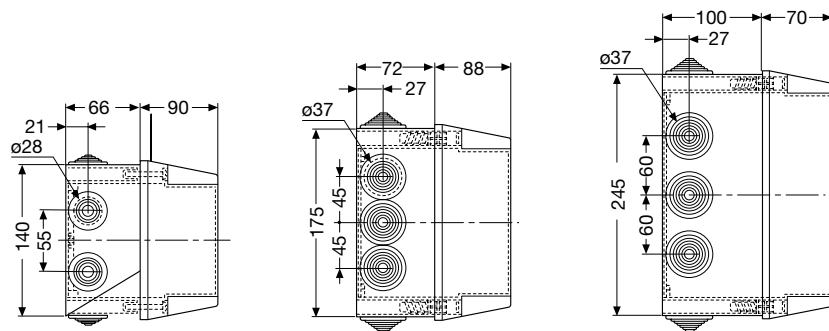

1SL0830A00  
1SL0860A00  
1SL0880A00  
1SL0960A00


1SL0832A00  
1SL0862A00  
1SL0882A00  
1SL0962A00  
1SL0982A00

1SL0834A00  
1SL0864A00  
1SL0884A00  
1SL0964A00


## Junction boxes - technical details

IP 44 and IP 55 junction boxes in thermoplastic material


### Drilling sheets and internal dimensions

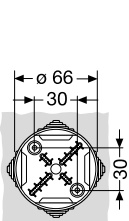


00 800 - 00 581  
1SL0900A00  
1SL0910A00

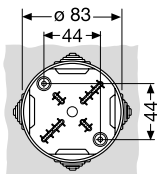


00 802  
1SL0901A00

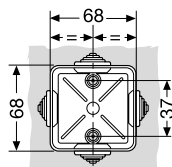


00 808  
1SL0902A00

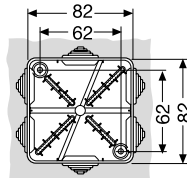


00 810  
1SL0903A00

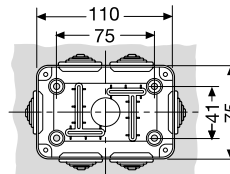


00 820 - 00 850  
1SL0820A00  
1SL0850A00

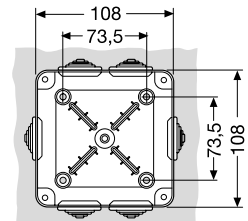


00 816 - 00 846  
1SL0816A00  
1SL0846A00  
1SL0916A00  
1SL0946A00

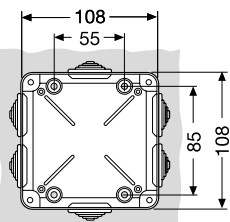


00 821 - 00 851  
1SL0821A00  
1SL0851A00  
1SL0921A00  
1SL0951A00

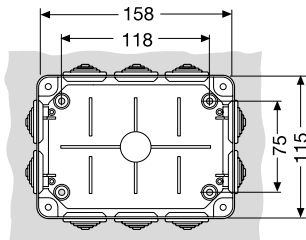


00 822 - 00 852 - 00 872  
1SL0822A00 - 1SL0852A00 - 1SL0872A00  
1SL0922A00 - 1SL0952A00

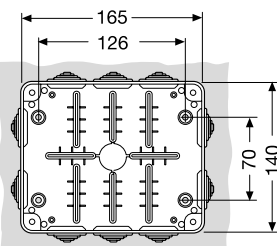

1SL0824A00 - 1SL0830A00  
1SL0874A00 - 1SL0854A00  
1SL0860A00 - 1SL0880A00  
1SL0924A00  
1SL0954A00  
1SL0960A00

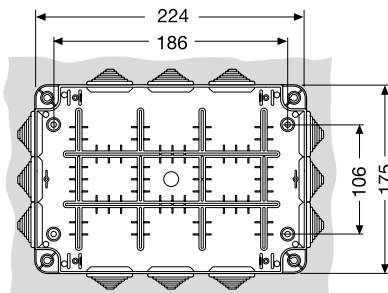

1SL0826A00 - 1SL0832A00  
1SL0876A00 - 1SL0856A00  
1SL0862A00 - 1SL0884A00  
1SL0926A00  
1SL0956A00  
1SL0962A00

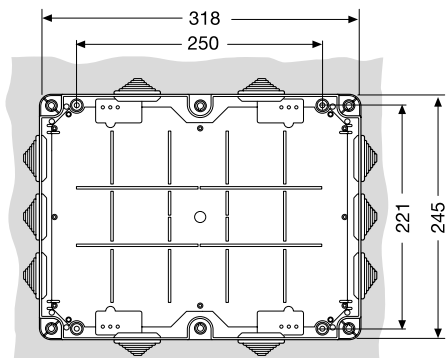


1SL0828A00 - 1SL0834A00  
1SL0878A00 - 1SL0858A00  
1SL0864A00 - 1SL0884A00  
1SL0928A00  
1SL0958A00  
1SL0964A00


## Junction boxes - technical details

IP 65 junction boxes in polycarbonate


### Front view

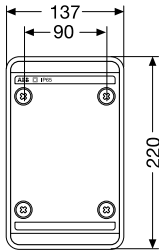


12 804

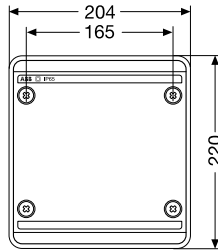


12 808

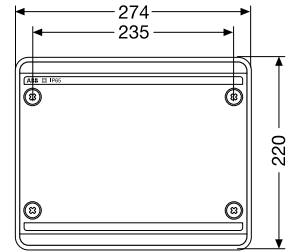


12 812

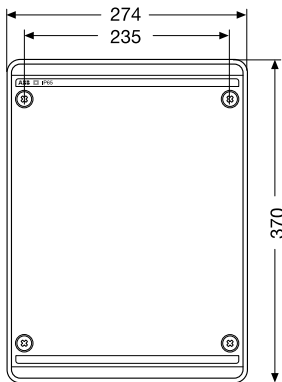

12 814

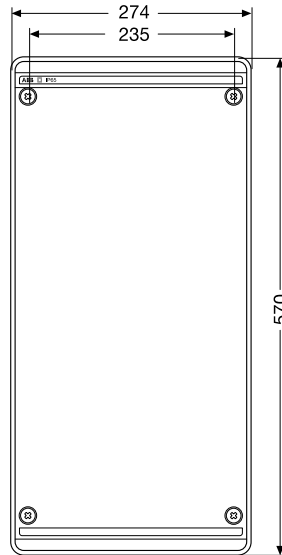


12 816

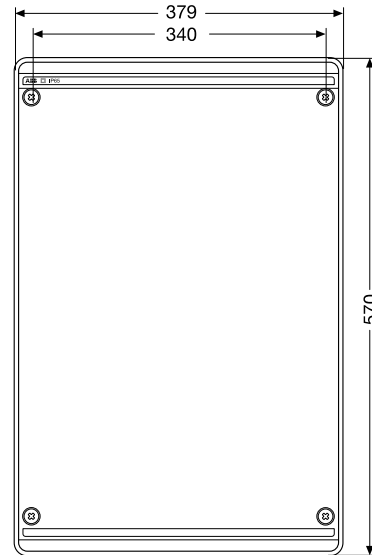


12 818


### Side view

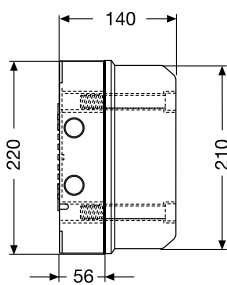

12 804 - 12 808 - 12 812

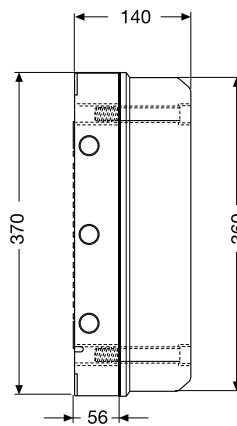

12 814

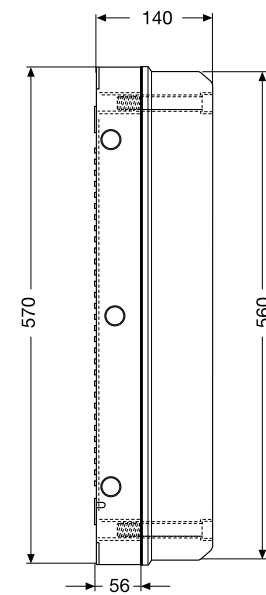


12 816 - 12 818


## Junction boxes - technical details

IP 65 junction boxes in polycarbonate


### Drilling sheet

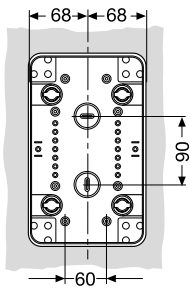


12 804

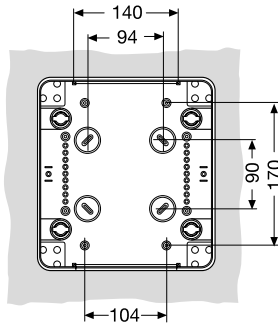


12 808

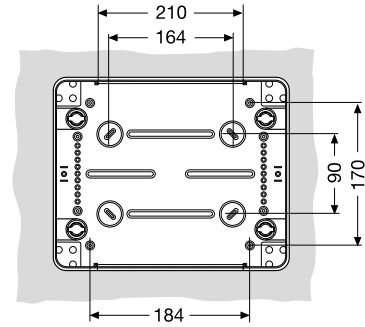


12 812

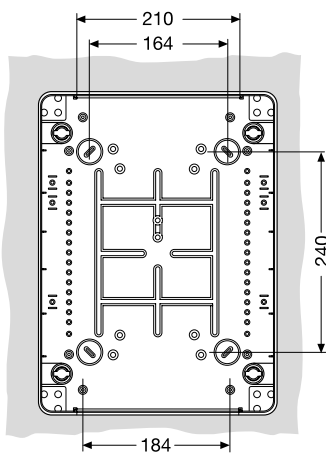

12 814

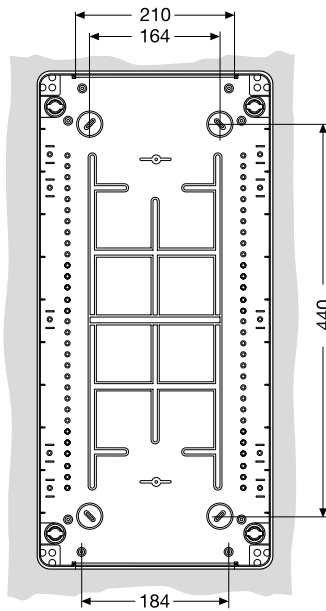

12 816

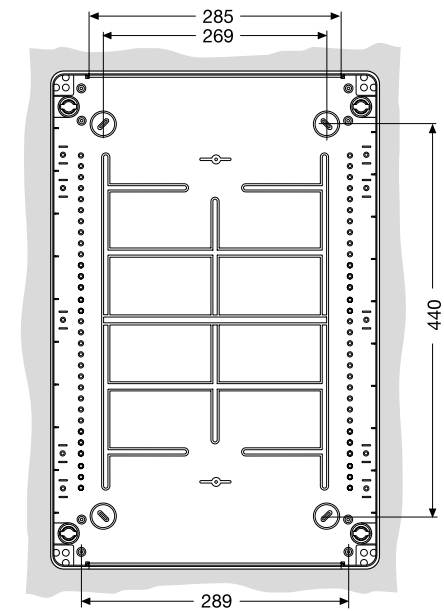

12 818