

Cordona

Elegant LED lighting



IP65 decorative emergency LED luminaire

- LED light source/optional fluorescent
- Designed for escape route and open area lighting
- Polycarbonate luminaire body with clear or translucent diffuser
- ELR/SLR exemption for luminaires with Emergency as the primary function
- Semi-recessing accessory available
- Complies to IEC 60598.2.22 and IEC 60598-1
- Available in Opal and Clear diffuser



Luminaire


Order code	Description	Input voltage	Lamp type	Lamp output (lm)	Power consumption (VA/W)	Operation / duration (hrs)	Environment temp. (°C)	Weight (kg)
CPW1LA1	LED 2D WH/OPL-OPT HF	110-230 AC/DC 0-60Hz	1 x LED 20W	1830	20.8 / 19.5	230V	0-40	1.8
CPW1LA11	LED 2D WH/CLR-OPT HF	110-230 AC/DC 0-60Hz	1 x LED 20W	2355	20.8 / 19.5	230V	0-40	1.8
CTCPW4LA1	LED 2D M3 WH/OPL-OPT CT	220-240 AC 50/60Hz	1+1 x LED 20+2W	1830/207	25.8 / 23	3	0-30	2.2
CTCPW4LA11	LED 2D M3 WH/CLR-OPT CT	220-240 AC 50/60Hz	1+1 x LED 20+2W	2355/207	25.8 / 23	3	0-30	2.2
LTCCPW1LA1	LED 2D WH/OPL-OPT LTC	220-240 AC 50/60Hz	1 x LED 20W	1830	20.8 / 19.5	230V	0-40	1.9
LTCCPW1LA11	LED 2D WH/CLR-OPT LTC	220-240 AC 50/60Hz	1 x LED 20W	2355	20.8 / 19.5	230V	0-40	1.9
STCPW4LA1	LED 2D M3 WH/OPL-OPT SLFTST	220-240 AC 50/60Hz	1+1 x LED 20+2W	1830/207	25.8 / 23	3	0-30	2.2
STCPW4LA11	LED 2D M3 WH/CLR-OPT SLFTST	220-240 AC 50/60Hz	1+1 x LED 20+2W	2355/207	25.8 / 23	3	0-30	2.2



Accessories

Order code	Description
CPW/BZ	Semi-recessing bezel

See spacing tables on pages 130

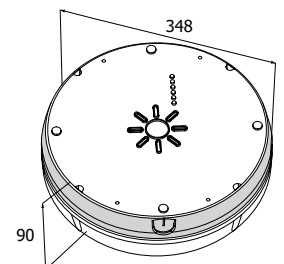

Ceiling cutout 346 mm when semi-recessing.