


# Serenga

In harmony with the interior

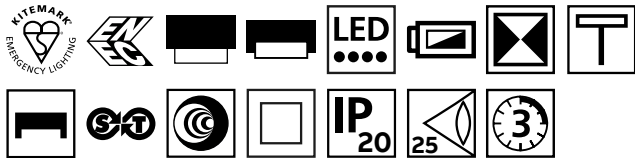

- LED escape route illumination, plastic frame, aluminium trim (C model = CURVED on both sides)**
- 2 surface mount orientations
  - 4 LED exit sign with downlighters or 2 LED exit sign
  - First-Fix with optional mounting accessories
  - High grade polycarbonate body with aluminium trim
  - Complies to BS EN 60598.2.22



## Control assembly

Order code	Description	Input Voltage	Operation / Environment duration (hrs)	temp. (°C)	Weight (kg)
SER-M3-003	Control module & battery pack	220 - 240 AC 50Hz	3	5-25	0.8
CTSER-M3-003	Control module & battery pack, CT version	220 - 240 AC 50Hz	3	5-25	0.9
CTSER-M3V2-003	Control module & battery pack, CT version	220 - 240 AC 60Hz	3	5-25	0.9
IR2SER-M3-003	Control module & battery pack, IR2 version	220-240 AC 50 Hz	3	5-25	0.9
SER-M3V2-003	Control module & battery pack	220 - 240 AC 60Hz	3	5-25	0.8
SER-230-003	Control module mains	85 - 240 AC/DC 50/60Hz	230V	0-40	0.8
SER-230LTC-003	Control module, LTC version	85 - 240 AC 50/60Hz	230V	0-40	0.8

## Smart-Frame

Order code	Description	Lamp type	Power consumption self contained (VA/W)	Power consumption slave (VA/W)	Weight (kg)
SER-FS2D	Smart frame 2 LED - curved face	2 x 1W LED	17.5 / 8.6	8.0 / 3.5	0.9
SER-FS4D	Smart frame 4 LED - curved face	4 x 1W LED			
SER-FS2DS	Smart frame 2 LED - curved face/ flag format	2 x LED 1W (Side wired)			
SER-FS4DS	Smart frame 4 LED - curved face/ flag format	4 x LED 1W (Side wired)			

ISO 7010 pictogram legends are shown. Euro format & Special legends are available to order see pages 138-141.

## Legends

Part No.	Pictogram
<b>ISO 7010 legend format</b>	
SER-SCN10	
SER-SCN11	
SER-SCN12	
SER-SCN13	
<b>Arabic legend format</b>	
SER-SCB01	
<b>Safety signs</b>	
SER-SC802	
SER-SC803	

## Accessories

Order code	Pictogram
SER-BZKIT	
SER-RKIT150	
SER-RKIT300	
SER-RKIT500	
SER-RKIT1000	

