

## Contact us

### ABB Oy

P.O. Box 622  
FI-65101 Vaasa  
Finland



[abb.com/lowvoltage](http://abb.com/lowvoltage)

© Copyright 2023 ABB. All rights reserved.  
Specifications subject to change without notice.


34OT\_G2-34 rev. A/ 1SCC301134M0201 # 20.11.2023




## OT Plus OT63...100G2-

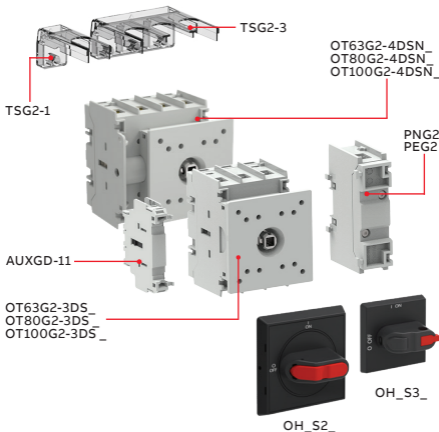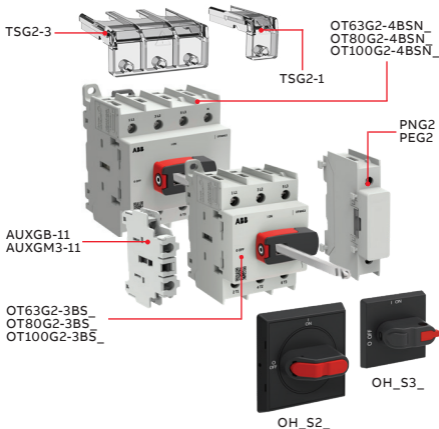


## Mounting

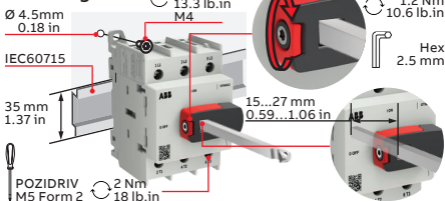

## Padlock

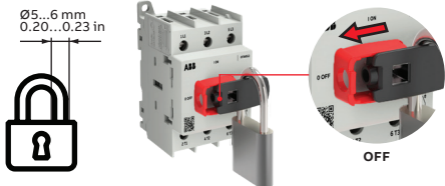

## Adjustable neutral pole timing

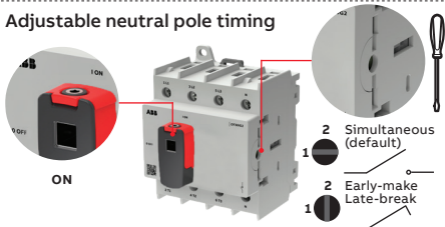

## Clearances per UL60947-4-1



Wire type	1 Wire (mm <sup>2</sup> )	2 Wire (mm <sup>2</sup> )	Stripping length	Tightening torque
Class 5-Flexible	1.5-35	1.5-16		
Class 2-Stranded	1.5-35	1.5-16		
Class 6-Very flexible with ferrule	1.5-4	1.5-4	13-16 mm 0.51-0.63 in	2 Nm 18 lb.in
Class 1-Solid	1.5-6	1.5-6		
UL - CU wire size (AWG)	16-2	16-8		



 Warning! Hazardous voltage! Installation by person with electrotechnical expertise only.

