

**PANEL MARKS:**

**RNSB12G9645A**

**TECHNICAL SPECIFICATIONS**

PANEL TYPE: ReliaGear neXT SuperBox  
 QUANTITY: 1  
 AMPS: 1200A  
 VOLTAGE: Up to 600V  
 SYSTEM: 3P3W or 3P4W  
 KAIC: Up to 200 KAIC SC FULLY RATED  
 MATERIAL: COPPER BUS  
 PLATE: SILVER PLATE  
 ENCLOSURE: NEMA 1  
 MOUNTING: SURFACE

**MAIN DISCONNECT DEVICE**

FEED DIR. Bottom  
 TYPE: Breaker  
 AMPS: 1200A  
 POLES: 3

**INTERIOR X-VALUES**



TOTAL X BUS 32 AVAILABLE X BUS 32

**OPTIONS INCLUDED**

QTY DESCRIPTION  
 1 Copper Bus Heat Rated  
 1 47 Ckt bonded grd

**BOM**

QTY	CAT #	DESCRIPTION
1	GDBG47AL	Ground
1	IN3212NN3H2	Bus
1	NL12I0G7X7BAL	Neutral
1	ER9645A	Enclosure
1	IF3245F	Frame
1	FT45S00155	Front 1 of 2
1	FT45S00325	Front 2 of 2
1	GC45F32NNA	Gutter
1	300127626P445	GF Mounting Rail
9	SR03BF	Spacer
9	SR03BB	Spacer
2	SR02BF	Spacer
2	SR02BB	Spacer
1	SR01BF	Spacer
1	SR01BB	Spacer

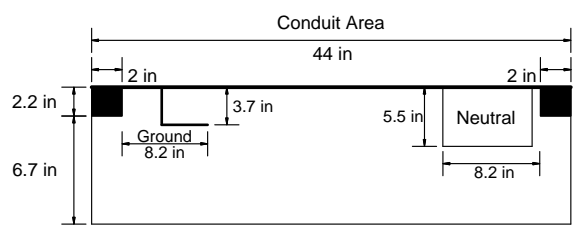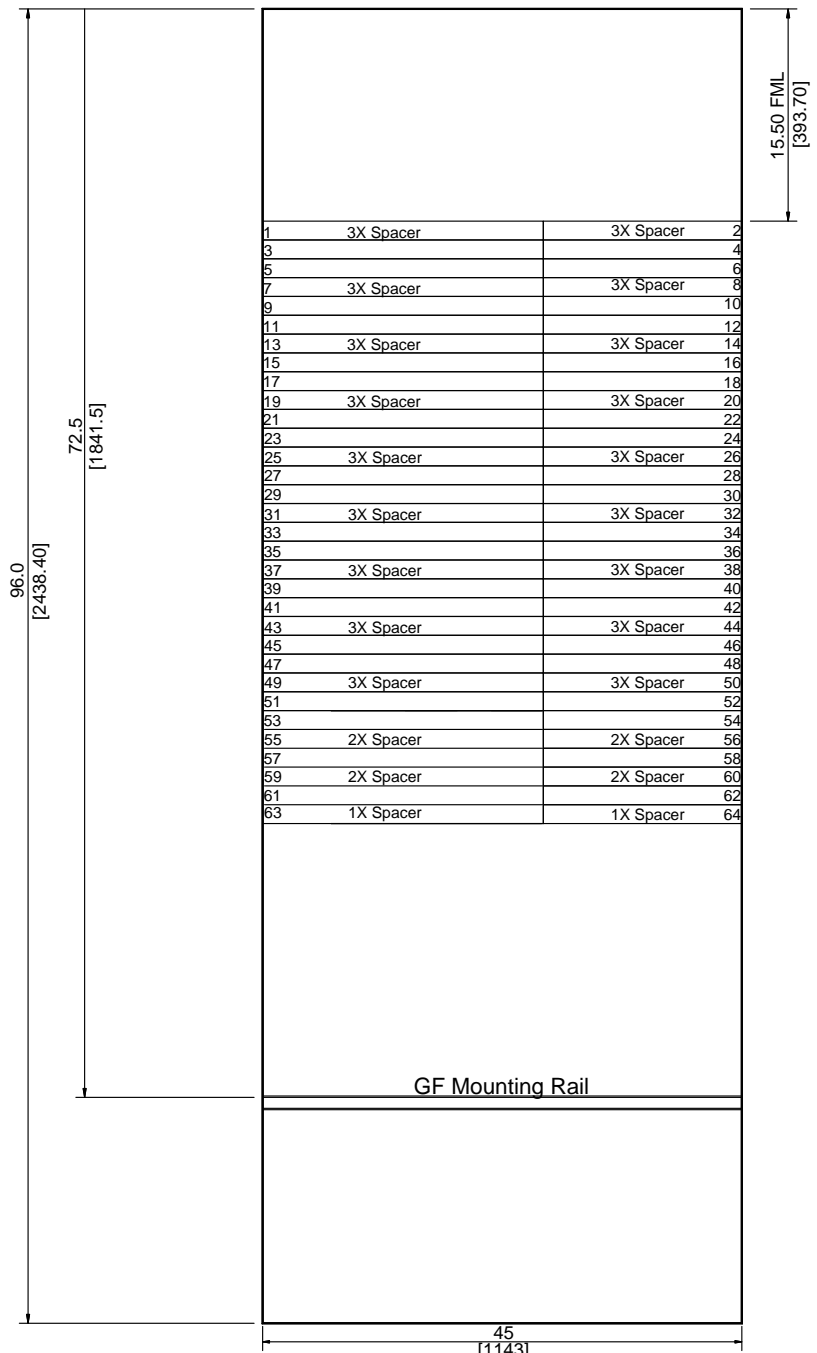

<b>PANEL INFORMATION</b>	
INTERNAL DIMENSIONS	96"X45"X11"
NOTES	
EXTERNAL DIMENSIONS	96.3"X45.7"X11"

1. FML - FRAME MOUNTING LOCATION.
2. DRAWING NOT TO SCALE.
3. DIMENSIONS ARE IN INCHES[mm].

NEUTRAL ARE PRESSURE LUGS.

PROJECT NAME :  
 CUSTOMER:



PANEL ID:  
 CREATED BY:  
 DATE:  
 REVISION NO.

PRODUCT NAME:  
**ReliaGear neXT  
 PANELBOARD**

DRAWING NO:  
 ITEM NO:  
 MARKS:  
 QUOTE NO:  
 SHEET: