

# Spitfire® LED Signature Spitfire LED recessed Nexus® non-maintained



## Range


Signature range

## Product group

Spitfire® LED

## Features

- 3 year warranty
- Superior photometric classification
- LED technology 100,000 hours lamp life
- Single or dual LED option
- High temperature NiCad batteries
- Nexus® monitored, either cabled or wireless
- Spring fixing design allows for different ceiling thickness (1mm-20mm)
- White adaptors included to convert standard 60mm lamp head to 85mm diameter and 141 diameter size
- White square adaptor available for standard lamp head
- Metal trim covers available in black or natural stainless steel finish for standard round and square lamp heads
- Metal trim covers can also be painted to any colour

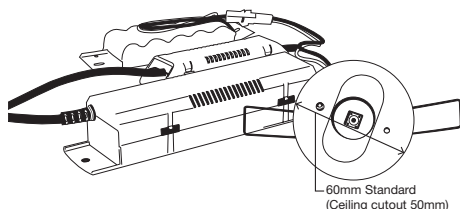

## Nexus products

Catalogue no.	Description
SFNXS1LED	LED Spitfire single Nexus LX recessed
SFNXS2LED	LED Spitfire dual Nexus LX recessed
SFNRF1LED	LED Spitfire single Nexus RF recessed
SFNRF2LED	LED Spitfire dual Nexus RF recessed

## Accessories

Catalogue no.	Description
02-SF1LSSTRIM	Single LED round trim stainless steel
02-SF1LBLTRIM	Single LED round trim black
02-SF2LSSTRIM	Dual LED round trim stainless steel
02-SF2LBLTRIM	Dual LED round trim black
02-SF1LSQSSTRIM	Single LED with square adaptor trim stainless steel
02-SF1LSQBLTRIM	Single LED with square adaptor trim black
02-SF2LSQSSTRIM	Dual LED with square adaptor trim stainless steel
02-SF2LSQBLTRIM	Dual LED with square adaptor trim black
02-SFLEDSQADAPT	White plastic square adaptor for LED Spitfire
02-SFLEDLGBLKIT	Black adaptor kit
SFLEDVWR-KIT	Vandal resistant and weather resistant kit to suit the 60mm recessed head

## Spare parts

Catalogue no.	Description
03-01220	Battery 5 cell NiCad 6.0V 1.8Ah

## Dimensions

Lamp head	Ceiling cutout
60mm standard	50mm
85mm adaptor	70mm
141mm adaptor	130mm

## Weight

Model	Weight
Nexus LX/RF	1.0kg

## Construction

Part	Construction
Lamp head	White polycarbonate

## Light source

Model	Light source
Single LED	2W
Dual LED	3W

## Power consumption

Model	Power consumption
Nexus LX/RF	5.1W


## Photometrics

Model	Class	Classification
Single LED	C0	D40
	C90	D40
Dual LED	C0	D50
	C90	D50

**Note:** Designed to comply with AS2293 and meet relevant Australian EMC standards

## Spitfire LED lamp head options

### Supplied with product

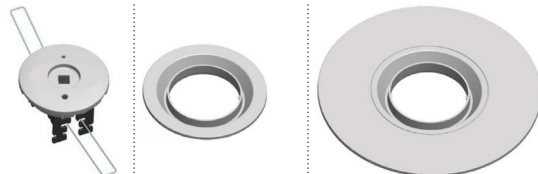

60mm lamp head

85mm adaptor

141mm adaptor

### Black adaptor




60mm lamp head

Round trim black  
02-SF1LBLTRIM  
02-SF2LBLTRIM

Black adaptor kit  
02-SFLEDLGBLKIT

### Round trims

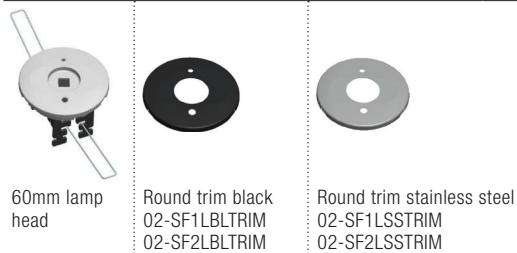

60mm lamp head

Round trim black  
02-SF1LBLTRIM  
02-SF2LBLTRIM

Round trim stainless steel  
02-SF1LSSTRIM  
02-SF2LSSTRIM

### Square trims



60mm lamp head

White square adaptor  
02-SFLEDSQADAPT

Square trim black  
02-SF1LSQBLTRIM  
02-SF2LSQBLTRIM

Square trim s/steel  
02-SF1LSQSSTRIM  
02-SF2LSQSSTRIM

**Note:** All trims clip over the face of the 60mm lamp head and all adaptors fit behind the 60mm lamp head

For more information please contact:

**ABB Australia Pty Limited**

Phone: 1800 60 20 20

E-mail: AU-ABB-Stanilite@abb.com

[www.stanilite.com.au](http://www.stanilite.com.au)

**Note:** We reserve the right to make technical changes or modify the contents of this document without prior notice. With regard to purchase orders, the agreed particulars shall prevail. ABB does not accept any responsibility whatsoever for potential errors or possible lack of information in this document.

We reserve all rights in this document and in the subject matter and illustrations contained therein. Any reproduction, disclosure to third parties or utilisation of its contents – in whole or in parts – is forbidden without prior written consent of ABB.

Copyright © 2017 ABB  
All rights reserved