



| AVAILABLE HUB PART NUMBERS | | | | | | | |
|----------------------------|---------------------------|------|-----------------|-------|------|------|------|
| CONDUIT SIZE | UNIVERSAL HUB CATALOG NO. | MOD# | A-THD | B-DIA | C | D | E |
| 3/4 | TC75 | 2 | 3/4" - 14 | 1.31 | 0.81 | 1.03 | 3.31 |
| 1 | TC100 | 2 | 1" - 11 1/2 | 1.53 | 0.69 | 1.03 | 3.31 |
| 1 1/4 | TC125 | 2 | 1 1/4" - 11 1/2 | 1.88 | 0.53 | 1.03 | 3.31 |
| 1 1/2 | TC150 | 2 | 1 1/2" - 11 1/2 | 2.12 | 0.42 | 1.03 | 3.31 |
| 2 | TC200 | 2 | 2" - 11 1/2 | 2.62 | 0.20 | 1.03 | 3.31 |
| 2 1/2 | TC250 | 2 | 2 1/2" - 8 | 3.19 | NONE | 1.22 | 3.31 |
| CLOSING CAP | TCCP | 1 | NONE | NONE | NONE | 0.25 | 3.38 |

FRONT VIEW (DOORS OPEN CONDITION)


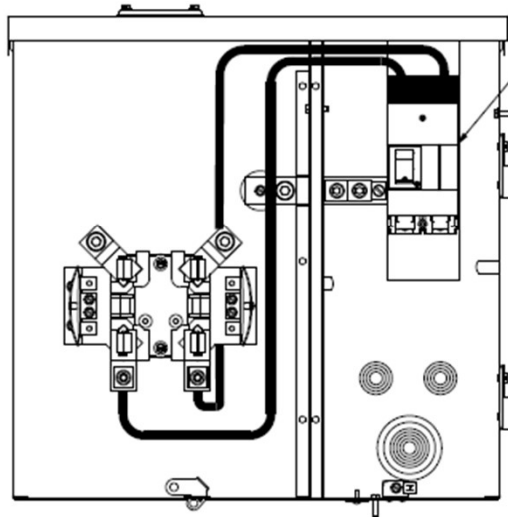


200 AMP BOLT-IN CIRCUIT BREAKER

HUB CLOSING CAP

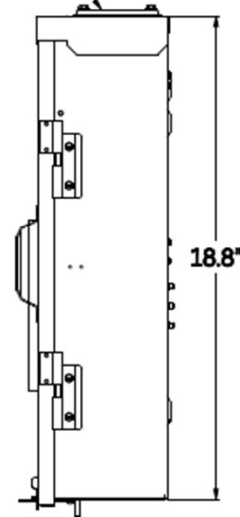

FRONT LAYOUT VIEW (DOORS CLOSED CONDITION)

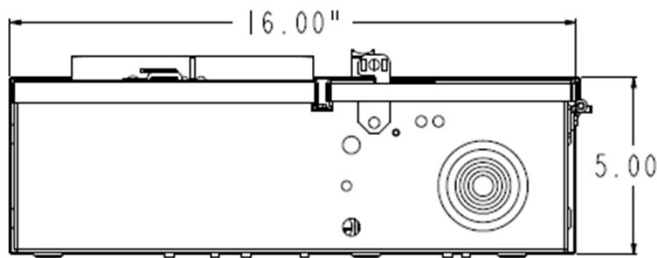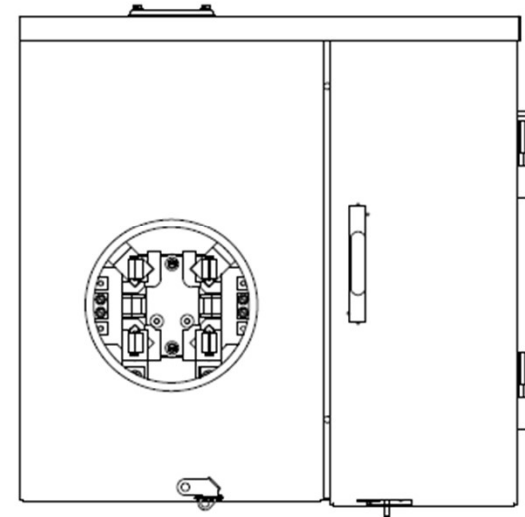

**MAIN WIRE SIZE
(1)#2-250MCM**



Main Breaker A2 - Ringless - 200A 10K - 0/0 Circuits - N3R Encl
Surface Front - UG/OH Incoming Feed - GP Listed

| CAT NO | DWG DATE | REV # |
|-------------|------------|-------|
| TSMR020CSGP | 12/14/2020 | 01 |