


—
INSTALLATION INSTRUCTION

Fourth pole


OTP_40FPN2, OTP_40FDN1

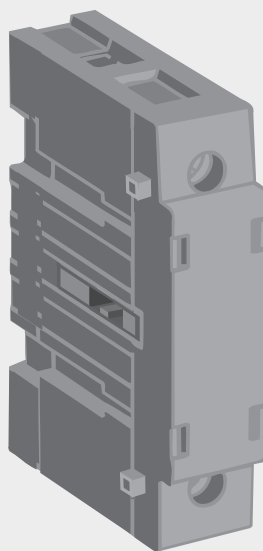


OTP_40FPN2

OTPS40FDN1

7(N) L4
8(N) T4

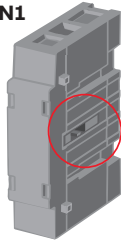

OTPL40FD

 


UL US IND. CONT. EQ 9E73
 General Use Ratings
 600 VAC 40 A
 Listed for use with
 OT16FT3, OT25FT3,
 OT40FT3

UL not completed
OTPL40

OT16FT3, OT25FT3, OT40FT3

OTPS40FDN2

OTPS40FDN2


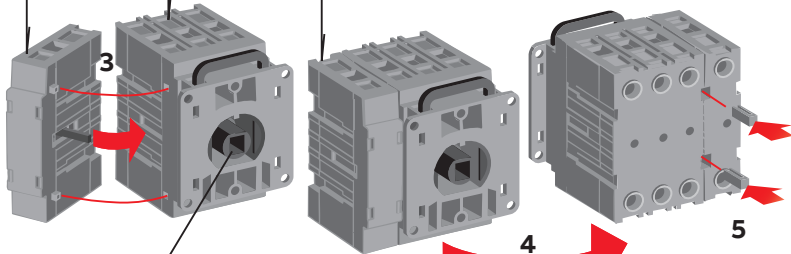


1


9-10 mm
0.35-0.39 in

0,75...10 mm²
18...8 AWG

  Note:
0,75 mm²
18 AWG



6

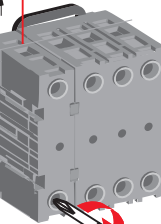


0,8 Nm
7 lb.in

POZIDRIVE
M3,5 Form 2


OTP_40FDN2

OTPS40FPN2

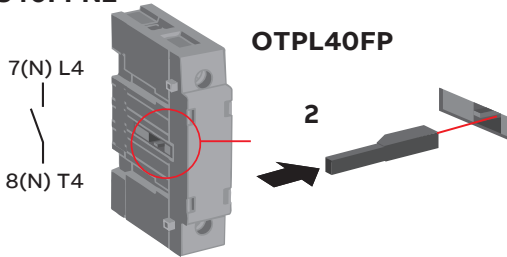

UL IND.CONT.
EQ 9E73
General Use Ratings
600 VAC 40 A
Listed for use with
OT16F3, OT25F3,
OT40F3
UL not completed
OTPL40

OT16F3, OT25F3, OTPS40FPN2 OT40F3

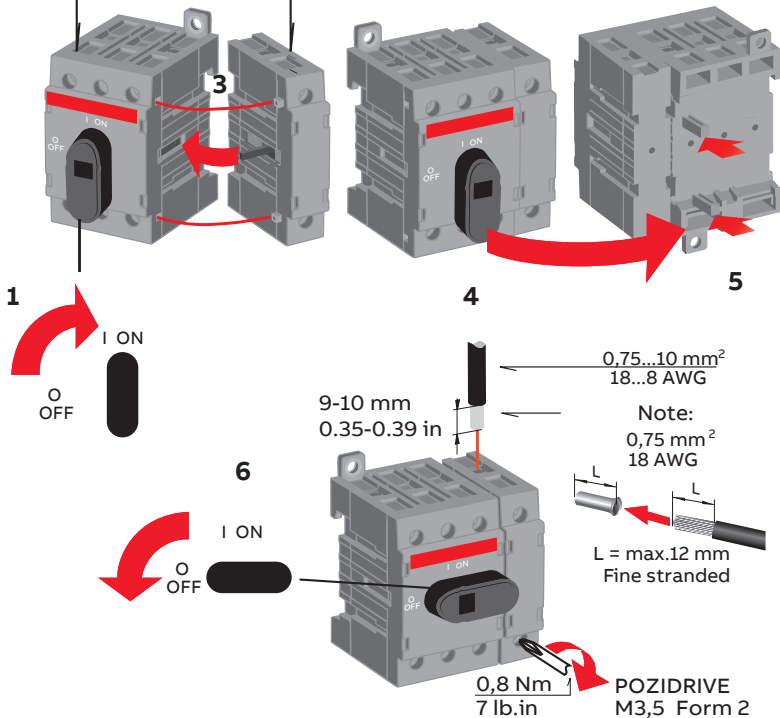



Contact us

ABB Oy

Muottitie 2A 65320

Vaasa, Finland

abb.com/lowvoltage