


Guideway

Innovative & stylish

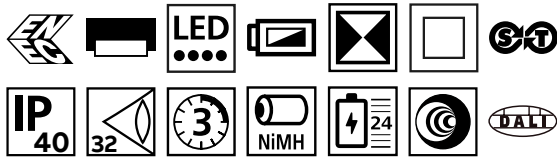

Guideway 32m - Recessed

- Bright and uniformed light distribution with 500 cd/sq.m
- Versatile mounting options with First-Fix control gear
- Unique frameless legend design with click-lock assembly
- Quick release legend panels

Luminaire

Order code	Description	Input voltage	Lamp type	Power Operation		Environment temp. (°C)	Weight (kg)	Including
				consumption (VA/W)	/ duration (hrs)			
CTEGR3LS1-S32	REC LED SIGN M3 CT-TST 32M	220-240 AC 50Hz	1 x LED 4W	7.1 / 6.5	3	5-35	1.5	
EGR1LS1D-S32	REC LED SIGN CPS 230DIM 32M	220-240 AC/DC 0-60Hz			230V	0-35	1.5	
EGR1LS1LTC-S32	REC LED SIGN CPS LTC 230 VAC 32M	220-240 AC 50/60Hz		230V	0-35	1.5		
EGR1LS1-S32	REC LED SIGN CPS 230 VAC 32M	220-240 AC/DC 0-60Hz		230V	0-35	1.5		
EGR3LS1-S32	REC LED SIGN M3 32M	220-240 AC 50Hz		3	5-35	1.5		
DAEGR3LS1-S32	REC LED SIGN M3 32M DALI	220-240 AC 50Hz		3	5-35	1.5		

60 hrs charge at first commissioning, 24 hrs re-charge thereafter
Add '-00' for product without legends

Single sided

Part No.	Legends
ISO 7010 legend format	
XEN2EG32	
XEN3EG32	
XEN6EG32	
XEN5EG32	
XEN0G32	
Arabic legend format	
XBN1EG32	

ISO 7010 pictogram legends are shown
Euro format & Special legends are available to order see pages 139-141

Accessories

Order code	Description	Colour
EG-T4SG	Alu Cover discs, 2+2 self contained	
EG-T4VG	Alu Cover discs, 2+2 CPS	

Suspension kit accessories

Order code	Description
EG-TKIT50	Pendant 500
EG-TKIT100	Pendant 1000
EG-WKIT150	Wire suspension kit

Flag mounted

Part No.	Legends
ISO 7010 legend format	
XEN602EG32	
XEN603EG32	
XEN606EG32	
XEN605EG32	

