

*Lightalarms IC-2...
Combining Great Looks,
Performance, and
Economy Into One
Ultra-Slim, Easy-To Install
Emergency Light.*



application: Aesthetically attractive, economical unit ideal for commercial or institutional facilities. Unit offers easy installation on either wall or ceiling, and reliable performance in a low-profile, contemporary design.

features

- **CONSTRUCTION:** Injection molded from high impact, scratch and corrosion resistant thermoplastic in an architecturally attractive "mist white" color.
- **QUICK, LABOR-SAVING INSTALLATION:** Simply wire the mounting plate to the building AC and secure. Then, using the AC quick-connect plug, snap the housing onto the mounting plate, and the unit is ready to be powered.
- **ELECTRONICS:**
 - Dual-voltage transformer.
 - Constant voltage, temperature compensated charger.
 - High reliability, automatic, instantaneous transfer.
 - Low voltage disconnect prevents damage to battery by over discharging.
 - Labor-saving AC line latch prevents battery discharge during installation to a non-energized circuit.
 - Brownout protection activates unit when AC power dips so low as to dim or extinguish normal area lighting.
 - Minimal components for improved reliability.

- **INSTRUMENTATION:**
 - Visual charge monitor LED indicates AC is present and battery is on charge.
 - Integrated momentary test switch allows for quick operational check of entire system.


- **POWER REQUIREMENTS:** 120/277 Volt AC.

battery
6 volt, maintenance free, sealed lead calcium

unit selection chart

Volts	Model #	Capacity in Watts to 87 ¹ / ₂ % Of Nominal Battery Voltage	
		1 1/2 Hours	2 Hours
6	IC-2	12	8

dimensions Dimensions are approximate and subject to change.

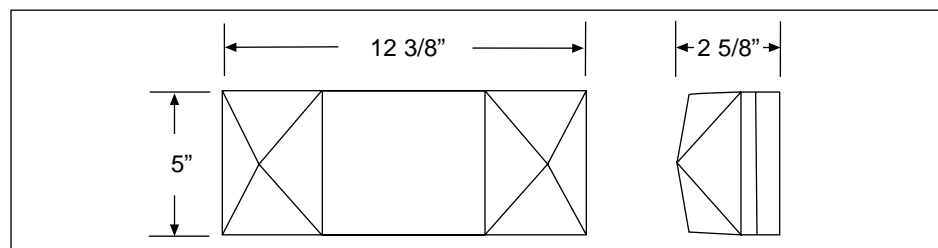

lamps

Standard with two 5.4-watt, high intensity wedge base incandescent lamps. Choice of lamp locations offers optimum lighting placement for either corridor or forward illumination.

options

(Add suffix to model number) Suffix
3-wire cord & plug (120) 3CP

accessories

(Order as separate item) Model
Guard WG13

Note: Certain option combinations may effect the UL listing. Please contact the factory for specifics.