


Guideway

Innovative & stylish



Guideway 32m - Surface

- Bright and uniformed light distribution with 500 cd/sq.m
- Versatile mounting options with First-Fix control gear
- Unique frameless legend design with click-lock assembly
- Quick release legend panels

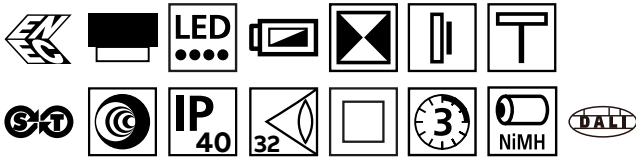

Luminaire

Order code	Description	Input voltage	Power Operation		Environment temp. (°C)	Weight (kg) including
			Lamp type	consumption / duration (VA/W) (hrs)		
CTEG3LS1-S32	LED SIGN M3 CT-TST 32M	220-240 AC 50Hz	1 x LED	7.1 / 6.5	3	1.6
EG1LS1D-S32	LED SIGN SLAVE 230VAC DIM 32M	220-240 AC/DC 0-60Hz	4W		230V	
EG1LS1LTC-S32	LED SIGN SLAVE LTC 230VAC 32M	220-240 AC 50/60 Hz			230V	
EG1LS1-S32	LED SIGN SLAVE 230VAC 32M	220-240 AC/DC 0-60Hz			230V	
EG3LS1-S32	LED SIGN M3 32M	220-240 AC 50Hz			3	
DAEG3LS1-S32	LED SIGN M3 32M DALI	220-240 AC 50Hz			3	

Includes back to wall mounting accessory as standard
 60 hrs charge at first commissioning, 24 hrs re-charge thereafter
 Black versions available on request
 Add '-00' for product without legends

Single sided

Part No.	Legends
ISO 7010 legend format	
XEN2EG32	
XEN3EG32	
XEN6EG32	
XEN5EG32	
XEN0G32	
Arabic legend format	
XBN1EG32	

ISO 7010 pictogram legends are shown.
 Euro format & Special legends are available to order see pages 138-141.

Flag mounted

Part No.	Legends
ISO 7010 legend format	
XEN602EG32	
XEN603EG32	
XEN606EG32	
XEN605EG32	



Accessories

Order code	Description
EG-TKIT50	Pendant 500
EG-TKIT100	Pendant 1000
EG-WKIT150	Wire suspension kit

