


Guideway

Innovative & stylish



Guideway 22m - Recessed

- Bright and uniformed light distribution with 500 cd/sq.m
- Versatile mounting options with First-Fix control gear
- Unique frameless legend design with click-lock assembly
- Quick release legend panels

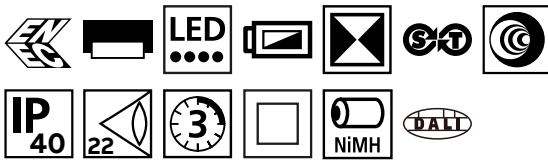

Luminaire

Order code	Description	Input voltage	Lamp type	Power consumption / duration		Environment temp. (°C)	Weight (kg)	Including
				(VA/W)	(hrs)			
CTEGR3LS1-S22	REC LED SIGN M3 CT-TST 22M	220-240 AC 50Hz	1 x LED	4.4 / 4	3	5-35	1.2	
EGR1LS1D-S22	REC LED SIGN 230DIM 22M	220-240 AC/DC 0-60Hz	2W		230V	0-35	1.2	
EGR1LS1LTC-S22	REC LED SIGN SLAVE LTC 230VAC 22M	220-240 AC 50/60 Hz			230V	0-35	1.2	
EGR1LS1-S22	REC LED SIGN SLAVE 230VAC 22M	220-240 AC/DC 0-60Hz			230V	0-35	1.2	
EGR3LS1-S22	REC LED SIGN M3 22M	220-240 AC 50Hz			3	5-35	1.2	
DAEGR3LS1-S22	REC LED SIGN M3 22M DALI	220-240 AC 50Hz			3	5-35	1.2	

60 hrs charge at first commissioning, 24 hrs re-charge thereafter
 Black versions available on request
 Add '-00' for product without legends

Single sided

Part No.	Legends
ISO 7010 legend format	
XEN2EG22	
XEN3EG22	
XEN6EG22	
XEN5EG22	
XEN0G22	
Arabic legend format	
XBN1EG22	

ISO 7010 pictogram legends are shown.
 Euro format & Special legends are available to order see pages 138-141.

Flag mounted

Part No.	Legends
ISO 7010 legend format	
XEN602EG22	
XEN603EG22	
XEN606EG22	
XEN605EG22	



Accessories

Order code	Description	Colour
EG-T4SG	Alu Cover discs, 2+2 self contained	
EG-T4VG	Alu Cover discs, 2+2 slave	

Suspension kit accessories

Order code	Description
EG-TKIT50	Pendant 500
EG-TKIT100	Pendant 1000
EG-WKIT150	Wire suspension kit

