


TECHNICAL DATA SHEET - INTERACTIVE PDF

Compression Tool, Manual

TBM4S Dieless crimp tool

T&B Tools

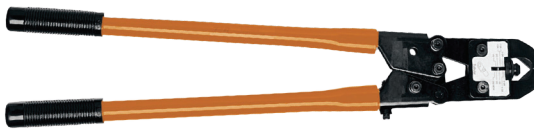

Manual dieless compression tool for use on compression lugs and splices.

3-Part Specification:
End User Tools

Features:

- Wide range of #8 AWG to 250 kcmil for copper lugs and #8 to 4/0 AWG for aluminum lugs
- Adjustable indenter eliminates the need to buy and maintain numerous individual dies
- Shure-Stake® mechanism helps ensure a properly completed crimp each time
- Easily adjusted by turning knurled adjusting wheel and aligning pointer with proper terminal size

 
Conforms to:

- UL 486A-B when used with Color-Keyed® connectors

Specifications:

- Weight: 5 lbs
- Dimensions: 24 ¼" L x 7/8" W x 3" H

Crimp style, indent:



tnb.abb.com (US/Latin America)
tnb.ca.abb.com (Canada)
abb.com

We reserve the right to make technical changes or modify the contents of this document without prior notice. With regard to purchase orders, the agreed particulars shall prevail. ABB does not accept any responsibility whatsoever for potential errors or possible lack of information in this document.

We reserve all rights in this document and in the subject matter and illustrations contained therein. Any reproduction – in whole or in part – is forbidden without prior written consent of ABB. © 2022 ABB Installation Products Inc. and/or its related companies. All Rights Reserved.