
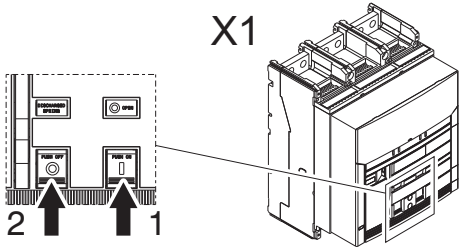
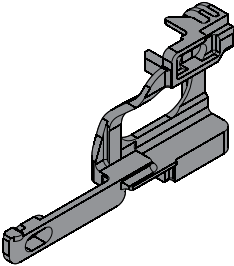
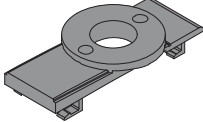
 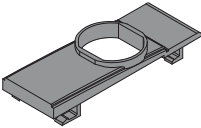



Emax - Tmax

DOC. N.° 1SDH000529R0662 - B1651


KLC - Predisposizione blocchi Profalux -Ronis - KIRK - Castell X1
KLC - Provision for Profalux -Ronis - KIRK - Castell lock X1
KLC - Vorbereitung für Schlüsselverriegelungen Profalux - Ronis - KIRK - Castell X1
KLC - Version pour verrouillages Profalux -Ronis - KIRK - Castell X1
KLC - Preinstalación bloques Profalux-Ronis - KIRK - Castell X1

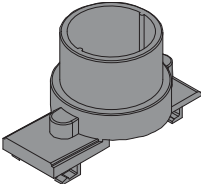

	PROFALUX	RONIS	KIRK	CASTELL		PROFALUX	RONIS	KIRK	CASTELL
	1	1	1	1		-	-	1	-
	1	1	1	1		-	-	2	-
	2	2	2	2		-	-	2	-
	2	2	2	2		-	-	-	1
	1	1	-	-		-	-	-	1
	1	1	-	-		-	-	-	2
	-	-	1	-		-	-	-	2
						-	-	-	1


A

PROFALUX - RONIS

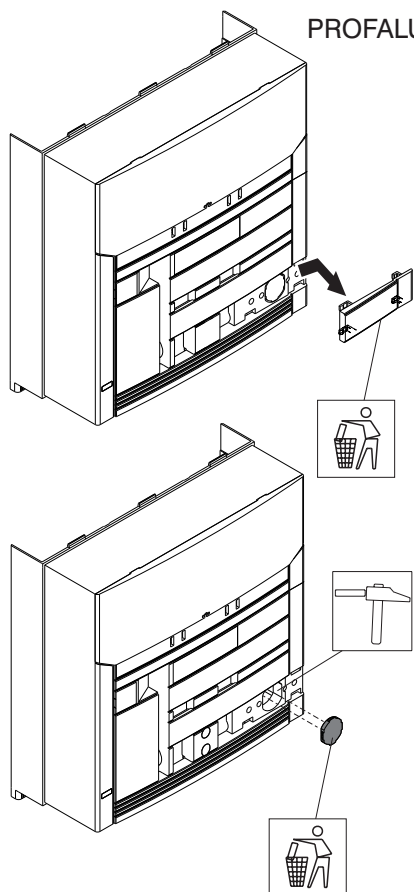


B

PROFALUX - RONIS

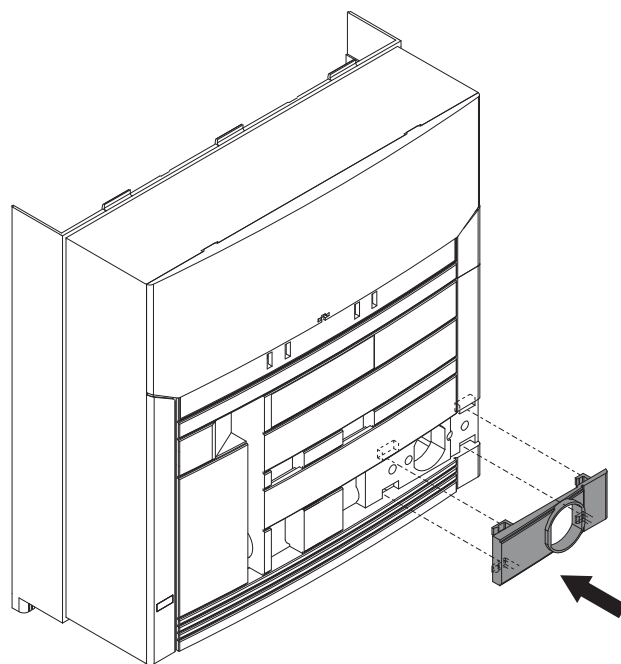

C


PROFALUX - RONIS

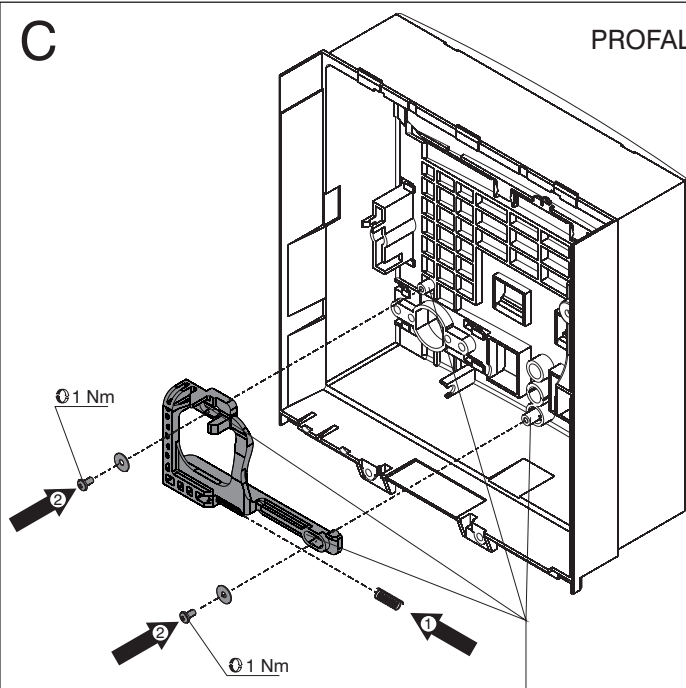


Lubrificare con grasso vaselina
 Lubrificate with vaseline grease
 Schmieren mit Fett Vaseline
 Lubrifier avec de la graisse vaseline
 Lubrificar con grasa vaselina

D

RONIS

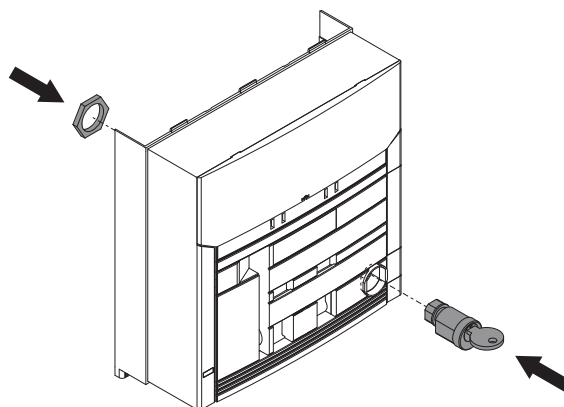

-Serratura Ronis tipo 1351 B; Rotazione camma 90°.
 Acquisto serratura a carico del cliente.
 -Ronis lock 1351 B with 90° cam rotation.
 Lock to be purchased by the customer.
 -Schloß Ronis Typ 1351 B; Nockendrehung 90°.
 Das Schloß muß vom Kunden erworben werden.
 -Serrure Ronis type 1351 B; rotation came 90°.
 Achat serrure à la charge du client.
 -Cerradura Ronis tipo 1351 B; Rotación de la leva 90°.
 Compra de la cerradura a cargo del cliente.

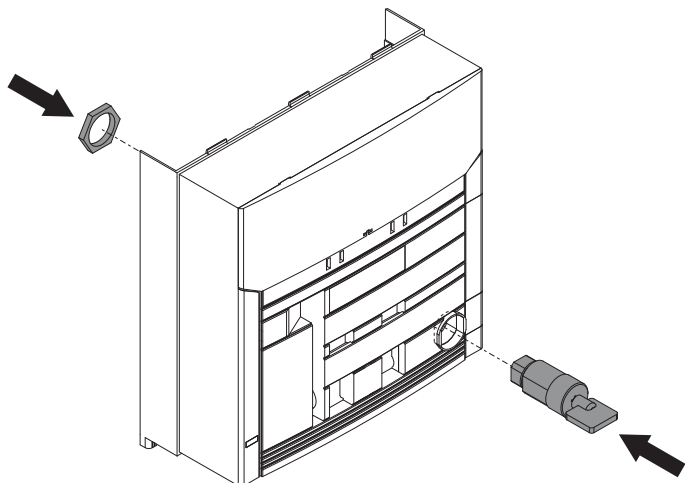E**PROFALUX**





-Serratura Profalux B 24D4Z; Rotazione camma 90°.
Acquisto serratura a carico del cliente.

-Ronis lock Profalux B 24D4Z with 90° cam rotation.
Lock to be purchased by the customer.

-Schloß Profalux B 24D4Z; Nockendrehung 90°.
Das Schloß muß vom Kunden erworben werden.

-Serrure Profalux type B 24D4Z; rotation came 90°.
Achat serrure à la charge du client.

-Cerradura Profalux tipo B 24D4Z; Rotación de la leva 90°.
Compra de la cerradura a cargo del cliente.

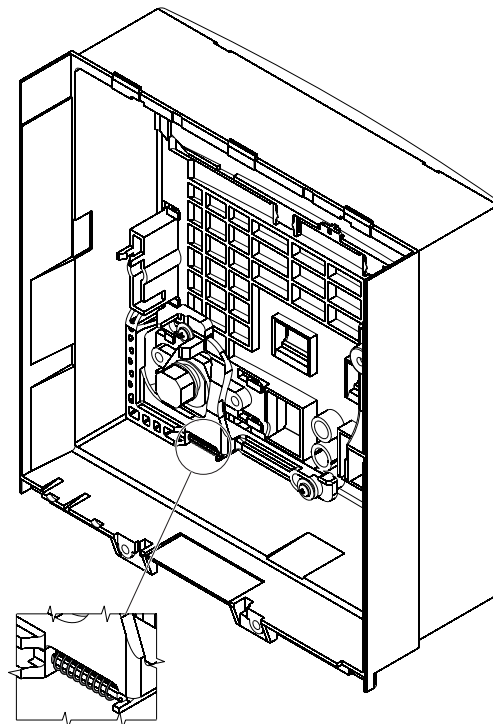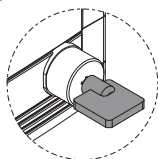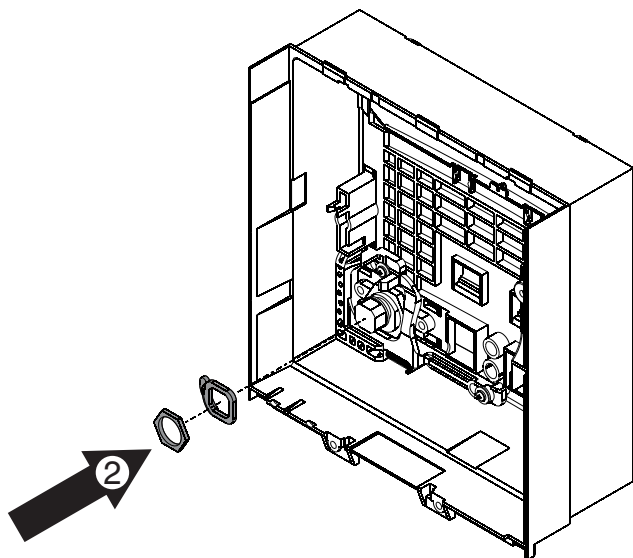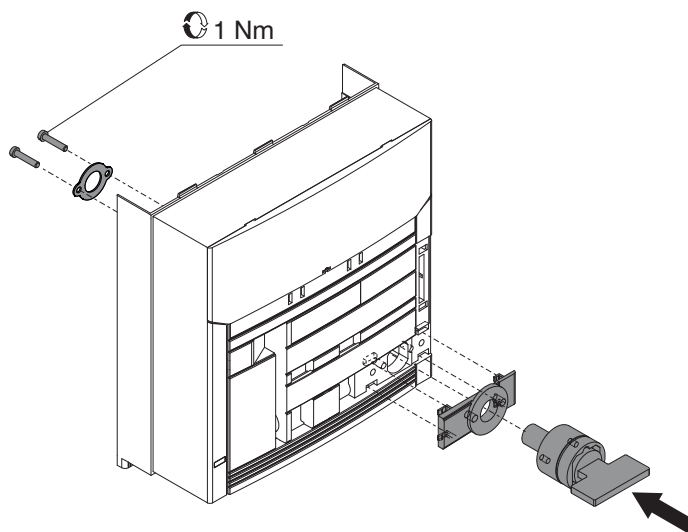F**PROFALUX - RONIS****G****PROFALUX - RONIS****1****2****H****CASTELL**




-Serratura Castell PSD0138 (s) REV2; Rotazione camma 90°.
Acquisto serratura a carico del cliente.

-Ronis lock Castell PSD0138 (s) REV2 with 90° cam rotation.
Lock to be purchased by the customer.

-Schloß Castell PSD0138 (s) REV2; Nockendrehung 90°.
Das Schloß muß vom Kunden erworben werden.

-Serrure Castell type PSD0138 (s) REV2; rotation came 90°.
Achat serrure à la charge du client.

-Cerradura Castell tipo PSD0138 (s) REV2; Rotación de la leva 90°.
Compra de la cerradura a cargo del cliente.

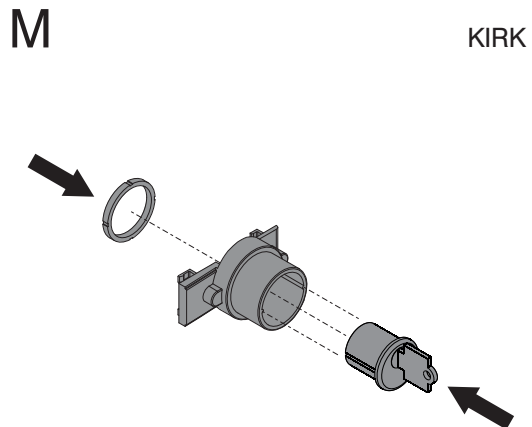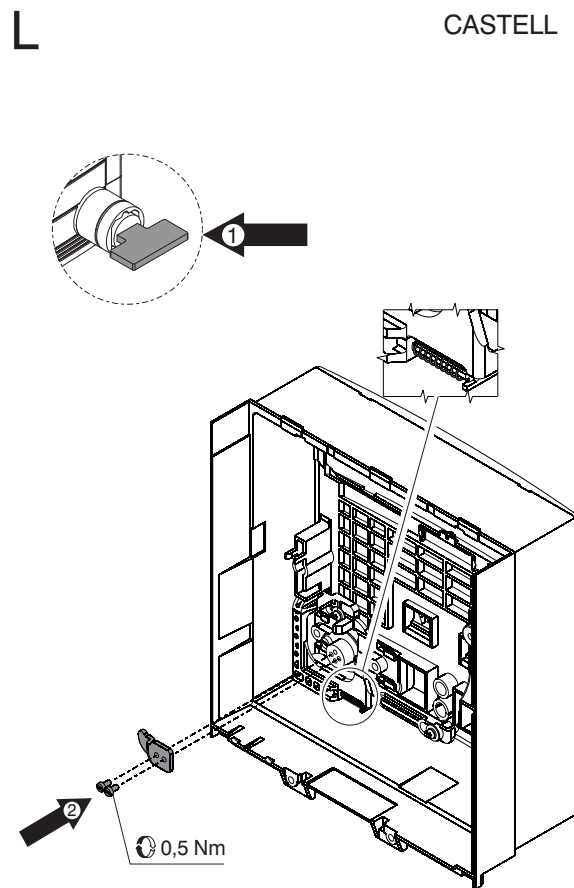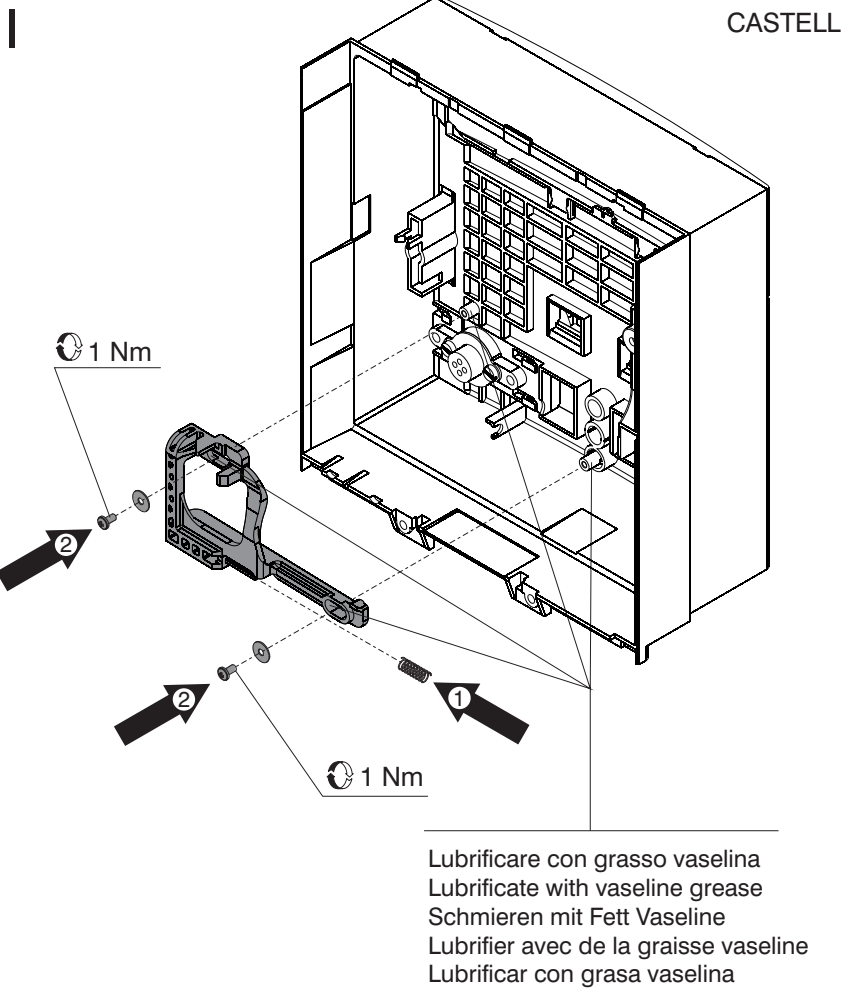


-Serratura Kirk CN22; Rotazione camma 90°.
Acquisto serratura a carico del cliente.

-Ronis lock Kirk CN22 with 90° cam rotation.
Lock to be purchased by the customer.

-Schloß Kirk CN22; Nockendrehung 90°.
Das Schloß muß vom Kunden erworben werden


-Serrure Kirk type CN22; rotation came 90°.
Achat serrure à la charge du client.

-Cerradura Kirk tipo CN22; Rotación de la leva 90°.
Compra de la cerradura a cargo del cliente.

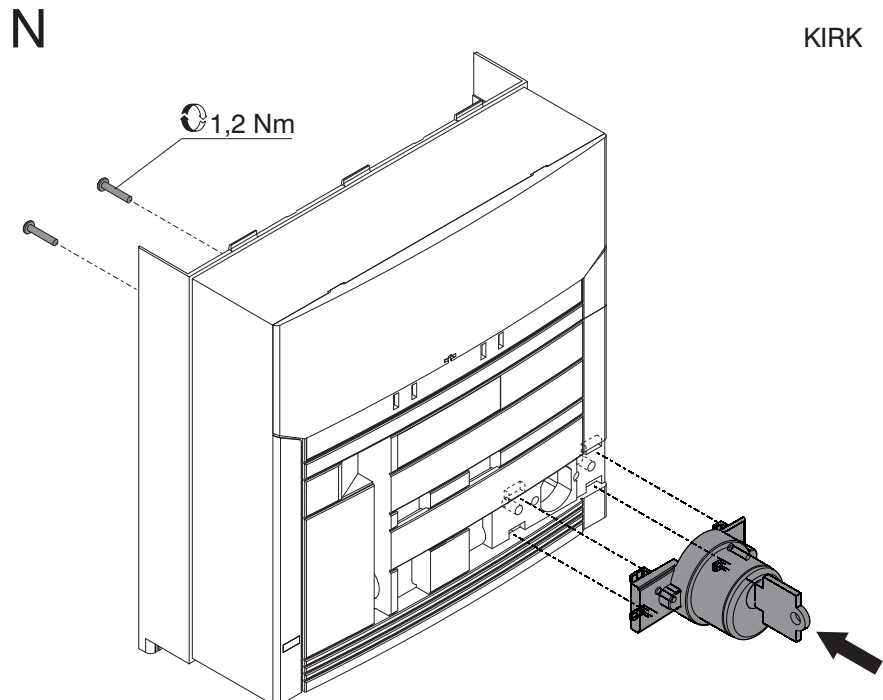

O


KIRK

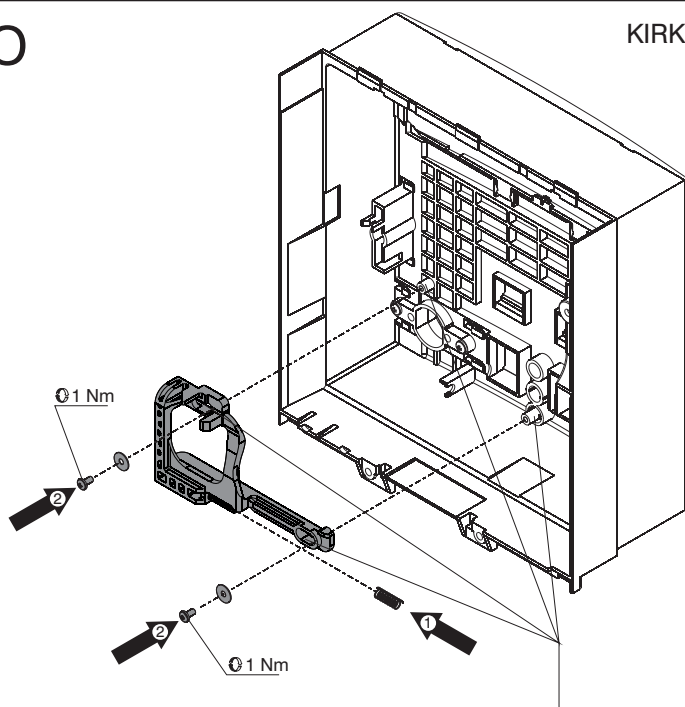

Lubrificare con grasso vaselina
 Lubricate with vaseline grease
 Schmieren mit Fett Vaseline
 Lubrifier avec de la graisse vaseline
 Lubrificar con grasa vaselina


P

KIRK

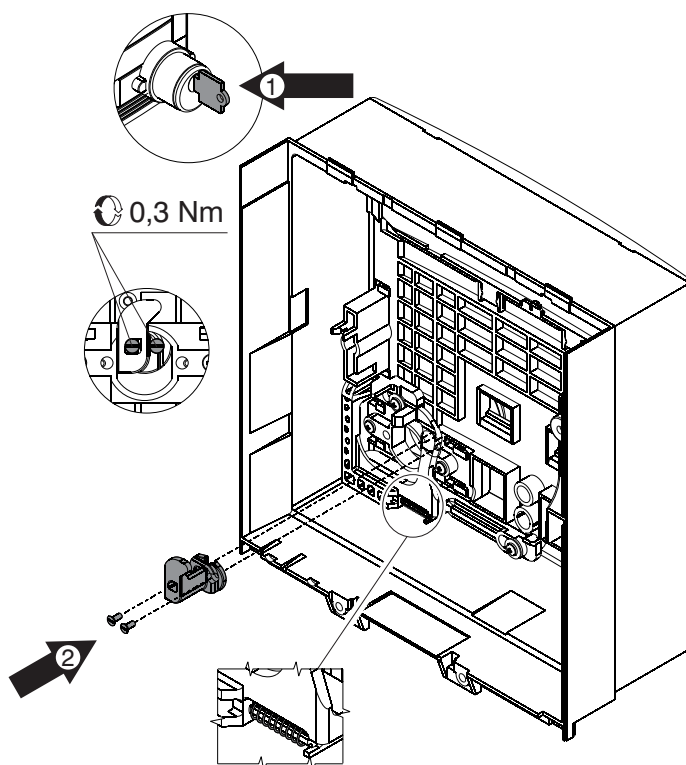


Q




PROFALUX - RONIS

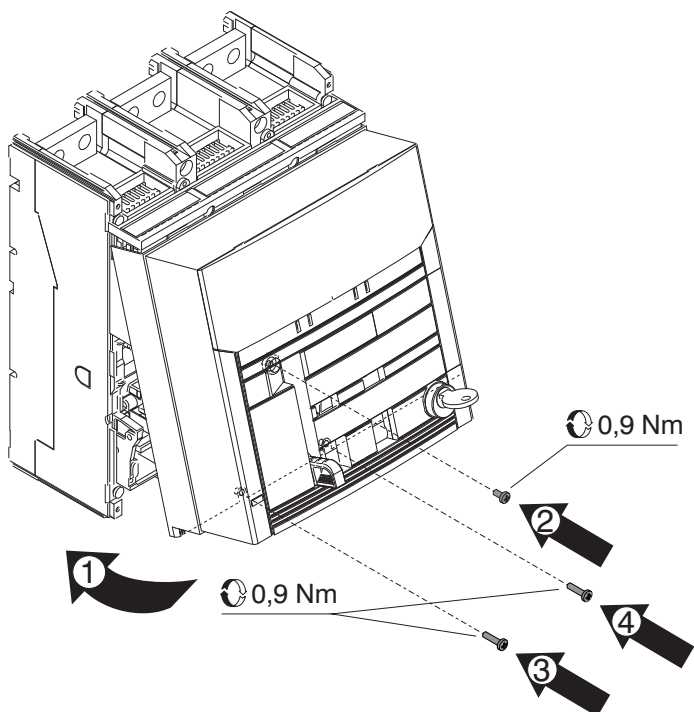

R

CASTELL

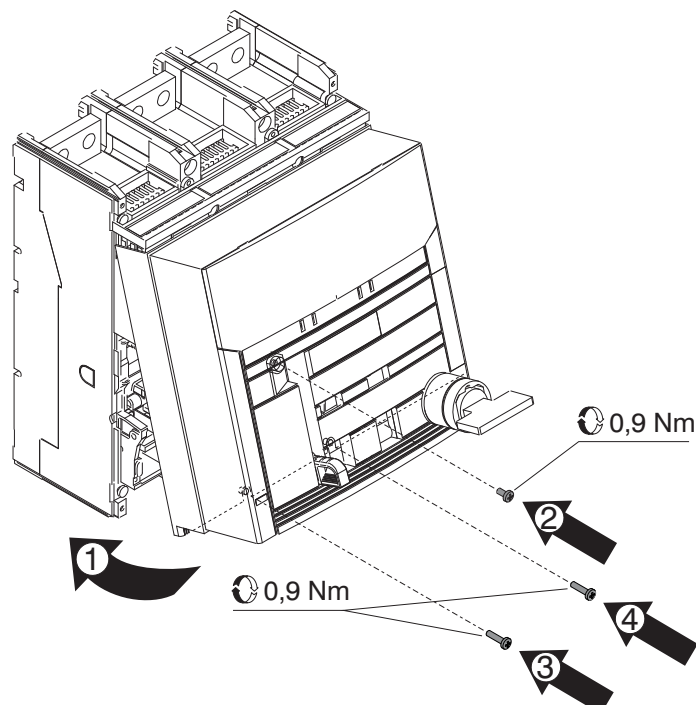

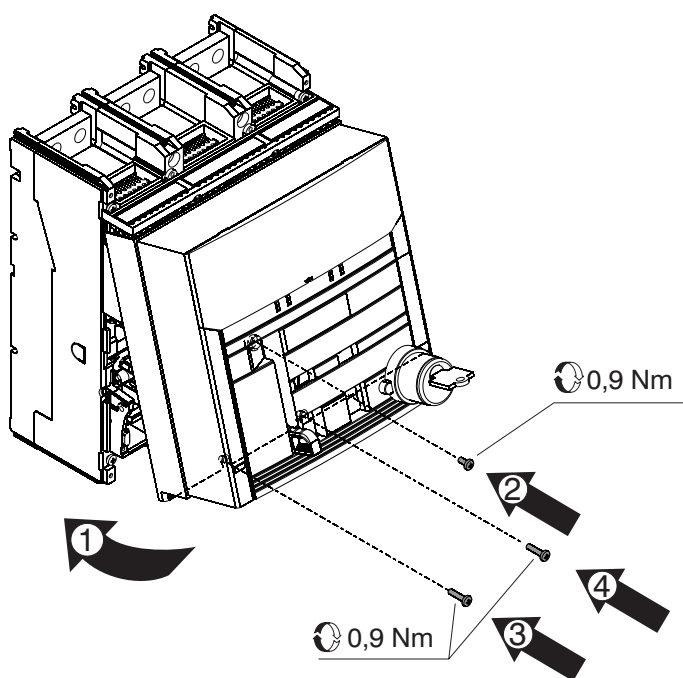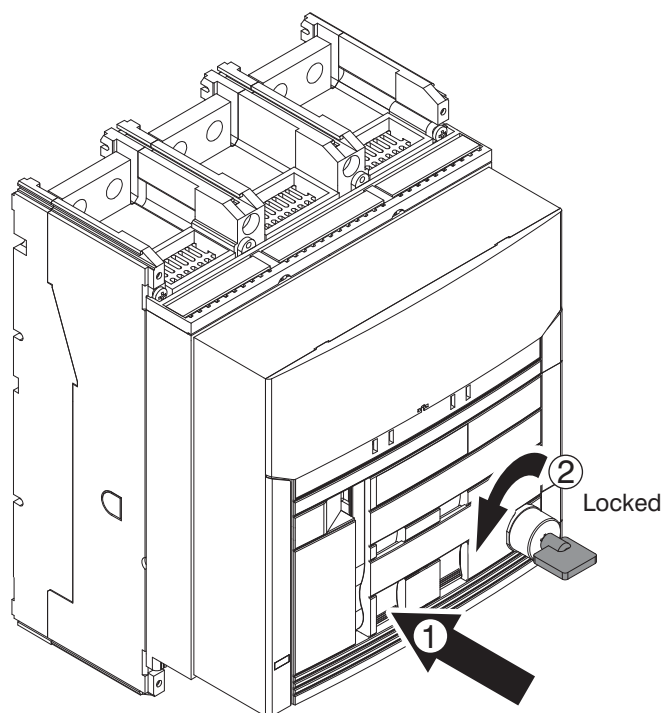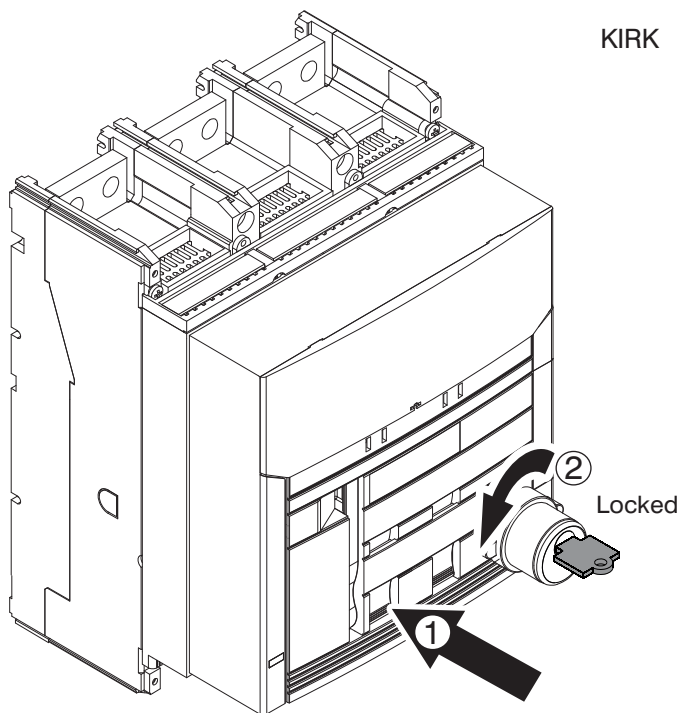S**KIRK****T****PROFALUX - RONIS****U****KIRK****V****CASTELL**