

PRODUCT SHEET

JSD-TK10-19


2TLA930058R0000

10 m cable with 19-pin M23 female connector.
To be used when connecting HD5-S-111 to a safety controller.

**Pin configuration**

No	Color	Conductor diameter
1	White	0,25 mm ²
2	Brown	0,25 mm ²
3	Green	0,25 mm ²
4	Yellow	0,25 mm ²
5	Grey	0,25 mm ²
6	Pink	0,25 mm ²
7	Blue	0,25 mm ²
8	Red	0,14mm ²
9	Black	0,14mm ²
10	Violet	0,14mm ²
11	Grey/Pink	0,14mm ²
12	Red/Blue	0,14mm ²
13	White/Green	0,14mm ²
14	Brown/Green	0,25 mm ²
15	White/Yellow	0,25 mm ²
16	Yellow/Brown	0,25 mm ²
17	White/Grey	0,25 mm ²
18	Grey/Brown	0,14mm ²
19	White/Pink	0,14mm ²

Dimensions

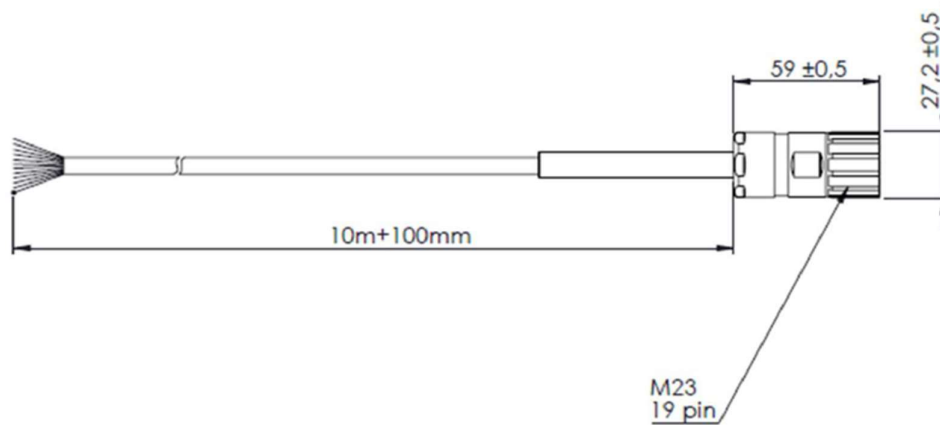

Ordering information

Description	Type	Order code
JSD-TK10-19	M23 Cable	2TLA930058R0000

Technical data

Technical data

Conductor diameter	11x0.25 mm ² ; 8x0.14 mm ²
Conductor material	Finely stranded copper
Wire insulation color	See table
Jacket insulation Material	PUR, halogen-free
Jacket insulation Outer Diameter	7.90 mm ± 0.20 mm
Jacket insulation Color	Black RAL 9005
M23-contact Material	PVC
M23-contact Outer Diameter	27 mm
M23-contact Color	Black
Nominal Voltage	24 V DC
Maximum Rated Voltage	36 V DC
IP-class	IP65
Temperature range	-40 to +90 C°

ABB Electrification Sweden AB
SE-721 61 Västerås, Sweden
abb.com/lowvoltage

Note

We reserve the right to make technical changes or modify the contents of this document without prior notice. With regard to purchase orders, the agreed particulars shall prevail. ABB does not accept any responsibility whatsoever for potential errors or possible lack of information in this document.

Copyright© 2022 ABB
All rights reserved