



Contact us

ABB Oy
Muuttitie 2A, 65320
Vaasa, Finland
abb.com/lowvoltage

© Copyright 2025 ABB. All rights reserved.
Specifications subject to change without notice.

34OT_PNG_PEG rev. C / 15CC390190M0201 # 28.02.2025



OT Plus Additional poles PNG_PEG_

PNG2 - Fixed neutral


PEG2 - Protective earth
OT63...100G2-BS
OT63...100G2-DS

PNG3 - Fixed neutral



PEG3 - Protective earth
OT30...160G3-BS
OT30...160G3-DS

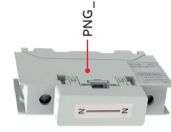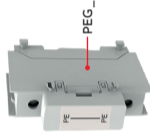


Install

 




Remove

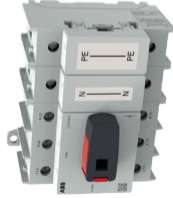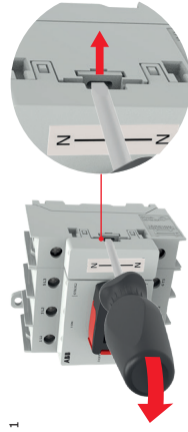

Install

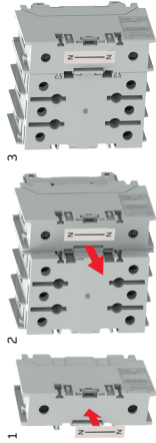

Remove

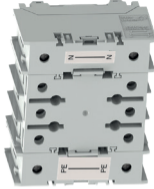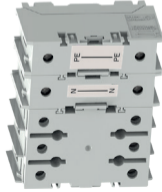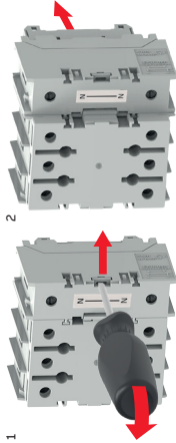

PNG2, PEG2

Wire type (Cu only)	1 Wire (mm ²)	2 Wire (mm ²)	Stripping length	Tightening torque
Class 5-Flexible	1.5-35	1.5-16	13-16 mm	POZIDRIV M5 Form 2
Class 2-Stranded	1.5-35	1.5-16	0.51- 0.63 in	2 Nm 18 lb.in
Class 6-Very flexible with ferrule	1.5-4	1.5-4		
Class 1-Solid	1.5-6	1.5-6		
UL - CU wire size (AWG)	16-2	16-8		

PNG3, PEG3

Wire type (Cu only)	1 Wire (mm ²)	2 Wire (mm ²)	Stripping length	Tightening torque
Class 5-Flexible	4-70	4-25	16-18 mm	Hex 4 mm
Class 2-Stranded	4-70	4-25	0.63- 0.71 in	6 Nm 53 lb.in
Class 6-Very flexible with ferrule	2.5-4	2.5-4		
Class 1-Solid	2.5-6	2.5-6		
UL - CU wire size (AWG)	12-2/0			



Warning! Hazardous voltage! Installation by person with electrotechnical expertise only.

