


On-load tap-changer type UCGL./C, VUCGL./C, 13 tap positions, linear switching.
 Max. effective No. of turns in pos. 1.
 The tap-changer is delivered set in pos. 7,
 the preceding pos. was 6.

Lindningskopplare typ UCGL./C, VUCGL./C, 13 lägen,
 linjär koppling.
 Max antal effektiva varv i läge 1.
 Lindningskopplaren levereras inställd i läge 7,
 föregående läge var 6.

Pos. Läge	Tap selector and diverter switch connect	30
1	1-V-x	
2	2-H-v	
3	3-V-x	
4	4-H-v	
5	5-V-x	
6	6-H-v	
7	7-V-x	
8	8-H-v	
9	9-V-x	
10	10-H-v	
11	11-V-x	
12	12-H-v	
13	13-V-x	

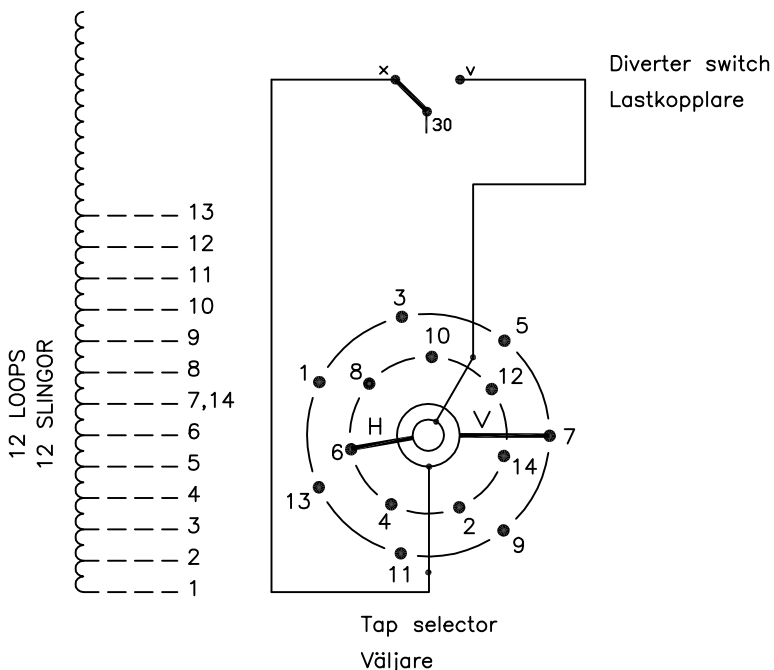


The tap-changer is shown in pos. 7,
 the preceding pos. was 6.
 The tap selector is seen from above.
 Contact arm V is located above contact arm H.

Lindningskopplaren visad i läge 7,
 föregående läge var 6.
 Väljaren sedd uppifrån.
 Kontaktarm V ligger över kontaktarm H.

Continuous lines show leads included in the
 tap-changer. Dashed lines show leads belonging
 to the cleats and leads.

Heldragna linjer visar ledare som ingår i
 lindningskopplaren. Streckade linjer visar
 ledare som tillhör anslutningsdonet.

We reserve all rights in this document and in the
 information contained therein. Reproduction, use or
 disclosure to third parties without express authority
 is strictly forbidden.
 © ABB 19

Sheet	Cont
	Year
Dept	Week
	Cont
Rev Ind	1
	VUCG Added.
Appd	SUKN
	07 47
Year	07
	47
Week	07
	47
Accepted by qual control	Accepted for prod by
	R.Yngvesson
Description (English)	DESCRIPTION (English)
	CONNECTION DIAGRAM
Description (own language)	DESCRIPTION (own language)
	KOPPLINGSSCHEMA
File name	0373-9
	Lang
Sheet	1
	Rev Ind
Cont	-
	5492 0373-9
 Asea Brown Boveri	