



中国国家强制性产品认证证书

证书编号：2024010307659819

认证委托人名称及地址

ABB Stotz-Kontakt GmbH
Eppelheimer Strasse 82 69123 Heidelberg Germany

生产者名称及地址

ABB Stotz-Kontakt GmbH
Eppelheimer Strasse 82 69123 Heidelberg Germany

生产企业名称及地址

ABB Bulgaria EOOD
1, Varna Str., 2850 Petrich, Bulgaria

产品名称和系列、型号、规格

电动机保护用断路器
MS325、MO325 具体规格见附页

产品标准和技术要求

GB/T 14048.2-2020; GB/T 14048.4-2020

上述产品符合《强制性产品认证实施规则 低压电器 低压元器件》
(CNCA-C03-02:2024)的要求，特发此证。

发证日期：2024年07月18日 有效期至：2029年07月17日

证书信息和有效性可扫描下方二维码或登录发证机构网站查验，
也可在认监委网站（www.cnca.gov.cn）查询。



签发：

谢肇煦



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

中国质量认证中心有限公司





中国国家强制性产品认证证书

证书编号: 2024010307659819

证书附页: 第 1 页 共 2 页

MS325, MO325

Uimp: 6kV;

Ui: 690V;

Ue: AC400V, AC500V, AC690V;

In: 0.1-0.16A, 0.16-0.25A, 0.25-0.4A, 0.4-0.63A, 0.63-1A, 1-1.6A, 1.6-2.5A, 2.5-4A, 4-6.3A,

6.3-9A, 9-12.5A, 12.5-16A, 16-20 A, 20A-25A;

过电流脱扣器类型: 热磁式;

Ics 和 Icu 见下表:

Short-circuit characteristics			
Current range(A ...A)	400V AC	500V AC	690V AC
	Icu=Ics(kA)	Icu=Ics(kA)	Icu=Ics(kA)
0.10~0.16	100kA	100kA	100kA
0.16~0.25			
0.25~0.40			
0.40~0.63			
0.63~1.00			
1.00~1.60			
1.60~2.50			40kA
2.50~4.00		60kA	10kA
4.00~6.30		40kA	7kA
6.30~9.00		30kA	5kA
9.00~12.5	75kA	27kA	4.5kA
12.5~16.0	60kA	25kA	4kA
16.0~20.0	55kA	22kA	3.5kA
20.0~25.0	50kA	20kA	3kA

选择性类别: A; 使用类别: AC-3, AC-3e;

适用频率: 50/60Hz; 适用于隔离;

脱扣级别: 10A;

极数: 3P

本页为证书附页, 应与证书主页同时使用。



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

中国质量认证中心有限公司



中国国家强制性产品认证证书

证书编号: 2024010307659819

证书附页: 第 2 页 共 2 页

型号解释:

MS 325 - 16
1 2 3

1: Product series 产品系列: MS/MO

MO: only have magnetic tripping that thermal tripping function is deactivated

MS: with thermal tripping and magnetic tripping

2: Basic type 基本型号: 325

3: Current range 额定电流:

0.16/0.25/0.40/0.63/1.00/1.60/2.50/4.00/6.30/9.00/12.5/16.0/20.0/25.0

本页为证书附页, 应与证书主页同时使用。



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

中国质量认证中心有限公司



CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation

CERTIFICATE NO.: 2024010307659819

NAME AND ADDRESS OF THE APPLICANT

ABB Stotz-Kontakt GmbH
Eppelheimer Strasse 82 69123 Heidelberg Germany

NAME AND ADDRESS OF THE MANUFACTURER

ABB Stotz-Kontakt GmbH
Eppelheimer Strasse 82 69123 Heidelberg Germany

NAME AND LOCATION OF THE FACTORY

ABB Bulgaria EOOD
1, Varna Str., 2850 Petrich, Bulgaria

PRODUCT NAME,MODEL AND SPECIFICATION

Manual Motor Starters
MS325、 MO325 see the appendix

STANDARDS AND TECHNICAL REQUIREMENTS FOR THE PRODUCTS

GB/T 14048.2-2020;GB/T 14048.4-2020

This is to certify that the above mentioned product(s) complies with the requirements of
implementation rules for compulsory certification(REFNO. CNCA-C03-02:2024).

Valid from: Jul.18,2024

Valid until: Jul.17,2029

The certificate information and validity could be checked by scanning the QR code below or logging in to
the website of the issuing authority, or on the website of the CNCA (www.cnca.gov.cn).



SIGNATURE:

谢肇煦



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.





CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

CERTIFICATE NO. : 2024010307659819

Appendix: Page 1 of 2

MS325, MO325

Uimp: 6kV;

Ui: 690V;

Ue: AC400V, AC500V, AC690V;

In: 0.1-0.16A, 0.16-0.25A, 0.25-0.4A, 0.4-0.63A, 0.63-1A, 1-1.6A, 1.6-2.5A, 2.5-4A, 4-6.3A,

6.3-9A, 9-12.5A, 12.5-16A, 16-20 A, 20A-25A;

Over current release type: Thermal Magnetic type;

Ics and Icu see table below:

Short-circuit characteristics			
Current range(A ...A)	400V AC	500V AC	690V AC
	Icu=Ics(kA)	Icu=Ics(kA)	Icu=Ics(kA)
0.10 ~0.16	100kA	100kA	100kA
0.16~0.25			
0.25~0.40			
0.40~0.63			
0.63~1.00			
1.00~1.60			
1.60~2.50			40kA
2.50~4.00	75kA	60kA	10kA
4.00~6.30		40kA	7kA
6.30~9.00		30kA	5kA
9.00~12.5		27kA	4.5kA
12.5~16.0	60kA	25kA	4kA
16.0~20.0	55kA	22kA	3.5kA
20.0~25.0	50kA	20kA	3kA

Selectivity Category: A; Utilization Category: AC-3, AC-3e;

50/60Hz; Suitable for isolation;

Trip class

com.cqc.cms.component.word.CertiAnnexDataModelcom.cqc.cms.component.word.

This page is attached to the certificate and should be used at the same time as the certificate page.



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.

本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation




CERTIFICATE FOR CHINA COMPULSORY PRODUCT CERTIFICATION

CERTIFICATE NO. : 2024010307659819

Appendix: Page 2 of 2

CertiAnnexDataModel: 10A;
Poles: 3P

本翻译文件不具有法律效力，
不得单独使用
This translated document
does not have legal validity and
cannot be used in isolation

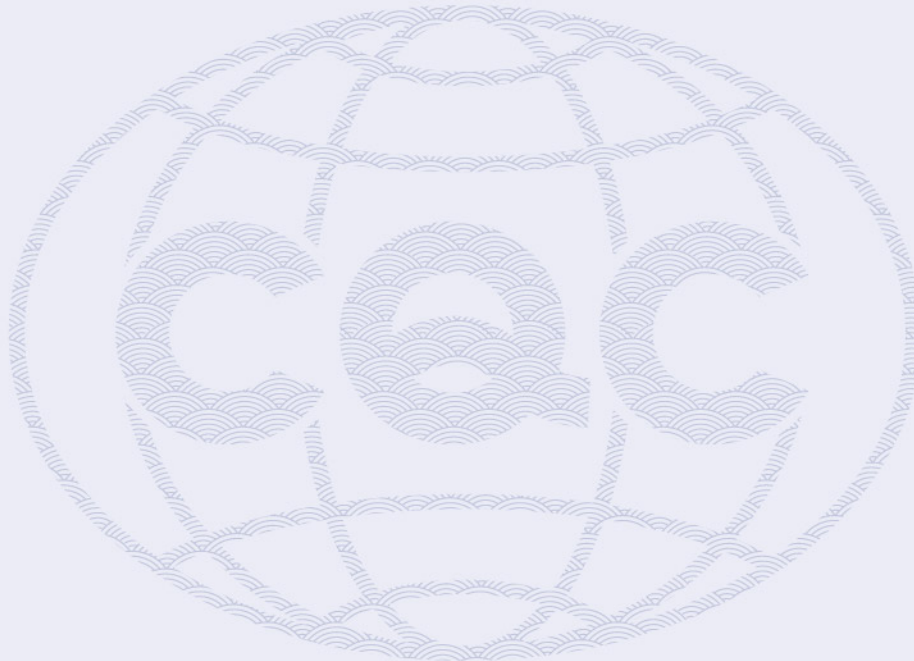

This page is attached to the certificate and should be used at the same time as the certificate page.



中国质量认证中心
CHINA QUALITY CERTIFICATION CENTRE

CHINA QUALITY CERTIFICATION CENTRE CO., LTD.