


MULTIPLES OF PLUG RATING

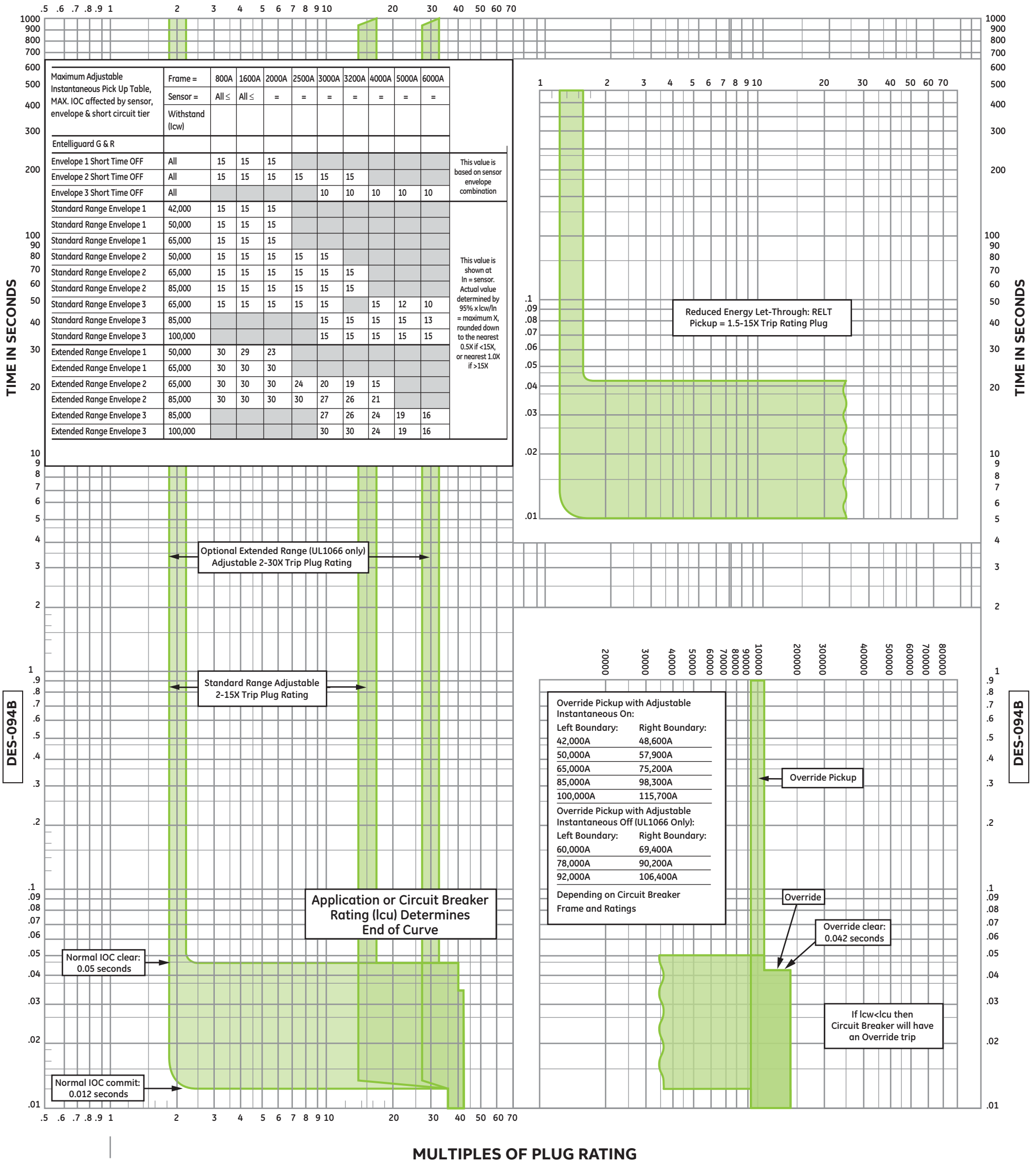

Low-Voltage Circuit Breakers

Frames	800-5000A	UL1066
Frames	800-6000A	UL489
Sensors	400-6000A	

All Voltages: 600 Vac and below

EntelliGuard TU Trip Unit for EntelliGuard G and R (Retrofill) Circuit Breakers
UL489 and UL1066 Stored Energy Mechanism Circuit Breakers

Instantaneous, Override (HSIOC)
Reduced Energy Let-Through Instantaneous (RELT)

Curves apply at 60 Hertz and from -20°C to 55°C circuit breaker ambient temperature.

DES-094B

Pickup Range
2X-15X Trip Rating Plug Standard
2X-30X Trip Rating Plug Extended Range
Maximum Pickup may be limited by CB AIC Rating or Withstand