

TECHNICAL DATA SHEET - INTERACTIVE PDF

Cable Tie, standard, 18 lbs. series

Colored Ties

Catamount[®]




Cable ties are primarily used to cinch wires and cables together to form a neat and organized bundle.

Certifications / Standards:



3-Part Specification: End User Tools

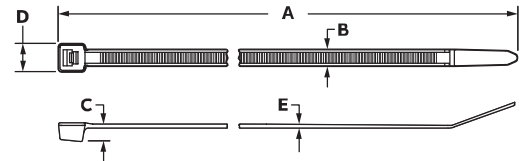

Ratings:

- Tensile Strength: 18lb (80N)
- Min. Operating Temperature: -40°F (-40°C)
- Max. Operating Temperature: 185°F (85°C)
- Min. Installation Temperature: 32°F (0°C)
- Min. Bundle Diameter: 0.06" (1.6mm)
- Max. Bundle Diameter: 0.75" (19mm)

Installation:

- Install with approved ABB cable tie tool such as ERG50, QC-100, L-200, L-400-C

Materials / Finishes:

- Natural Polyamide (Nylon 6.6)

Conforms to:

- AH-2 Plenum Rated
- UL94 V-2
- Type 21

Product selection - in. (mm)

Part no:	Color	A	B	C	D	E
GID no:		±0.25 (6.4)	±0.01 (0.25)	±0.03 (0.76)	±0.03 (0.76)	±0.01 (0.25)
L-4-18-2-C 7TAG054090R0076	Red	4.1 (104)	0.1 (2.5)	0.168 (4.3)	0.185 (4.7)	0.035 (0.9)
L-4-18-3-C 7TAG054090R0080	Orange					
L-4-18-4-C 7TAG054090R0099	Yellow					
L-4-18-5-C 7TAG054090R0103	Green					
L-4-18-6-C 7TAG054090R0120	Blue					
L-4-18-7-C 7TAG054090R0139	Purple					
L-4-18-8-C 7TAG054090R0143	Grey					
L-4-18FL-18-C 7TAG054090R0163	Fl. Green					
L-4-18FL-11-C 7TAG054090R0157	Fl. Pink					
L-4-18FL-17-C 7TAG054090R0161	Fl. Yellow					
L-4-18FL-16-C 7TAG054090R0159	Fl. Orange					
L-4-18FL-20-C 7TAG054090R0165	Fl. Blue					

Note: Product must be installed in accordance with applicable national and local electrical codes.