

TECHNICAL DATA SHEET - INTERACTIVE PDF

# Locknuts

## Stainless steel

**T&B® Fittings**



### Features:

- Stainless Steel 316 Construction
- Tightens without deformation
- Locknuts specially designed to:
  - Provide extended reach for clamping on thin boxes and enclosures
  - Permit tightening from outside
- Conduit range from ½" to 4"

### Applications:

- To connect externally threaded conduit or connector to a threadless opening in a box or enclosure

### Material / Finishes:

- 316 Stainless Steel

Locknuts for use on threaded conduit or connectors


### Certifications / Standards:



**3-Part Specification:**  
**Tools and Calculators**

### Conforms to:

- UL514B
- File number: E23018

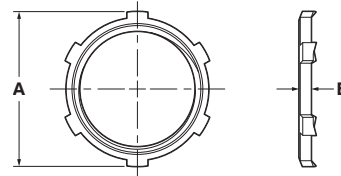

### Product selection and dimensions

Part no.	Conduit Trade size	A (Dia.) inches	B (thickness) inches
RLN12SST	½"	1.13"	0.13"
RLN34SST	¾"	1.38"	0.15"
RLN1SST	1"	1.72"	0.17"
RLN114SST	1¼"	2.07"	0.17"
RLN112SST	1½"	2.38"	0.17"
RLN2SST	2"	2.89"	0.19"
RLN212SST	2½"	3.70"	0.39"
RLN3SST	3"	4.29"	0.39"
RLN312SST	3½"	4.80"	0.39"
RLN4SST	4"	5.31"	0.39"

Note: Product must be installed in accordance with applicable national and local electrical codes.